


PART

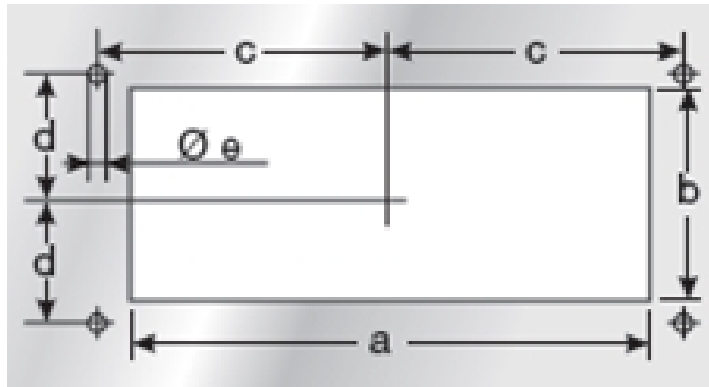

CUTOUT

NOTES:

- VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A LIST OF CURRENT PARTS APPLICABLE FOR USE WITH THIS PRODUCT.
- DIMENSIONS IN [ ] ARE METRIC.
- ALL MATERIALS AND COMPONENTS USED MEET THE MATERIAL RESTRICTIONS OF RoHS (EUROPEAN DIRECTIVE 2011/65/EU ON THE RESTRICTION OF HAZARDOUS SUBSTANCES) AS PROPOSED BY THE RoHS TECHNICAL ADAPTATION COMMITTEE.
- MATERIAL:  
FRAME - POLYPROPYLENE (PP)  
BLOCK - TPE
- PROTECTION CLASS WHEN USED WITH CEG GROMMETS:  
NEMA 1,12,4x\*  
IP 65
- TEMPERATURE RANGE: -22 - 212 °F
- FLAMMABILITY: VO
- RoHS COMPLIANT
- COMPLIANCE cURus
- UV RESISTANT
- WEIGHT: SEE TABLE

\*INDOOR USE



PART NUMBER	A	B	INSTALLATION HEIGHT in. (mm)	NUMBER OF OPENINGS			a	b	c	d	e	PART WEIGHT lbs. (g)	Pkg Qty
	in. (mm)	in. (mm)		SMALL	MEDIUM	LARGE	in. (mm)	in. (mm)	in. (mm)	in. (mm)	in. (mm)		
CEST2-E12	5.83 (148)	2.28 (58)	0.71 (18)	12	-	-	4.41 (142)	1.42 (36)	2.56 (112)	0.63 (16)	0.22 (5.5)	0.264 (120)	1
CEST2-E9	5.83 (148)	2.28 (58)	0.71 (18)	8	1	-	4.41 (142)	1.42 (36)	2.56 (112)	0.63 (16)	0.22 (5.5)	0.262 (119)	1
CEST2-E8	5.83 (148)	2.28 (58)	0.71 (18)	6	2	-	4.41 (142)	1.42 (36)	2.56 (112)	0.63 (16)	0.22 (5.5)	0.264 (120)	1
CEST2-E4	5.83 (148)	2.28 (58)	0.71 (18)	-	4	-	4.41 (142)	1.42 (36)	2.56 (112)	0.63 (16)	0.22 (5.5)	0.287 (130)	1
CEST2-E3	5.83 (148)	2.28 (58)	0.71 (18)	-	1	2	4.41 (142)	1.42 (36)	2.56 (112)	0.63 (16)	0.22 (5.5)	0.264 (120)	1
CEST2-D8	4.76 (121)	2.28 (58)	0.71 (18)	8	-	-	3.39 (86)	1.42 (36)	2.03 (52)	0.63 (16)	0.22 (5.5)	0.236 (107)	1
CEST2-D7	4.76 (121)	2.28 (58)	0.71 (18)	6	1	-	3.39 (86)	1.42 (36)	2.03 (52)	0.63 (16)	0.22 (5.5)	0.227 (103)	1
CEST2-D3	4.76 (121)	2.28 (58)	0.71 (18)	-	3	-	3.39 (86)	1.42 (36)	2.03 (52)	0.63 (16)	0.22 (5.5)	0.223 (101)	1
CEST2-D2	4.76 (121)	2.28 (58)	0.71 (18)	-	-	2	3.39 (86)	1.42 (36)	2.03 (52)	0.63 (16)	0.22 (5.5)	0.214 (97)	1
CEST2-C6	3.98 (101)	2.28 (58)	0.71 (18)	6	-	-	2.56 (65)	1.42 (36)	1.63 (41)	0.63 (16)	0.22 (5.5)	0.203 (92)	1
CEST2-C5	3.98 (101)	2.28 (58)	0.71 (18)	4	1	-	2.56 (65)	1.42 (36)	1.63 (41)	0.63 (16)	0.22 (5.5)	0.192 (87)	1
CEST2-C2	3.98 (101)	2.28 (58)	0.71 (18)	-	2	-	2.56 (65)	1.42 (36)	1.63 (41)	0.63 (16)	0.22 (5.5)	0.198 (90)	1
CEST2-B4	2.91 (74)	2.28 (58)	0.71 (18)	4	-	-	1.81 (46)	1.42 (36)	1.14 (29)	0.63 (16)	0.22 (5.5)	0.150 (68)	1
CEST2-A6	5.83 (148)	1.5 (38)	0.71 (18)	6	-	-	4.41 (142)	0.67 (17)	2.56 (112)	-	0.22 (5.5)	0.157 (71)	1

00A	9/13/2022	SERH	MDS	JADE	INITIAL RELEASE	124032/00
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN

PART NUMBER		SEE TABLE	
TITLE			
CEST2 Control Drawing			
CUSTOMER DRAWING			
ITEM REVISION NAME		00872EBC/00	
DATASET FILE NAME		00872EBC_DC/00A	
THIRD ANGLE PROJECTION		PANDUIT	
MATERIAL		SEE NOTE 4	
DRAWING NUMBER		00872EBC-DC	
DRAWN BY	DATE	CHK	SCALE
SERH	9/13/2022	MDS	1:1
SHEET 1 OF 1			B

B-SIZE CUSTOMER