


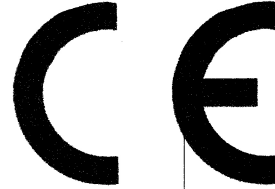

EU Declaration of Conformity

The undersigned representing the following supplier:

Panduit Corp.
World Headquarters
18900 Panduit Drive
Tinley Park, IL 60487
USA



Herewith declare under our sole responsibility:

Our product(s): Cable Tie Mounts

Product identification: Refer to Annex A

These products are in conformity with the provisions of the following EU Directives when used accordance with the instructions contained in the product documentation.

2014/35/EU Low Voltage Directive

And that the standards referenced below have been applied:

EN62275: 2015 Cable Management systems- Cable ties for electrical installations

Year of CE marking: 1996

The authorized representative located within the community maintains a copy of the technical documentation required by the directives: Panduit GmbH, Am Kronberger Hang 8, 65824 Schwalbach, Germany, Phone: +49(0)6995096129, E-mail: EMEA-CustomerServices@panduit.com.

I hereby declare that the product named above meets the essential requirements of, is in conformity with, and the CE mark has been applied according to, the relevant EC directives listed above using the relevant sections of the EC standards and other normative documents listed above.

Christopher S. Clancy
VP, Legal & General Counsel
Panduit Corp.

Date: May 27, 2020
Place: Tinley Park, Illinois, USA

Annex A

Adhesive Backed Cable Tie Mounts: **ABM***
Low Profile Cable Tie Mounts, user applied adhesive: **AM***
Epoxy Applied Cable Tie Swivel Mounts: **ASMS***
Control Panel Switch Cable Tie Mounts: **CPM***
Closed Cable Tie Connector Rings: **CR***
Open Cable Tie Connector Rings: **CROS***
Cable Spacer Crosses: **CSCS***
Epoxy Applied Cable Tie Mounts: **EMS***
Push Rivet Applied Low Profile Cable Tie Mounts: **KIMS***
Lightning Hole Cable Tie Mounts: **LHMS***
Low Profile Cable Tie Mounts: **LPMM*, LPMS*, SSMLP***
Metal Screw-On Mounts: **MBMS***
Lashing Tie Mounting Clips: **MCEH***
Metal Clip-On Cable Tie Mounts: **MCMS***
Masonry Push Barb Cable Tie Mounts: **MPMS*, MPMH***
Multiple Tie Plates: **MTP***
Push Button Cable Tie Mounts: **PBMS***
Push Barb Cable Tie Mounts: **PM2H***
Pan-Post Standoffs: **PP***
Winged Push Barb Cable Tie Mounts: **PWMS***
Right Angle Bases: **RAFCBI***
Right Angle Cable Tie Mounts: **RAMH*, RAMS***
Screw Applied Cable Tie Mounts: **SGTM***
4-way Tie Anchor Mounts: **TA1*, SSMTA***
Tie Anchor Mounts: **TA2***
Cable Tie Plates: **TP***
Pan-Ty[®] Cable Tie Mounts: **TM*, TMEH*, SSM***

Where * can be multi-digit alphanumeric codes and "-" indicating one or more of the following: length, width, thickness, nominal hole diameter, maximum panel thickness, maximum bundle diameter, minimum lops tensile strength, load rating, packaging size, material, application environment (weather resistant, screw size/metric screw size as applicable)