

# Panduit Cable Ties

Panduit® offers the most comprehensive selection of cable tie styles, sizes, materials, and colors to meet the needs of our customers. Our cable ties bundle, mount, and identify in countless indoor, outdoor, and harsh environment applications.



## Most Popular Cable Tie Styles

Cable Tie Style	Description
Panduit Locking Cable Ties	Designed to satisfy the needs of general applications, while delivering consistent performance and reliability. Featuring a curved tip to allow for easy pick up from flat surfaces and faster initial threading.
Panduit Dome-Top® Barb Tys	Features a unique patented design with its round smooth edges. Paired with the stainless steel locking barb, these cable ties provide consistent performance, reliability and infinite adjustability through the entire bundle range.
Panduit Releasable Cable Ties	The release tab permits easy release where changes are anticipated during development, production or servicing in the field. Ideal for heavy duty applications.


## Most Popular Cable Tie Materials

Cable Tie Material	Description	Continuous Use Temperature Rating
Nylon 6.6	Nylon 6.6 material is very versatile and can be used in countless applications. Because of the plenum rating Nylon 6.6 cable ties can be used in air handling spaces. Designed to be used in indoor environments only.	-76°F (-60°C) to 185°F (85°C)
Weather Resistant Nylon 6.6	Weather Resistant Nylon 6.6 material has great resistance to damage caused by ultraviolet light and can be used in both indoor and outdoor environments.	-76°F (-60°C) to 185°F (85°C)
Heat Stabilized Nylon 6.6	Heat Stabilized material is designed for high temperature applications in indoor environments only.	-76°F (-60°C) to 239°F (115°C)
Metal Detectable Nylon 6.6	Metal Detectable material is designed to help the food, beverage and pharmaceutical industries meet product manufacturing standards. The metal impregnated material is identifiable by metal detection equipment and is for indoor use only.	-40°F (-40°C) to 185°F (85°C)
Tefzel	Tefzel material is ideal for applications requiring resistance to environmental stresses such as: chemical attack, gamma radiation, ultraviolet radiation, and extreme high and low temperatures, can be used in both indoor and outdoor environments.	-76°F (-60°C) to 338°F (170°C)

## Panduit Locking Cable Tie, Miniature Cross Section


For more details about the style and material of the listed cable ties please reference page 12.

- Versatile cable ties, can be used in countless applications
- Curved tip allows for faster initial threading
- UL 62275 per UL file E56854

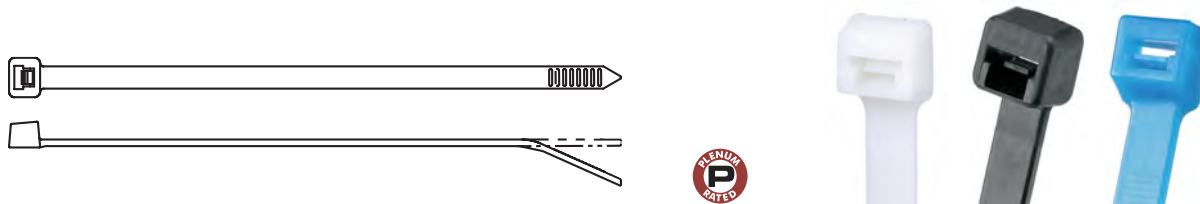

### Miniature Cable Ties 18 lbs (80N)

Part Number	Length In. (mm)	Width In. (mm)	Max. Bundle Dia. In. (mm)	Material	Color	UV Resistant	AH-2 Plenum Rated	Flammability Rating	UL 62275 Type	Pkg Qty	Installation Tools
<b>Panduit Locking Cable Tie</b>											
<a href="#">PLT1M-M</a>	3.9 (99)	.098 (2.5)	0.87 (22)	Nylon 6.6	Natural		✓	V-2	2, 21	1000	GTS-E, GS2B-E, PTS
<a href="#">PLT1M-M0</a>	3.9 (99)	.098 (2.5)	0.87 (22)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	1000	
<a href="#">PLT1M-M30</a>	3.9 (99)	.098 (2.5)	0.87 (22)	Heat Stabilized Nylon 6.6	Black			V-2	2, 21	1000	
<a href="#">PLT1M-M76</a>	4.0 (102)	.098 (2.5)	0.87 (22)	Tefzel	Aqua	✓		V-0	1, 11	1000	
<a href="#">PLT1.5M-M</a>	5.6 (142)	.098 (2.5)	1.25 (32)	Nylon 6.6	Natural		✓	V-2	2, 21	1000	
<a href="#">PLT2M-M</a>	8.0 (203)	.098 (2.5)	2.00 (51)	Nylon 6.6	Natural		✓	V-2	2, 21	1000	
<a href="#">PLT2M-M0</a>	8.0 (203)	.098 (2.5)	2.00 (51)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	1000	

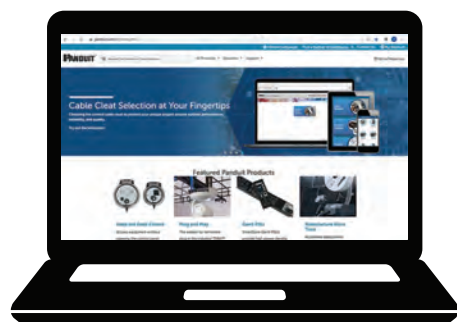


**Like what you see...  
and want more?**

Visit [www.panduit.com](http://www.panduit.com) for the full offering of Panduit products

**Panduit Locking Cable Tie & Dome-Top® Barb Ty, Intermediate Cross Section**

For more details about the style and material of the listed cable ties please reference page 12.

- Versatile cable ties, can be used in countless applications
- Curved tip allows for faster initial threading
- UL 62275 per UL file E56854

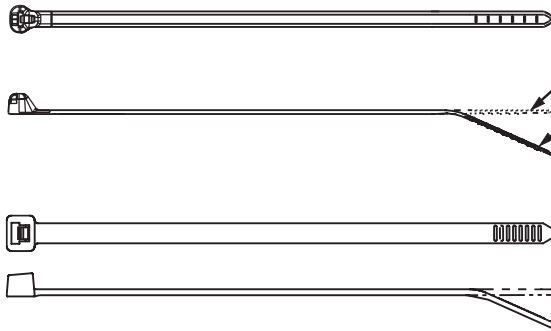


**Intermediate Cable Ties 40 lbs (178 N), -86 and -76 30 lbs (133 N)**

Part Number	Length In. (mm)	Width In. (mm)	Max. Bundle Dia. In. (mm)	Material	Color	UV Resistant	AH-2 Plenum Rated	Flammability Rating	UL 62275 Type	Pkg Qty	Installation Tools
<b>Panduit Locking Cable Tie</b>											
<a href="#">PLT1.5I-M</a>	5.6 (142)	0.142 (3.6)	1.38 (35)	Nylon 6.6	Natural		✓	V-2	2, 21	1000	<a href="#">GTS-E,</a> <a href="#">GS2B-E,</a> <a href="#">PTS</a>
<a href="#">PLT1.5I-M0</a>	5.6 (142)	0.142 (3.6)	1.38 (35)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	1000	
<a href="#">PLT2I-M</a>	8.0 (203)	0.142 (3.6)	2.00 (51)	Nylon 6.6	Natural		✓	V-2	2, 21	1000	
<a href="#">PLT2I-M0</a>	8.0 (203)	0.142 (3.6)	2.00 (51)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	1000	
<a href="#">PLT2I-C86</a>	8.0 (203)	0.135 (3.4)	2.00 (51)	Metal Detectable Nylon 6.6	Lt Blue			HB		100	
<a href="#">PLT2I-M76</a>	8.0 (203)	0.135 (3.4)	2.00 (51)	Tefzel	Aqua	✓		V-0	1, 11	1000	
<a href="#">PLT3I-M0</a>	11.4 (290)	0.145 (3.7)	3.00 (76)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	1000	
<b>Panduit Dome-Top® Barb Ty</b>											
<a href="#">BT3I-C0</a>	11.3 (287)	0.141 (3.6)	3.00 (76)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	100	<a href="#">GTS-E,</a> <a href="#">GS2B-E,</a> <a href="#">PTS</a>

## Panduit Locking Cable Tie & Dome-Top® Barb Ty, Standard Cross Section

For more details about the style and material of the listed cable ties please reference page 12.

- Versatile cable ties, can be used in countless applications
- Curved tip allows for faster initial threading
- UL 62275 per UL file E56854

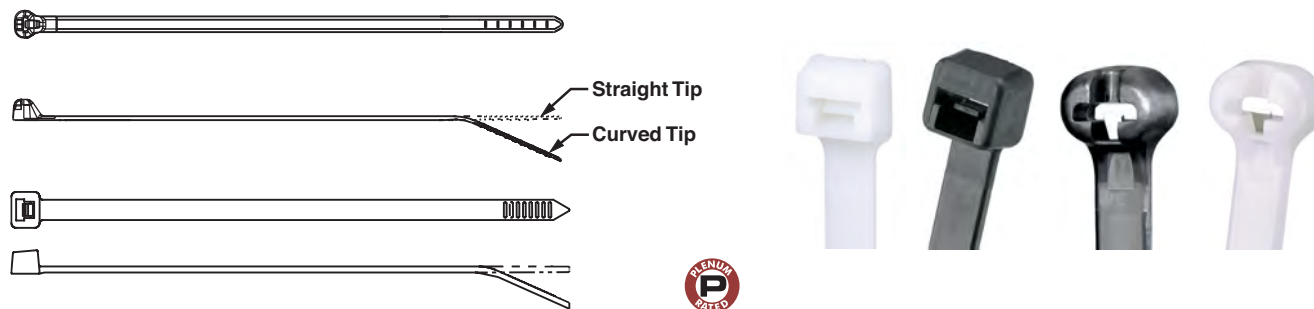

### Standard Cable Ties 50 lbs (222 N)


Part Number	Length In. (mm)	Width In. (mm)	Max. Bundle Dia. In. (mm)	Material	Color	UV Resistant	AH-2 Plenum Rated	Flammability Rating	UL 62275 Type	Pkg Qty	Installation Tools
<b>Panduit Locking Cable Tie</b>											
<a href="#">PLT2S-C</a>	7.4 (188)	0.190 (4.8)	1.88 (48)	Nylon 6.6	Natural		✓	V-2	2, 21, 2S, 21S	100	GTS-E, GS2B-E, GTH-E, GS4H-E, PTS, PTH
<a href="#">PLT2S-M</a>	7.4 (188)	0.190 (4.8)	1.88 (48)	Nylon 6.6	Natural		✓	V-2	2, 21, 2S, 21S	1000	
<a href="#">PLT2S-C0</a>	7.4 (188)	0.190 (4.8)	1.88 (48)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	100	
<a href="#">PLT2S-M0</a>	7.4 (188)	0.190 (4.8)	1.88 (48)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	1000	
<a href="#">PLT3S-C</a>	11.5 (292)	0.190 (4.8)	3.00 (76)	Nylon 6.6	Natural		✓	V-2	2, 21, 2S, 21S	100	
<a href="#">PLT3S-M</a>	11.5 (292)	0.190 (4.8)	3.00 (76)	Nylon 6.6	Natural		✓	V-2	2, 21, 2S, 21S	1000	
<a href="#">PLT3S-C0</a>	11.5 (292)	0.190 (4.8)	3.00 (76)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	100	
<a href="#">PLT3S-M0</a>	11.5 (292)	0.190 (4.8)	3.00 (76)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	1000	
<a href="#">PLT4S-C</a>	14.5 (368)	0.190 (4.8)	4.00 (102)	Nylon 6.6	Natural		✓	V-2	2, 21, 2S, 21S	100	
<a href="#">PLT4S-M</a>	14.5 (368)	0.190 (4.8)	4.00 (102)	Nylon 6.6	Natural		✓	V-2	2, 21, 2S, 21S	1000	
<a href="#">PLT4S-C0</a>	14.5 (368)	0.190 (4.8)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	100	
<a href="#">PLT4S-M0</a>	14.5 (368)	0.190 (4.8)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	1000	

<b>Panduit Dome-Top® Barb Ty</b>											
<a href="#">BT2S-M0</a>	8.0 (203)	0.185 (4.7)	2.00 (51)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	1000	GTS-E, GS2B-E, GTH-E, GS4H-E, PTS, PTH
<a href="#">BT3S-C0</a>	12.0 (305)	0.185 (4.7)	3.00 (76)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	100	
<a href="#">BT3S-M0</a>	12.0 (305)	0.185 (4.7)	3.00 (76)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	1000	
<a href="#">BT4S-M</a>	15.1 (384)	0.185 (4.7)	4.00 (102)	Nylon 6.6	Natural		✓	V-2	2, 21, 2S, 21S	1000	
<a href="#">BT4S-C0</a>	15.1 (384)	0.185 (4.7)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	100	
<a href="#">BT4S-M0</a>	15.1 (384)	0.185 (4.7)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	1000	

### Panduit Locking Cable Tie & Dome-Top® Barb Ty, Light-Heavy Cross Section

For more details about the style and material of the listed cable ties please reference page 12.

- Versatile cable ties, can be used in countless applications
- Curved tip allows for faster initial threading
- UL 62275 per UL file E56854

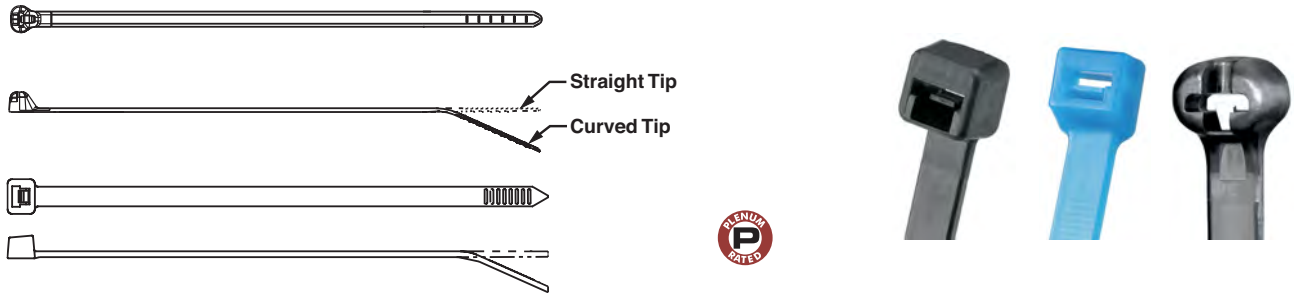


**Light-Heavy Cable Ties 120 lbs (534 N)**

Part Number	Length In. (mm)	Width In. (mm)	Max. Bundle Dia. In. (mm)	Material	Color	UV Resistant	AH-2 Plenum Rated	Flammability Rating	UL 62275 Type	Pkg Qty	Installation Tools
<b>Panduit Locking Cable Tie</b>											
<a href="#">PLT4H-L0</a>	14.5 (368)	0.300 (7.6)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	50	<a href="#">GTH-E,</a> <a href="#">GS4H-E,</a> <a href="#">GS4EH-E,</a> <a href="#">PTH</a>
<a href="#">PLT4H-TL0</a>	14.5 (368)	0.300 (7.6)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21	250	
<a href="#">PLT4H-TL76</a>	14.6 (371)	0.300 (7.6)	4.00 (102)	Tefzel	Aqua	✓		V-0	1, 11	250	
<b>Panduit Dome-Top® Barb Ty</b>											
<a href="#">BT4LH-L0</a>	14.9 (378)	0.275 (7.0)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	50	<a href="#">GTH-E,</a> <a href="#">GS4H-E,</a> <a href="#">GS4EH-E,</a> <a href="#">PTH</a>
<a href="#">BT4LH-TL0</a>	14.9 (378)	0.275 (7.0)	4.00 (102)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	250	
<a href="#">BT5LH-L0</a>	18.1 (460)	0.275 (7.0)	5.00 (127)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	50	
<a href="#">BT5LH-C0</a>	18.1 (460)	0.275 (7.0)	5.00 (127)	Weather Resistant Nylon 6.6	Black	✓	✓	V-2	2, 21, 2S, 21S	100	

### Panduit Releasable Cable Tie, Extra-Heavy Cross Section

For more details about the style and material of the listed cable ties please reference page 12.

- Versatile cable ties, can be used in countless applications
- UL 62275 per UL file E56854

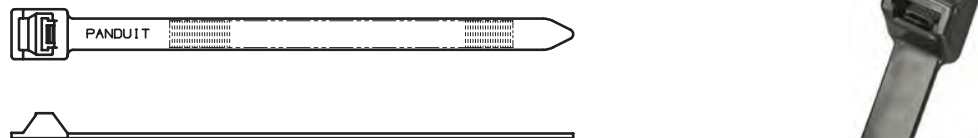

**Extra-Heavy Releasable Cable Tie 250 lbs (1112 N)**

Part Number	Length In. (mm)	Width In. (mm)	Max. Bundle Dia. In. (mm)	Material	Color	UV Resistant	AH-2 Plenum Rated	Flammability Rating	UL 62275 Type	Pkg Qty	Installation Tools
<b>Panduit Releasable Cable Tie</b>											
<a href="#">PRT5EH-C0</a>	20.1 (511)	0.500 (12.7)	5.00 (127)	Weather Resistant Nylon 6.6	Black	✓		V-2	1, 11	100	Hand install only