

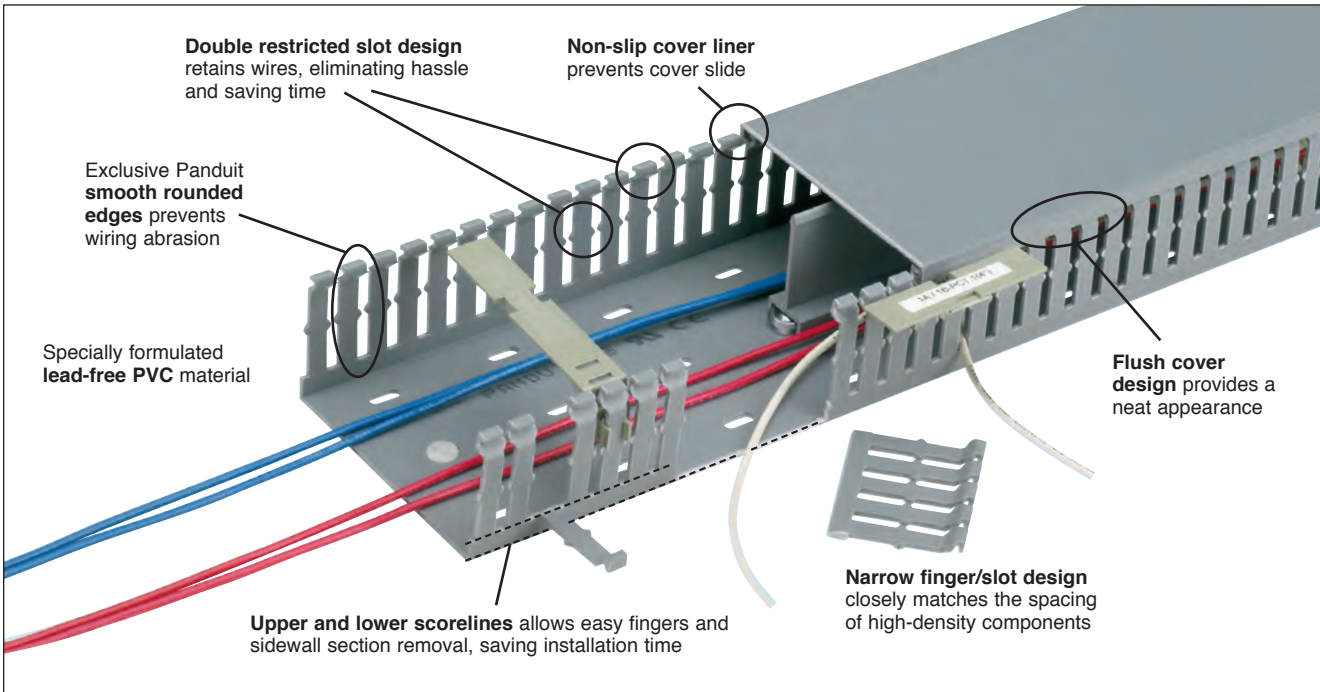
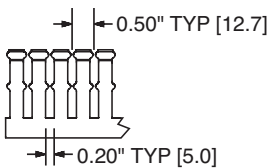


Features and Benefits – Panduit® Type F Narrow Slot Wiring Duct

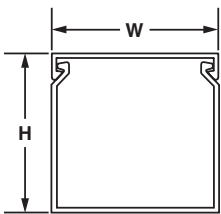

Panduit® Type F Narrow Slot Wiring Duct

- Narrow slot/finger design provides more slots to fit the spacing of high-density terminal blocks and other hardware
- Material: Lead-free PVC
- UL recognized continuous use temperature: 122°F (50°C)
- UL 94 flammability rating of V-0
- Conforms with NFPA 79-2015 section 13.3.1 requirement for flame retardant material
- Provided with mounting holes
- Base and cover length is 6 feet

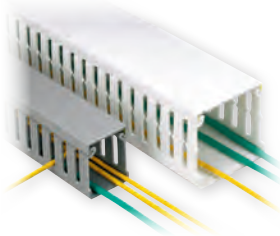

Multiple slot restrictors present with 2" and greater duct wall height.

Part Number	Duct Size (W x H)*		Slot Width		Cover Part Number	Std. Pkg. Qty.	Base Ctn. Qty.	Cover Ctn. Qty.
	In.	mm	In.	mm				
F1X3LG6	1.25 x 3.13	32.0 x 79.4	0.20	5.0	C1LG6	6	120	120
F1.5X3LG6	1.75 x 3.12	44.5 x 79.2			C1.5LG6			
F2X3LG6	2.25 x 3.14	57.2 x 79.8			C2LG6			
F2X4LG6	2.25 x 4.10	57.2 x 104.1			C2LG6			
F3X4LG6	3.25 x 4.10	82.6 x 104.1			C3LG6			
F4X4LG6	4.25 x 4.10	108.0 x 104.1			C4LG6			

Part number shown for LG (Light Gray). For other sizes and color availability visit www.Panduit.com.
 Base and cover sold separately.
 **"H" dimension includes duct and cover.
 For tool information, visit www.Panduit.com.