




2x2 Routing System Roadmap

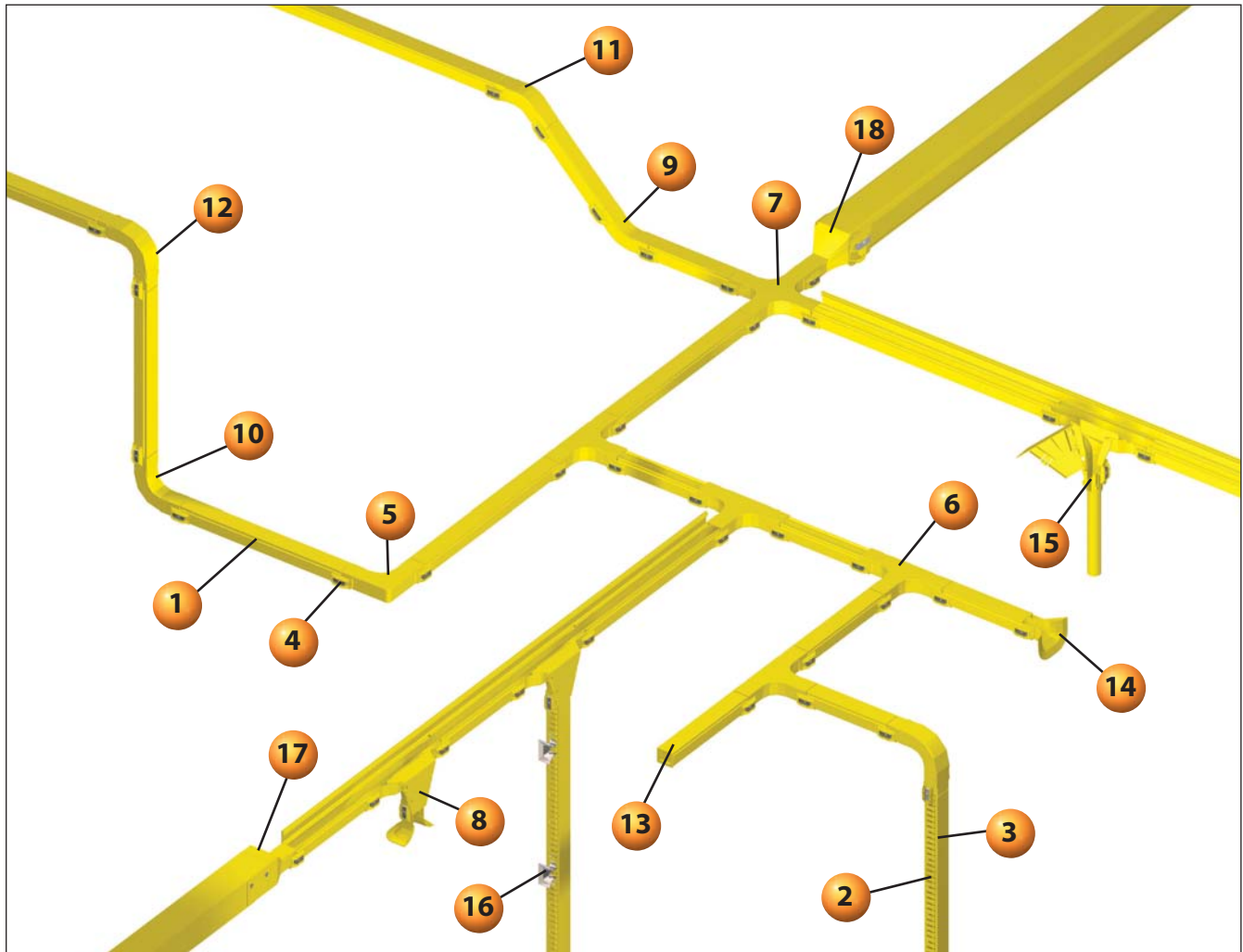


Fiber-Duct™ Mounting Brackets

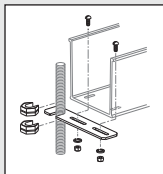


FTRBE12 – Existing Threaded Rod Bracket
(page J.63)

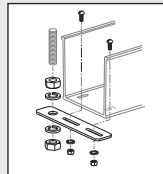


FTRBN12 – New Threaded Rod Bracket
(page J.63)

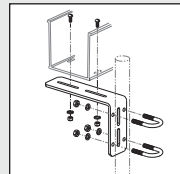


FUSB – Underfloor Pedestal Bracket
(page J.63)

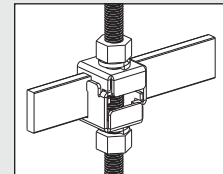


F2PCLB12 – Two-Piece Ladder Rack Bracket for Attaching Threaded Rod to 1 1/2" – 2" Ladder Rack
(page J.64)

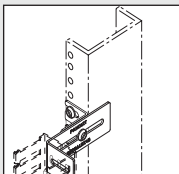


FZBA1.5X4 – Adjustable "Z" Bracket
(page J.64)

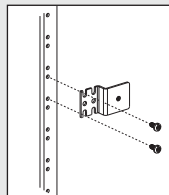

FZBLP – Low Profile "Z" Bracket
(page J.64)

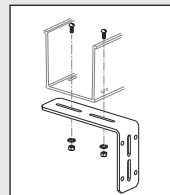

FLB – "L" Wall Mount Bracket
(page J.63)

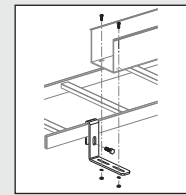

FLRB – Ladder Rack Bracket
(page J.63)

- 
1 **HS2X2**6 – 2x2 FiberRunner® Hinged Channel (page J.52)**
- 
2 **H2X2**6 – 2x2 FiberRunner® Hinged Slotted Channel (page J.52)**
- 
3 **HC2**6 – 2x2 FiberRunner® Snap-On Hinged Cover (page J.52)**
- 
4 **FBC2X2** – 2x2 QuikLock™ Coupler (page J.53)**
- 
5 **FRA2X2** – 2x2 Horizontal Right Angle Fitting (page J.60)**
- 
6 **FT2X2** – 2x2 Horizontal Tee Fitting (page J.60)**
- 
7 **FFWC2X2** – 2x2 4-Way Cross Fitting (page J.60)**
- 
8 **FVTHD2X2** – 2x2 Vertical Tee (page J.54)**
- 
9 **FIV452X2** – 2x2 Inside Vertical 45° Angle Fitting (page J.60)**
- 
10 **FIVRA2X2** – 2x2 Inside Vertical Right Angle Fitting (page J.60)**
- 
11 **FOV452X2** – 2x2 Outside 45° Angle Fitting (page J.60)**
- 
12 **FOVRA2X2** – 2x2 Outside Vertical Right Angle Fitting (page J.60)**
- 
13 **FHDEC2X2** – 2x2 End Cap Fitting (page J.53)**
- 
14 **FTR2X2** – 3-Sided BRC Trumpet Spillout for 2x2 Exit (page J.61)**
- 
15 **FIDT2X2** – 1-Port Spillout to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.61)**
- 
16 **TRC2HDBL – 2x2 Hinged Channel 1" Bend Radius Control Trumpet (page J.54)**
- 
17 **FRF42** – 4x4 to 2x2 Fiber-Duct™ Reducer Fitting (page J.60)**
- 
18 **FRRF4FD2** – 4x4 FiberRunner® to 2x2 Reducer Fitting (page J.43)**

**Available colors include: YL (Yellow), OR (Orange), BL (Black), and LG (Light Gray).