





Easy Selection Guide For Adhesive Backed Cable Tie Mounts

Panduit Corp.
17301 Ridgeland Avenue
Tinley Park, IL 60477-3091
Phone: 888-506-5400 Ext. 7346
Fax: 770-781-9076
Email: info@panduit.com
Website: www.panduit.com


ABM1M-A
ABM1M-AT

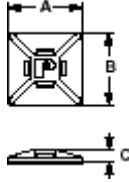


ABMM-A
ABMM-AT

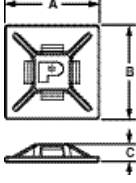


ABM2S

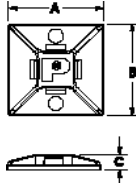


ABM100

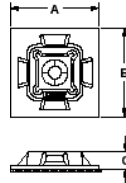

ABM112

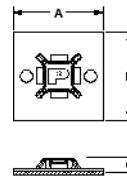



ABM3H
ABM4H

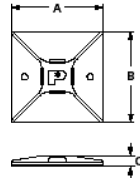

Part Number	Used With Cable Ties**	Dimensions Inches (mm)			Material	Color	Where Used	Adhesive Type/Static Load lbs. (g)	Packaging*			
		A	B	C					Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
ABM1M-A-C	M	.50 (12.7)	.50 (12.7)	.16 (4.0)	Nylon	White	Indoors	Rubber .13 (59)	100	500	1000	5000
ABM1M-AT-C	M	.50 (12.7)	.50 (12.7)	.16 (4.0)	Nylon	White	Indoors/ High Temp.	Acrylic .13 (59)	100	500	1000	5000
ABMM-A-C	M, I	.75 (19.1)	.75 (19.1)	.18 (4.6)	ABS	White	Indoors	Rubber .30 (136)	100	500	500	5000
ABMM-AT-C	M, I	.75 (19.1)	.75 (19.1)	.18 (4.6)	ABS	White	Indoors/ High Temp.	Acrylic .30 (136)	100	500	500	5000
ABMM-AT-C0	M, I	.75 (19.1)	.75 (19.1)	.18 (4.6)	ABS	Black	Outdoors/ High Temp.	Acrylic .30 (136)	100	500	500	5000
ABM2S-A-C	M, I, S	1.00 (25.4)	1.00 (25.4)	.20 (5.1)	ABS	White	Indoors	Rubber .50 (227)	100	500	500	5000
ABM2S-AT-C	M, I, S	1.00 (25.4)	1.00 (25.4)	.20 (5.1)	ABS	White	Indoors/ High Temp.	Acrylic .50 (227)	100	500	500	5000
ABM100-A-C	M, I, S	1.00 (25.4)	1.00 (25.4)	.24 (6.1)	Nylon	White	Indoors	Rubber .50 (227)	100	500	500	5000
ABM100-AT-C0	M, I, S	1.00 (25.4)	1.00 (25.4)	.24 (6.1)	Nylon	Black	Outdoors/ High Temp.	Acrylic .50 (227)	100	500	500	5000
ABM112-A-C	M, I, S	1.12 (28.6)	1.12 (28.6)	.16 (4.2)	Nylon	White	Indoors	Rubber .63 (286)	100	500	500	5000
ABM112-AT-C	M, I, S	1.12 (28.6)	1.12 (28.6)	.16 (4.2)	Nylon	White	Indoors/ High Temp.	Acrylic .63 (286)	100	1000	500	5000
ABM112-AT-C0	M, I, S	1.12 (28.6)	1.12 (28.6)	.16 (4.2)	Nylon	Black	Outdoors/ High Temp.	Acrylic .63 (286)	100	1000	500	5000
ABM3H-A-L	M, I, S LH, H, HLM	1.50 (38.1)	1.50 (38.1)	.25 (6.4)	Nylon	White	Indoors	Rubber 1.12 (508)	50	500	200	1000
ABM3H-AT-L	M, I, S LH, H, HLM	1.50 (38.1)	1.50 (38.1)	.25 (6.4)	Nylon	White	Indoors/ High Temp.	Acrylic 1.12 (508)	50	500	200	1000
ABM4H-A-L	M, I, S LH, H, HLM	2.00 (50.8)	2.00 (50.8)	.25 (6.4)	Nylon	White	Indoors	Rubber 1.12 (508)	50	500	200	1000
ABM4H-AT-L	M, I, S LH, H, HLM	2.00 (50.8)	2.00 (50.8)	.25 (6.4)	Nylon	White	Indoors/ High Temp.	Acrylic 1.12 (508)	50	500	200	1000

*Order Number of Pieces Required in Multiples of Packaging Quantities.

  
** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate, S = Standard, LH = Light Heavy, H = Heavy and HLM denotes TAK-TY™ Hook & Loop Cable Ties.



Tie Mounts Mechanically Applied



 TMEH



Part Number	Used With Cable Ties**	Dimensions Inches (mm)			Material	Color	Where Used	Mounting Method	Packaging*			
		A	B	C					Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
TM1S4-C	M	.513 (13.0)	.316 (8.0)	.230 (5.8)	Nylon	Natural	Indoors	#4 (M2.5) Screw	100	500	1000	5000
TM1S6-C	M	.513 (13.0)	.316 (8.0)	.230 (5.8)			Indoors	#6 (M3) Screw	100	500	1000	5000
TM2S8-C	M, I, S	.630 (16)	.425 (10.8)	.275 (7.0)			Indoors	#6 (M3) Screw	100	500	1000	5000
TM3S10-C	M, I, S, LH	.875 (22.2)	.620 (15.8)	.375 (9.5)			Indoors	#10 (M5) Screw	100	500	1000	5000
TMEH-S8-Q0	EH, HLT	1.65 (42)	.74 (19)	.61 (15)	Weather Resistant Nylon	Black	Outdoors	#8 (M4) Screw	25	250	100	500
TMEH-S10-Q0	EH, HLT	1.65 (42)	.74 (19)	.61 (15)			Outdoors	#10 (M5) Screw	25	250	100	500
TMEH-S25-Q0	EH, HLT	1.65 (42)	.74 (19)	.61 (15)			Outdoors	1/4" (M6) Screw	25	250	100	500

*Order Number of Pieces Required in Multiples of Packaging Quantities.

** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate, S = Standard, LH = Light Heavy, H = Heavy and HLT denotes TAK-TY™ Hook & Loop Cable Ties.

Push Mounts

Push Mount

Can be used where only one side of the panel is accessible.



Part Number	Used With Cable Ties**	Dimensions Inches (mm)	Panel Dimensions		Material	Color	Where Used	Mounting Method	Packaging*			
			Thickness Max.	Hole Diameter					Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
PM2H25-C	M, I, S	See Drawing	.125 (3.2)	.250 (6.4)	Nylon	Natural	Indoors	Inserted into pre-drilled hole	100	500	1000	5000

*Order Number of Pieces Required in Multiples of Packaging Quantities. ** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate and S = Standard.

Push Button Mount

Designed for use where both sides of the panel are accessible.




Part Number	Used With Cable Ties**	Dimensions Inches (mm)	Panel Dimensions		Material	Color	Where Used	Mounting Method	Packaging*			
			Thickness Max.	Hole Diameter					Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
PBMS-H25-C	M, I, S	See Drawing	.125 (3.2)	.250 (6.4)	Nylon	Natural	Indoors	Inserted into pre-drilled hole	100	500	1000	5000

*Order Number of Pieces Required in Multiples of Packaging Quantities. ** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate and S = Standard.

Tie Anchor Mounts

 Low profile, versatile mount for applications where space is limited.



Part Number	Used With Cable Ties**	Dimensions Inches (mm)				Material	Color	Where Used	Mounting Method	Packaging*			
		A	B	C	D					Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
TA1S8-C	M, I, S	.75 (19.1)	.375 (9.5)	.195 (5.0)	.170 (4.3)	Nylon	Natural	Indoors	#8 (M4) Screw	100	500	1000	5000

*Order Number of Pieces Required in Multiples of Packaging Quantities. ** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate and S = Standard.

Low Profile Mounts

Designed to secure wire bundles where space is limited.



Part Number	Used With Cable Ties**	Dimensions Inches (mm)				Material	Color	Where Used	Mounting Method	Packaging*			
		A	B	C	D					Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
LPMM-S2-C	M	.40 (10.2)	.32 (8.1)	.10 (2.5)	.096 ¹ (2.4)	Nylon	Natural	Indoors	#2 (M2) Flat-head Screw	100	1000	1000	10,000
LPMM-S5-C	M	.40 (10.2)	.32 (8.1)	.10 (2.5)	.137 ² (3.5)			Indoors	#5 (M3) Flat-head Screw	100	1000	1000	10,000
LPMS-S8-C	M, I, S	.75 (19.1)	.50 (12.7)	.12 (3.0)	.180 ² (4.6)			Indoors	#8 (M4) Flat-head Screw	100	1000	1000	5000

*Order Number of Pieces Required in Multiples of Packaging Quantities. ** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate and S = Standard.

Knock-In Low Profile Mounts

Secures wires to any pre-drilled panel.




Part Number	Used With Cable Ties**	A	Dimensions Inches (mm)	Hole Size	Material	Color	Where Used	Mounting Method	Packaging*			
									Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
KIMS-H366-C2	M, I, S	.155 (3.9)	See Drawing	.144 (3.7)	Nylon	Red	Indoors	Integral Push Rivet	100	500	1000	5000
KIMS-H430-C6	M, I, S	.180 (4.6)	See Drawing	.169 (4.3)	Nylon	Blue	Indoors	Integral Push Rivet	100	1000	1000	5000
KIMS-H500-C4	M, I, S	.202 (5.1)	See Drawing	.196 (5.0)	Nylon	Yellow	Indoors	Integral Push Rivet	100	500	1000	5000

*Order Number of Pieces Required in Multiples of Packaging Quantities. ** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate and S = Standard.

Masonry Push Mounts

 Used to secure wire, cable or tubing to masonry surfaces.



Part Number	Used With Cable Ties**	Dimensions Inches (mm)			Hole Dimensions		Material	Color	Where Used	Mounting Method	Packaging*			
		A	B	C	Drill Depth	Hole Diameter					Std. Pkg. Qty.	Std. Ctn. Qty.	Bulk Pkg. Qty.	Bulk Ctn. Qty.
MPMS25-C0	M, I, S	.97 (24.6)	.25 (6.4)	.22 (5.6)	1.25 (31.8)	.250 (6.4)	Weather-Resistant Nylon	Black	Outdoors or Indoors	Inserted into Pre-Drilled Hole	100	500	1000	5000
MPMH38-L0	M, I, S, LH, H, HLM	1.25 (31.8)	.30 (7.5)	.38 (9.6)	1.50 (38.1)	.375 (10)					50	500	500	5000

*Order Number of Pieces Required in Multiples of Packaging Quantities. ** Cable Tie Cross Section Sizes: M = Miniature, I = Intermediate, S = Standard, LH = Light Heavy, H = Heavy and HLM denotes TAK-TY™ Hook & Loop Cable Ties.

SA102N90-WA