

Net-Verse™ D-Type Cabinets

PANDUIT™

SPECIFICATION SHEET

specifications

The Net-Verse™ D-Type versatile cabinets shall consist of a welded and assembled steel frame construction available in 600mm (23.6") and 800mm (31.5") widths, 1000mm (39.4") and 1200mm (47.2") depths, and 42 RU and 45 RU heights. Cabinets shall include curved perforated front single hinge doors with 69% air flow rate and split rear perforated doors. Cabinet shall have two horizontal side panels on each side or optional as an accessory. The cabinet shall have fully adjustable equipment rails with provision for front (800mm wide) cable management fingers (fingers are sold separately). The top of cabinet includes brush cable entry points to prevent air leakage. Cabinet shall have optional equipment rails, vertical blanking panels and bottom panels for effective air sealing. Cabinet shall have two full height PDU brackets, one on each side. The entire cabinet shall be fully electrically bonded, including equipment rails, doors, and side panels. Cabinets shall have static 1200kg (2645 lbs.) load rating and rolling 500kg (1100 lbs.) load rating.



technical information

Dimensions:	600mm W (23.6") x 1000mm D (39.4") x 2045mm H (80.5") 600mm W (23.6") x 1000mm D (39.4") x 2178mm H (85.8") 600mm W (23.6") x 1200mm D (47.2") x 2045mm H (80.5") 600mm W (23.6") x 1200mm D (47.2") x 2178mm H (85.8") 800mm W (31.5") x 1000mm D (39.4") x 2045mm H (80.5") 800mm W (31.5") x 1000mm D (39.4") x 2178mm H (85.8") 800mm W (31.5") x 1200mm D (47.2") x 2045mm H (80.5") 800mm W (31.5") x 1200mm D (47.2") x 2178mm H (85.8")
Material:	Steel with durable black powder coat finish
Compliance:	EIA-310-E TIA/EIA-942
Packaging:	Cabinet ships assembled, one per pallet

key features and benefits

Doors	Curved perforated front single hinge doors with 69% air flow rate with two point locking system; perforated split hinge rear doors with three point locking system
Equipment rails	Fully adjustable equipment rails with RU marked to ensure correct location of IT equipment
Universal PDU brackets	Full height PDU brackets with provisions for securing and bundling cables
Horizontally split side panels	Provide easy secured access to installed equipment
Modular cable management fingers (Optional)	Provides bend radius control for each rack unit and can be positioned where required on cabinet posts for cable protection for increased network availability; provides design flexibility, scalability, and improved aesthetics for easier moves, adds, and changes
Durable coating	Cabinets are powder coated in a durable, low maintenance paint in black (RAL 9005)

applications

Net-Verse™ D-type Cabinets are the preferred choice for applications that require maximum flexibility and the capacity to manage high cable density in data center, enterprise or co-location deployment. The Net-Verse™ D-Type Cabinets are also compatible with Panduit cable management accessories and the Net-Contain™ Universal Aisle Containment System.

Net-Verse™ D-Type Cabinets
600mm W x 1000mm D Cabinet
includes casters and PDU bracket,
with side panels

42 RU: DA6212B
45 RU: DA6512B

600mm W x 1000mm D Cabinet
includes casters and PDU bracket,
(without side panels)

42 RU: DA6219B
45 RU: DA6519B

600mm W x 1200mm D Cabinet
includes casters and PDU bracket,
with side panels

42 RU: DA6222B
45 RU: DA6522B

600mm W x 1200mm D Cabinet
includes casters and PDU bracket,
(without side panels)

42 RU: DA6229B
45 RU: DA6529B

800mm W x 1000mm D Cabinet
includes casters and PDU bracket,
with side panels

42 RU: DA8212B
45 RU: DA8512B

800mm W x 1000mm D Cabinet
includes casters and PDU bracket,
(without side panels)

42 RU: DA8219B
45 RU: DA8519B

800mm W x 1200mm D Cabinet
includes casters and PDU bracket,
with side panels

42 RU: DA8222B
45 RU: DA8522B

800mm W x 1200mm D Cabinet
includes casters and PDU bracket,
(without side panels)

42 RU: DA8229B
45 RU: DA8529B

800mm W x 1000mm D Cabinet
includes casters, PDU bracket and
finger kit, with side panels

42 RU: DA8212BF
45 RU: DA8512BF

800mm W x 1000mm D Cabinet
includes casters, PDU bracket and
finger kit, (without side panels)

42 RU: DA8219BF
45 RU: DA8519BF

800mm W x 1200mm D Cabinet
includes casters, PDU bracket and
finger kit, with side panels

42 RU: DA8222BF
45 RU: DA8522BF

800mm W x 1200mm D Cabinet
includes casters, PDU bracket and
finger kit, (without side panels)

42 RU: DA8229BF
45 RU: DA8529BF

Accessories

Finger Kits

42 RU: D12F
45 RU: D15F


Tapped Rails

42 RU: D2ERTB
45 RU: D5ERTB


www.panduit.com/networkzone

Net-Verse™ D-Type Cabinets

Net-Verse™ D-Type Cabinet 600mm W x 42/45 RU x 1000mm/1200mm D

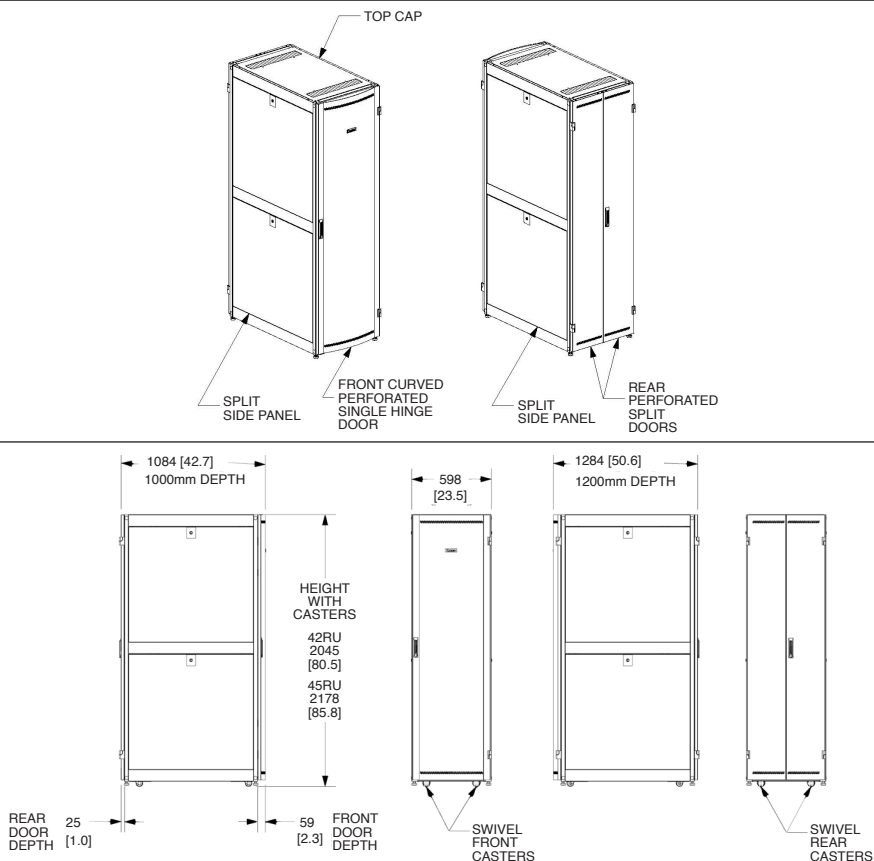

Net-Verse™ D-Type Cabinet 800mm W x 42/45 RU x 1000mm/1200mm D

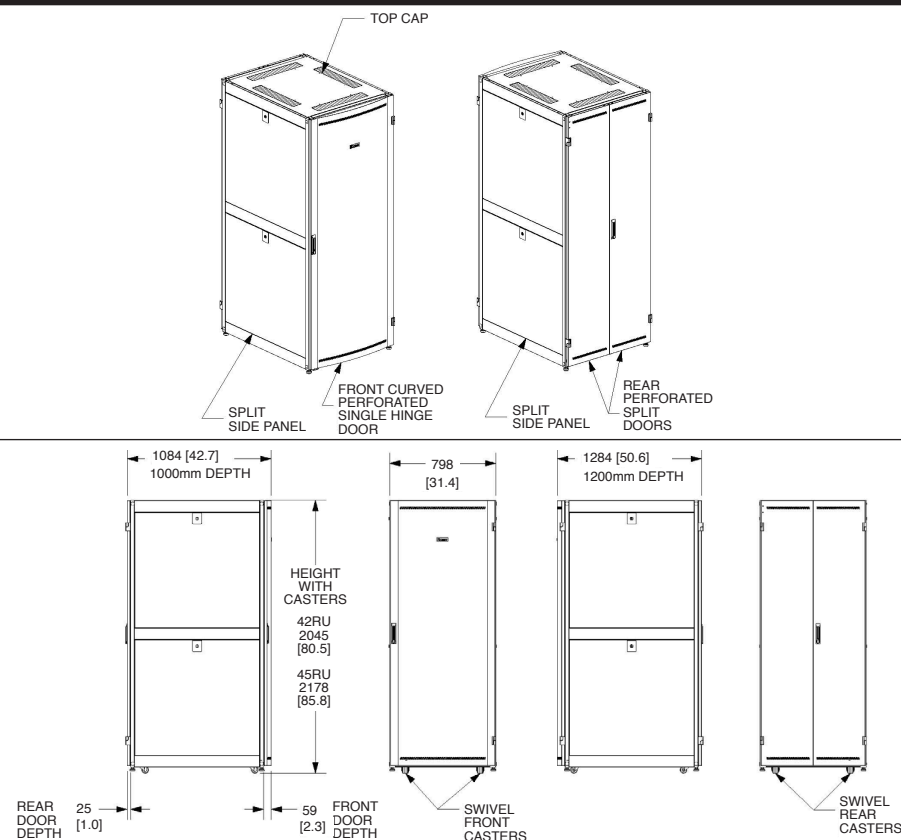

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty



For more information
Visit us at www.panduit.com

© 2018 Panduit Corp.
ALL RIGHTS RESERVED.
RKSP162--WW-CHI
1/2018