



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

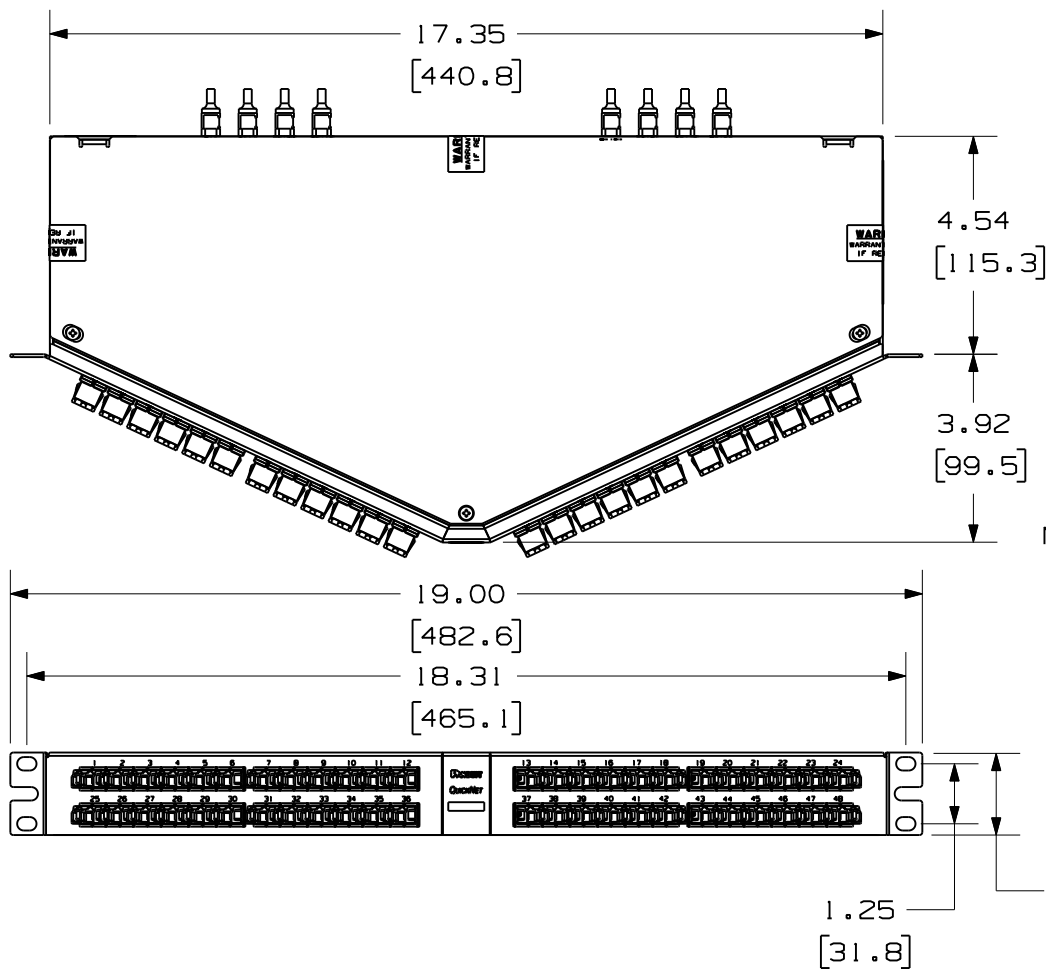

PANDUIT PART NUMBER	DESCRIPTION
F1ASXN-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 STANDARD FIBER STRAIGHT THROUGH
F1ASXN-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 STANDARD FIBER FLIPPED
F1ASXO-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 OPTIMIZED FIBER STRAIGHT THROUGH
F1ASXO-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 OPTIMIZED FIBER FLIPPED
F1ASZN-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 STANDARD FIBER STRAIGHT THROUGH
F1ASZN-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 STANDARD FIBER FLIPPED
F1ASZO-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 OPTIMIZED FIBER STRAIGHT THROUGH
F1ASZO-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 OPTIMIZED FIBER FLIPPED

NOTES:

- SEE CURRENT CATALOG FOR PART NUMBER SUFFIXES TO INDICATE COLOR AND/OR PACKAGE QUANTITIES.
- SEE CATALOG FOR A COMPLETE LIST OF PARTS APPLICABLE FOR USE WITH THIS PRODUCT.
- MATERIALS:
 - CASSETTE MATERIAL: ALUMINUM & STEEL
 - ADAPTER: COMPOSITE PLASTIC
- CASSETTE WEIGHT: 40.8oz [1157.7g]
- DIMENSIONS IN BRACKETS ARE METRIC

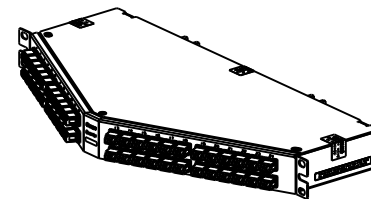


REV	DATE	BY	CHK	DESCRIPTION	ECN	R	CUST	SUP	OTH
R	10/21/09	MTV		RELEASED TO PRODUCTION	F00118AD-DC				

QUICKNET HDQ SERIES HIGH DENSITY CASSETTE
 IRU 96 FIBER ANGLED 12 FIBER MTP TO LC
 CUSTOMER DRAWING



 PANDUIT™
 CORP.
 TINLEY PARK, ILL 60477



ALL DIMENSIONS ARE GIVEN IN INCHES,
 UNLESS OTHERWISE SPECIFIED,
 DIMENSIONAL TOLERANCES ARE:
 (.X) (.XXX) ± .010 (.0.3)
 (.XX) ± .03 (.0.8) ANGLES

DRAWING FILENAME
 F00118AD_DC/01A

SCALE
 1:4

DRAWN BY
 MTV

REVIEW DRAWING NUMBERS

PART NO.
 SEE TABLE

DATE
 10-21-09

DRAWING NO.
 F00118AD-DC

CHK'D

SIZE
 A