



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

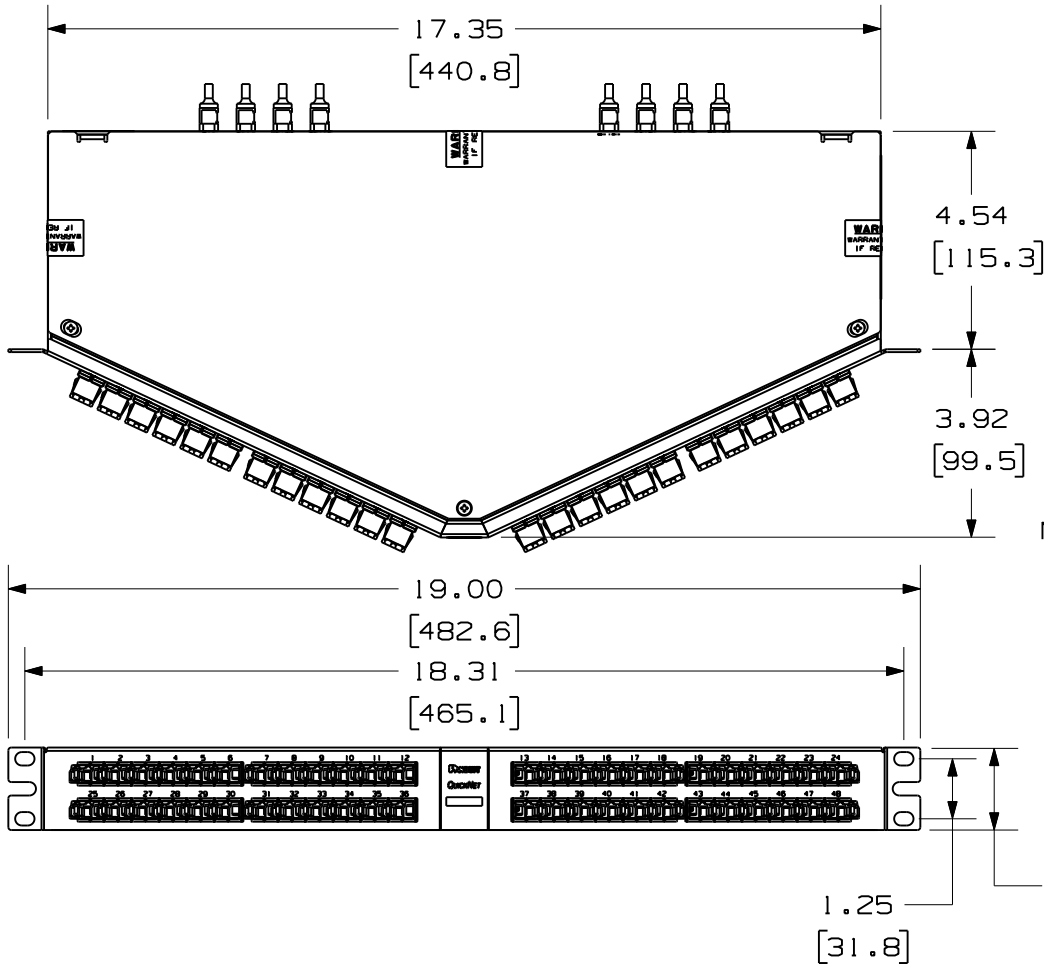

PANDUIT PART NUMBER	DESCRIPTION
FIASXN-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 STANDARD FIBER STRAIGHT THROUGH
FIASXN-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 STANDARD FIBER FLIPPED
FIASXO-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 OPTIMIZED FIBER STRAIGHT THROUGH
FIASXO-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM3 OPTIMIZED FIBER FLIPPED
FIASZN-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 STANDARD FIBER STRAIGHT THROUGH
FIASZN-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 STANDARD FIBER FLIPPED
FIASZO-9612-10S	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 OPTIMIZED FIBER STRAIGHT THROUGH
FIASZO-9612-10F	QUICKNET HDQ HIGH DENSITY CASSETTE OM4 OPTIMIZED FIBER FLIPPED

NOTES:

- SEE CURRENT CATALOG FOR PART NUMBER SUFFIXES TO INDICATE COLOR AND/OR PACKAGE QUANTITIES.
- SEE CATALOG FOR A COMPLETE LIST OF PARTS APPLICABLE FOR USE WITH THIS PRODUCT.
- MATERIALS:
 - CASSETTE MATERIAL: ALUMINUM & STEEL
 - ADAPTER: COMPOSITE PLASTIC
- CASSETTE WEIGHT: 40.8oz [1157.7g]
- DIMENSIONS IN BRACKETS ARE METRIC

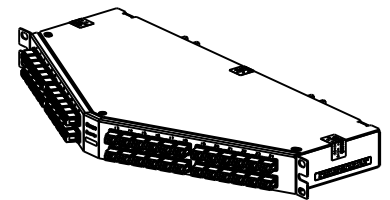


REV	DATE	BY	CHK	DESCRIPTION	ECN	R	CUST	SUP	OTH
R	10/21/09	MTV		RELEASED TO PRODUCTION	F00118AD-DC				

QUICKNET HDQ SERIES HIGH DENSITY CASSETTE
IRU 96 FIBER ANGLED 12 FIBER MTP TO LC
CUSTOMER DRAWING



 PANDUIT™
CORP.
TINLEY PARK, ILL 60477



ALL DIMENSIONS ARE GIVEN IN INCHES,
UNLESS OTHERWISE SPECIFIED,
DIMENSIONAL TOLERANCES ARE:
(.X) ±.03 | (.XXX) ±.010 | (0.3)
(.XX) ±.03 | (0.8) ANGLES

DRAWING FILENAME
F00118AD_DC/01A

SCALE
1:4

DRAWN BY
MTV

REVIEW DRAWING NUMBERS

PART NO.
SEE TABLE

DATE
10-21-09

DRAWING NO.
F00118AD-DC

CHK'D

SIZE
A