




6x4 Routing System Roadmap

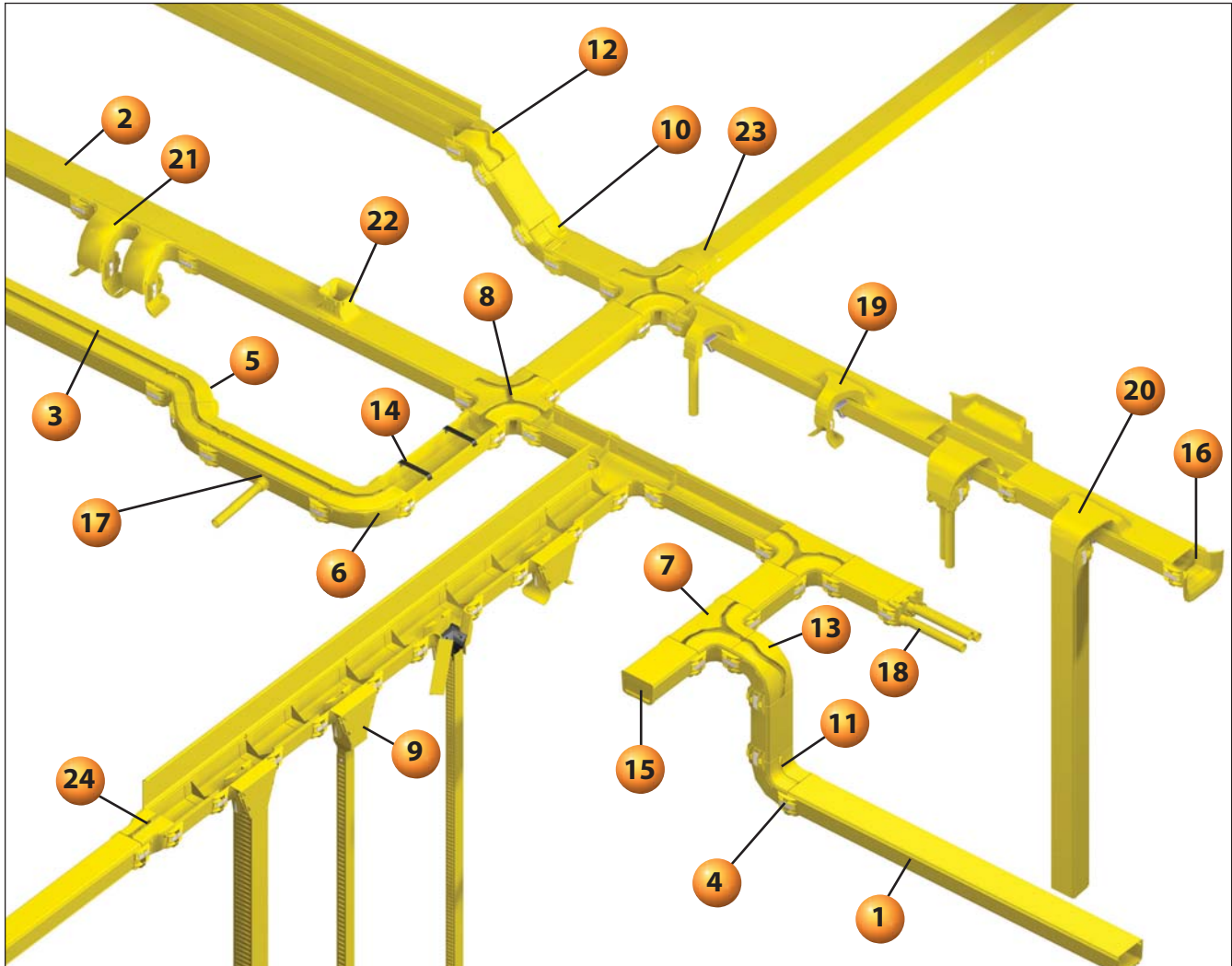


4x4 and 6x4 FiberRunner® Mounting Brackets

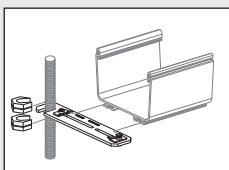


FR6TRBE58 – Existing Threaded Rod QuikLock™ Bracket (page J.33)

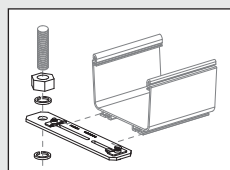


FR6TRBN58 – New Threaded Rod QuikLock™ Bracket (page J.33)

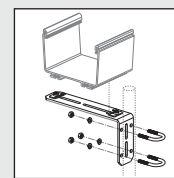


FR6USB – Underfloor Pedestal QuikLock™ Bracket (page J.33)

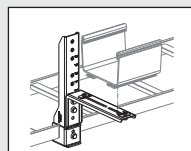


FR6ALB – Adjustable Ladder QuikLock™ Bracket (page J.33)

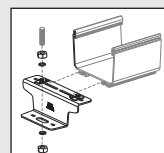


FR6CS58 – Center Support QuikLock™ Bracket (page J.33)

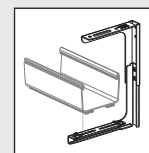

 
FR6ACB58 – Top Support Adjustable "C" QuikLock™ Bracket (page J.34)



 1 FR6X4** – 6x4 FiberRunner® Channel (page J.25)



 2 FRHC6** – 6x4 Snap-On Hinged Cover (page J.25)



3 FRSHC6** – 6x4 Split Hinged Cover (page J.25)



 
4 FRBC6X4** – 6x4 QuikLock™ Coupler (page J.26)




5 FRH456X4** – 6x4 Horizontal 45° Angle Fitting and FRH45SC6** – Optional Split Cover (page J.26)




6 FRRA6X4** – 6x4 Horizontal Right Angle Fitting and FRRASC6** – Optional Split Cover (page J.26)



 7 FRT6X4** – 6x4 Horizontal Tee Fitting and FRTSC6** – Optional Split Cover (page J.26)



 8 FRFWC6X4** – 6x4 4-Way Cross Fitting and FRFWCSC6** – Optional Split Cover (page J.27)




9 FRVT6X4** – 6x4 QuikLock™ Vertical Tee (page J.29)




10 FRIV456X4** – 6x4 Inside Vertical 45° Angle Fitting (page J.27)



 11 FRIVRA6X4** – 6x4 Inside Vertical 90° Angle Fitting (page J.27)



 12 FROV456X4** – 6x4 Outside Vertical 45° Angle Fitting and FROV45SC6** – Optional Split Cover (page J.27)



13 FROVRA6X4** – 6x4 Outside Vertical Right Angle Fitting and FROVRASC6** – Optional Split Cover (page J.28)



 
14 FRCR6BL-X – Cable Retainer for 6x4 System (page J.25)



15 FREC6X4** – 6x4 End Cap Fitting (page J.27)




16 FRTR6X4** – 3-Sided BRC Trumpet Spillout for 6x4 Exit (page J.32)




17 FR1.5IDE** – 1-Port Spillout Side Exit to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.31)



 
18 FRIDT6X4** – 3-Port Spillout to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.32)



 19 FRSPJ2X2** – Spill-Over Junction with 2x2 Exit and FRSPJC26** – Optional Cover for 6x4 System (pages J.29 and J.30)



 20 FRSPJ4X4** – Spill-Over Junction with 4x4 Exit and FRSPJC46** – Optional Cover for 6x4 System (page J.30)




21 FRDDS6X4** – 6x4 Dual Downspout and FRDDSHC6** – Optional Cover for 6x4 Dual Downspout (page J.31)



22 FRUPS6X4** – 6x4 Up Spout (page J.32)



 23 FRRF64** – 6x4 FiberRunner® Fitting to 4x4 Fiber-Duct™ Channel Reducer Fitting (page J.28)



24 FRRF6FR4** – 6x4 to 4x4 FiberRunner® Reducer Fitting and FRRF6FR4SC** – Optional Split Cover (page J.28)

**Available Colors include: YL (Yellow), OR (Orange), and BL (Black).
Note: Additional 6 x 4 and 4 x 4 bracket applications, see page J.38.