




### 4x4 Routing System Roadmap

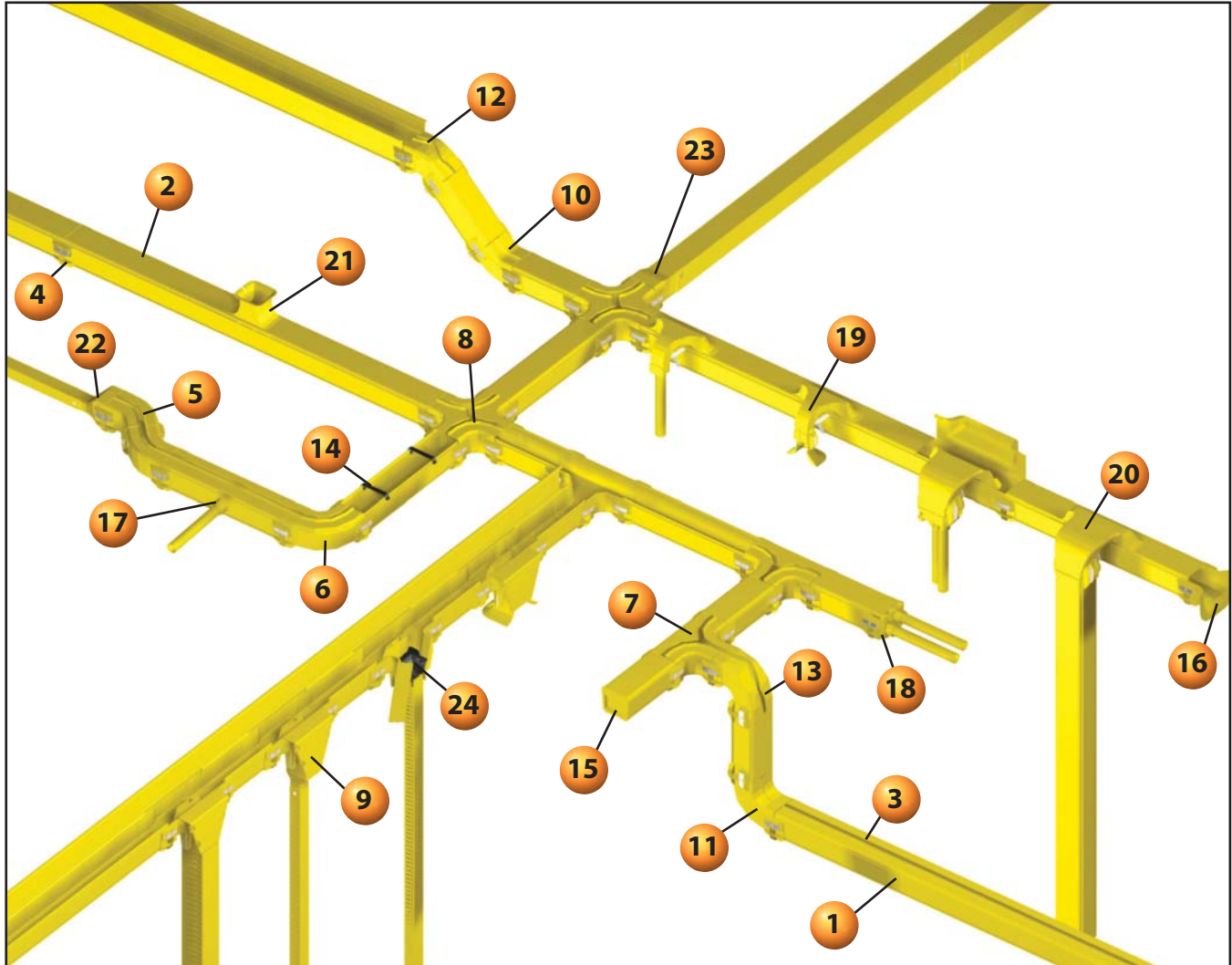


### 4x4 and 6x4 FiberRunner® Mounting Brackets

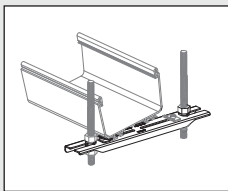


**FR6TB38 - Trapeze QuikLock™ Bracket**  
(page J.34)

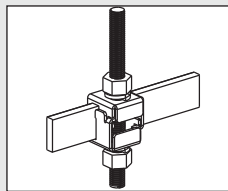


**F2PCLB - Two-Piece Ladder Rack Bracket for Attaching Threaded Rod to 1 1/2\"/>**

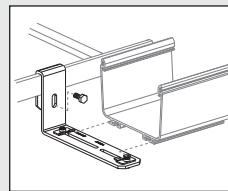


**FR6LRB - Ladder Rack QuikLock™ Bracket**  
(page J.35)

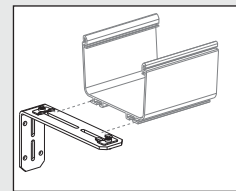

 
**FR6LB - \"L\" Wall Mount QuikLock™ Bracket**  
(page J.35)



 - 1** FR4X4\*\*6 – 4x4 FiberRunner® Channel (page J.40)



 
- 2** FRHC4\*\*6 – 4x4 Snap-On Hinged Cover (page J.40)




- 3** FRSHC4\*\*6 – 4x4 Split Hinged Cover (page J.40)



 
- 4** FRBC4X4\*\* – 4x4 QuikLock™ Coupler (page J.41)



 
- 5** FRH454X4\*\* – 4x4 Horizontal 45° Angle Fitting and FRH45SC4\*\* Optional Split Cover (page J.41)



 - 6** FRRA4X4\*\* – 4x4 Horizontal Right Angle Fitting and FRRASC4\*\* – Optional Split Cover (page J.41)



 - 7** FRT4X4\*\* – 4x4 Horizontal Tee Fitting and FRTSC4\*\* – Optional Split Cover (page J.42)



- 8** FRFWC4X4\*\* – 4x4 4-Way Cross Fitting and FRFWCSC4\*\* – Optional Split Cover (page J.42)



 
- 9** FRVT4X4\*\* – 4x4 QuikLock™ Vertical Tee (page J.44)




- 10** FRIV454X4\*\* – 4x4 Inside Vertical 45° Angle Fitting (page J.42)




- 11** FRIVRA4X4\*\* – 4x4 Inside Vertical 90° Angle Fitting (page J.42)



 - 12** FROV454X4\*\* – 4x4 Outside Vertical 45° Angle Fitting and FROV45SC4\*\* – Optional Split Cover (pages J.42 and J.43)



 
- 13** FROVRA4X4\*\* – 4x4 Outside Vertical Right Angle Fitting and FROVRASC4\*\* – Optional Split Cover (page J.43)




- 14** FRCR4BL-X – Cable Retainer for 4x4 System (page J.40)



 
- 15** FREC4X4\*\* – 4x4 End Cap Fitting (page J.42)



 
- 16** FRTR4X4\*\* – 3-Sided BRC Trumpet Spillout for 4x4 FiberRunner® Exit (page J.46)



 
- 17** FR1.5IDE\*\* – 1-Port Spillout Side Exit to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.46)



 - 18** FRIDT4X4\*\* – 2-Port Spillout to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.46)



 
- 19** FRSPJ2X2\*\* – Spill-Over Junction with 2x2 Exit and FRSPJC24\*\* – Optional Cover for 4x4 System (page J.45)




- 20** FRSPJ4X4\*\* – Spill-Over Junction with 4x4 Exit and FRSPJC44\*\* – Optional Cover for 4x4 System (pages J.45 and J.46)



 - 21** FRUPS4X4\*\* – 4x4 Up Spout (page J.46)



 - 22** FRRF4FD2\*\* – 4x4 FiberRunner® System to 2x2 Reducer Fitting with Cover (page J.43)



- 23** FRRF4FD4\*\* – 4x4 FiberRunner® System to 4x4 Fiber-Duct™ Reducer Fitting with Cover (page J.43)



- 24** FRLPR42BL – Low Profile Reducer 4x4 to 2x2 for Vertical Tee (page J.44)

\*\*Available colors include: YL (Yellow), OR (Orange), and BL (Black).  
Note: Additional 6x4 and 4x4 bracket applications, see page J.23.