




### 6x4 Routing System Roadmap

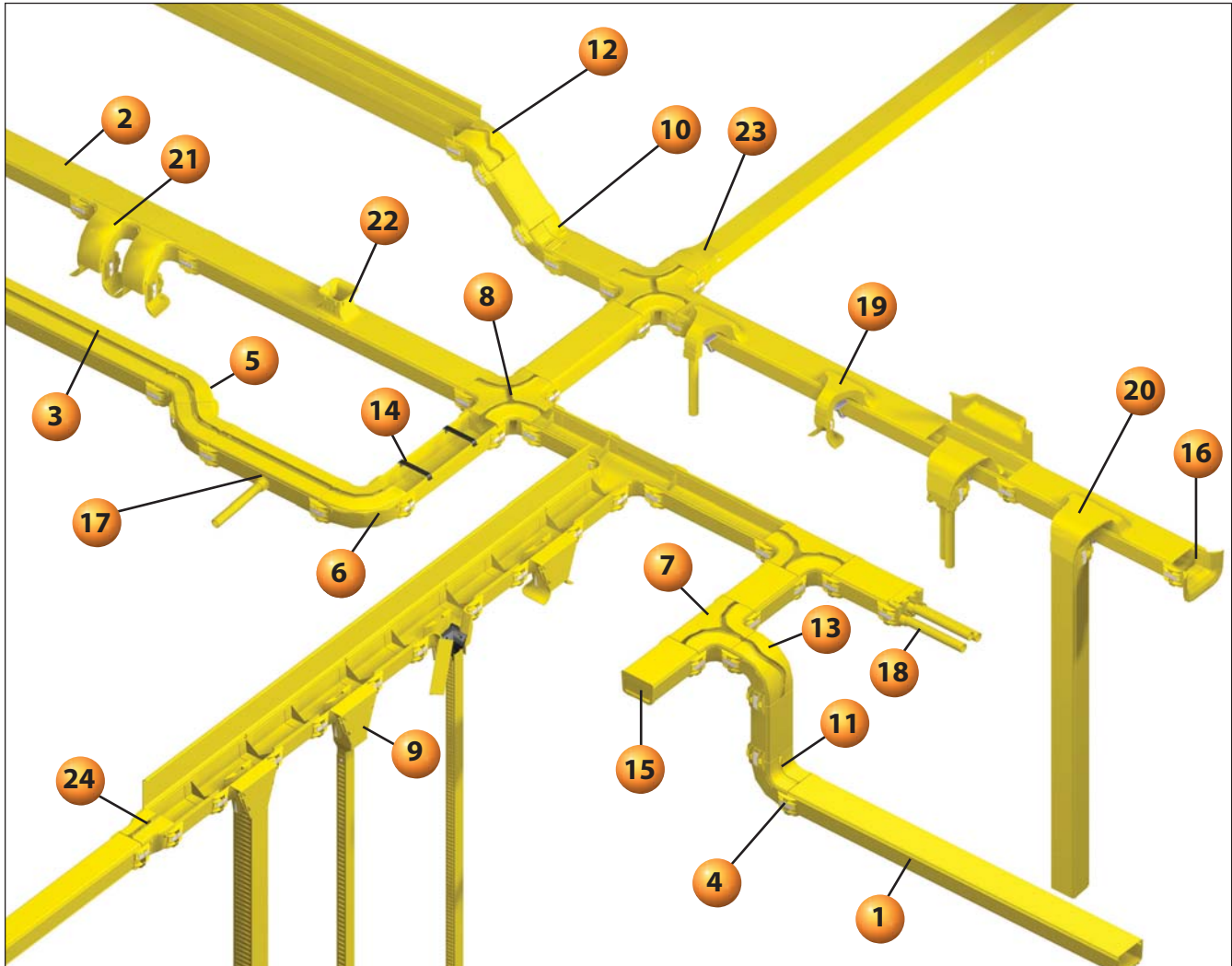


### 4x4 and 6x4 FiberRunner® Mounting Brackets

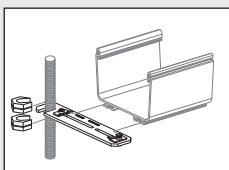


FR6TRBE58 – Existing Threaded Rod QuikLock™ Bracket (page J.33)

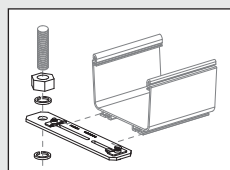


FR6TRBN58 – New Threaded Rod QuikLock™ Bracket (page J.33)

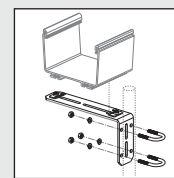


FR6USB – Underfloor Pedestal QuikLock™ Bracket (page J.33)

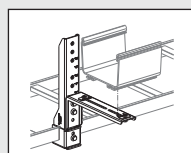


FR6ALB – Adjustable Ladder QuikLock™ Bracket (page J.33)

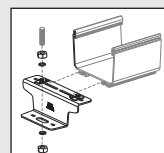


FR6CS58 – Center Support QuikLock™ Bracket (page J.33)

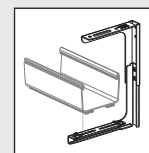

 
FR6ACB58 – Top Support Adjustable "C" QuikLock™ Bracket (page J.34)



 **1** FR6X4\*\* – 6x4 FiberRunner® Channel (page J.25)



 **2** FRHC6\*\* – 6x4 Snap-On Hinged Cover (page J.25)



**3** FRSHC6\*\* – 6x4 Split Hinged Cover (page J.25)



**4** FRBC6X4\*\* – 6x4 QuikLock™ Coupler (page J.26)



 
**5** FRH456X4\*\* – 6x4 Horizontal 45° Angle Fitting and FRH45SC6\*\* – Optional Split Cover (page J.26)



**6** FRRA6X4\*\* – 6x4 Horizontal Right Angle Fitting and FRRASC6\*\* – Optional Split Cover (page J.26)



**7** FRT6X4\*\* – 6x4 Horizontal Tee Fitting and FRTSC6\*\* – Optional Split Cover (page J.26)



**8** FRFWC6X4\*\* – 6x4 4-Way Cross Fitting and FRFWCSC6\*\* – Optional Split Cover (page J.27)



 
**9** FRVT6X4\*\* – 6x4 QuikLock™ Vertical Tee (page J.29)




**10** FRIV456X4\*\* – 6x4 Inside Vertical 45° Angle Fitting (page J.27)



**11** FRIVRA6X4\*\* – 6x4 Inside Vertical 90° Angle Fitting (page J.27)



 **12** FROV456X4\*\* – 6x4 Outside Vertical 45° Angle Fitting and FROV45SC6\*\* – Optional Split Cover (page J.27)



**13** FROVRA6X4\*\* – 6x4 Outside Vertical Right Angle Fitting and FROVRASC6\*\* – Optional Split Cover (page J.28)



 
**14** FRCR6BL-X – Cable Retainer for 6x4 System (page J.25)



**15** FREC6X4\*\* – 6x4 End Cap Fitting (page J.27)




**16** FRTR6X4\*\* – 3-Sided BRC Trumpet Spillout for 6x4 Exit (page J.32)




**17** FR1.5IDE\*\* – 1-Port Spillout Side Exit to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.31)



 
**18** FRIDT6X4\*\* – 3-Port Spillout to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.32)



 **19** FRSPJ2X2\*\* – Spill-Over Junction with 2x2 Exit and FRSPJC26\*\* – Optional Cover for 6x4 System (pages J.29 and J.30)



 **20** FRSPJ4X4\*\* – Spill-Over Junction with 4x4 Exit and FRSPJC46\*\* – Optional Cover for 6x4 System (page J.30)




**21** FRDDS6X4\*\* – 6x4 Dual Downspout and FRDDSHC6\*\* – Optional Cover for 6x4 Dual Downspout (page J.31)



**22** FRUPS6X4\*\* – 6x4 Up Spout (page J.32)



 **23** FRRF64\*\* – 6x4 FiberRunner® Fitting to 4x4 Fiber-Duct™ Channel Reducer Fitting (page J.28)



**24** FRRF6FR4\*\* – 6x4 to 4x4 FiberRunner® Reducer Fitting and FRRF6FR4SC\*\* – Optional Split Cover (page J.28)

\*\*Available Colors include: YL (Yellow), OR (Orange), and BL (Black).  
Note: Additional 6 x 4 and 4 x 4 bracket applications, see page J.38.