




6x4 Routing System Roadmap

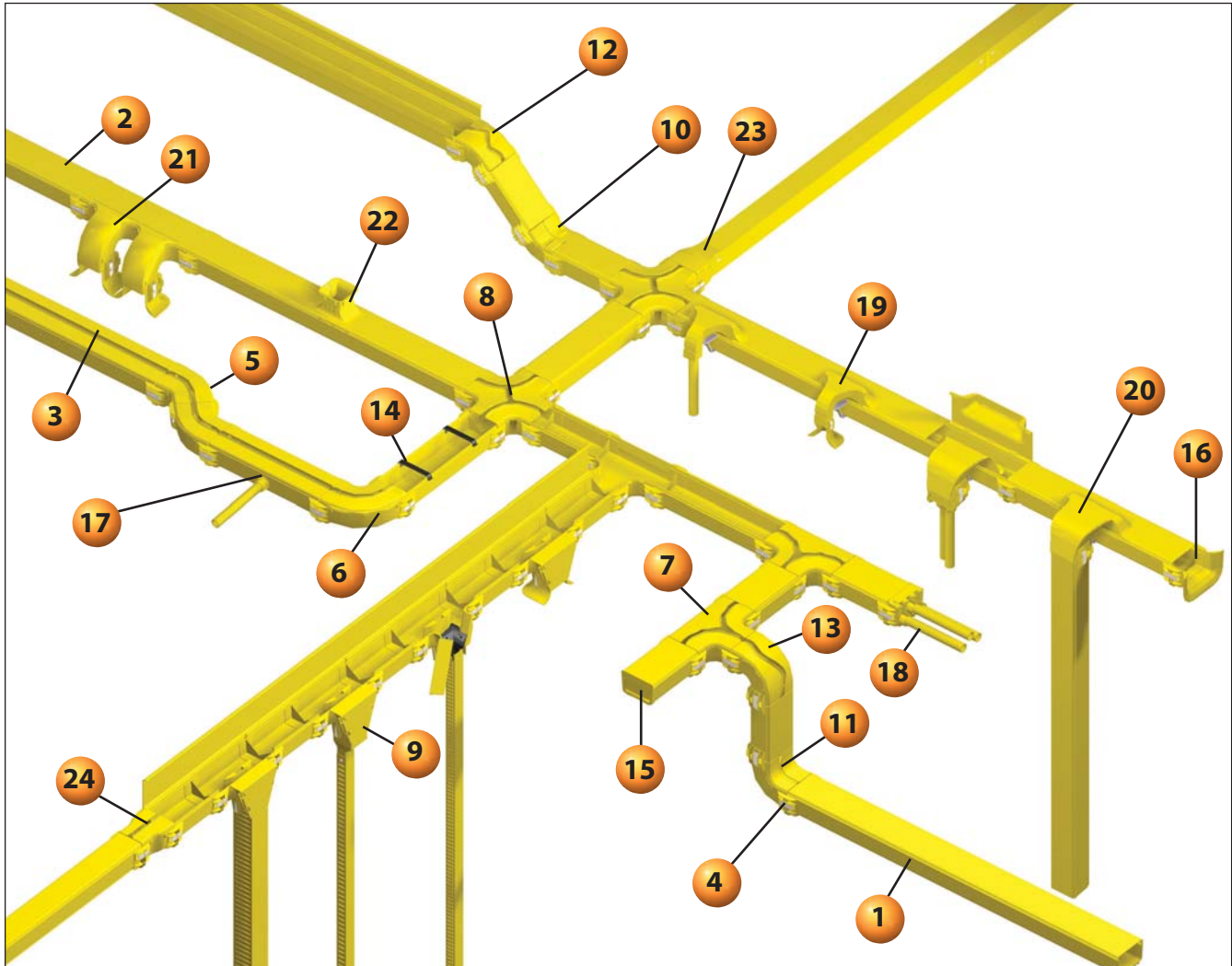


4x4 and 6x4 FiberRunner® Mounting Brackets

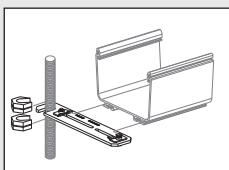


FR6TRBE58 – Existing Threaded Rod QuikLock™ Bracket (page J.33)

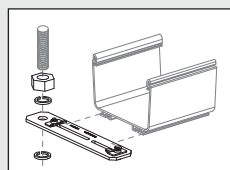


FR6TRBN58 – New Threaded Rod QuikLock™ Bracket (page J.33)

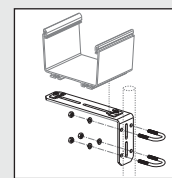


FR6USB – Underfloor Pedestal QuikLock™ Bracket (page J.33)

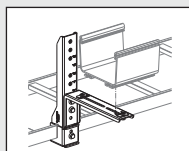


FR6ALB – Adjustable Ladder QuikLock™ Bracket (page J.33)

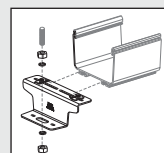


FR6CS58 – Center Support QuikLock™ Bracket (page J.33)

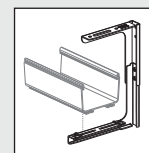

 
FR6ACB58 – Top Support Adjustable “C” QuikLock™ Bracket (page J.34)



 
- 1** FR6X4** – 6x4 FiberRunner[®] Channel (page J.25)



 - 2** FRHC6**6 – 6x4 Snap-On Hinged Cover (page J.25)



 - 3** FRSHC6**6 – 6x4 Split Hinged Cover (page J.25)




- 4** FRBC6X4** – 6x4 QuikLock[™] Coupler (page J.26)




- 5** FRH456X4** – 6x4 Horizontal 45° Angle Fitting and FRH45SC6** – Optional Split Cover (page J.26)



 
- 6** FRRA6X4** – 6x4 Horizontal Right Angle Fitting and FRRASC6** – Optional Split Cover (page J.26)



 - 7** FRT6X4** – 6x4 Horizontal Tee Fitting and FRTSC6** – Optional Split Cover (page J.26)



 - 8** FRFWC6X4** – 6x4 4-Way Cross Fitting and FRFWCSC6** – Optional Split Cover (page J.27)




- 9** FRVT6X4** – 6x4 QuikLock[™] Vertical Tee (page J.29)




- 10** FRIV456X4** – 6x4 Inside Vertical 45° Angle Fitting (page J.27)



 - 11** FRIVRA6X4** – 6x4 Inside Vertical 90° Angle Fitting (page J.27)



 - 12** FROV456X4** – 6x4 Outside Vertical 45° Angle Fitting and FROV45SC6** – Optional Split Cover (page J.27)



- 13** FROVRA6X4** – 6x4 Outside Vertical Right Angle Fitting and FROVRASC6** – Optional Split Cover (page J.28)



 
- 14** FRCR6BL-X – Cable Retainer for 6x4 System (page J.25)



- 15** FREC6X4** – 6x4 End Cap Fitting (page J.27)




- 16** FRTR6X4** – 3-Sided BRC Trumpet Spillout for 6x4 Exit (page J.32)




- 17** FR1.5IDE** – 1-Port Spillout Side Exit to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.31)



 
- 18** FRIDT6X4** – 3-Port Spillout to 1.5" (38mm) Inside Diameter Corrugated Tubing (page J.32)



 - 19** FRSPJ2X2** – Spill-Over Junction with 2x2 Exit and FRSPJC26** – Optional Cover for 6x4 System (pages J.29 and J.30)



 - 20** FRSPJ4X4** – Spill-Over Junction with 4x4 Exit and FRSPJC46** – Optional Cover for 6x4 System (page J.30)




- 21** FRDDS6X4** – 6x4 Dual Downspout and FRDDSHC6** – Optional Cover for 6x4 Dual Downspout (page J.31)



- 22** FRUPS6X4** – 6x4 Up Spout (page J.32)



 - 23** FRRF64** – 6x4 FiberRunner[®] Fitting to 4x4 Fiber-Duct[™] Channel Reducer Fitting (page J.28)



- 24** FRRF6FR4** – 6x4 to 4x4 FiberRunner[®] Reducer Fitting and FRRF6FR4SC** – Optional Split Cover (page J.28)

**Available Colors include: YL (Yellow), OR (Orange), and BL (Black).
Note: Additional 6 x 4 and 4 x 4 bracket applications, see page J.38.