


PART NUMBER	FIBER TYPE	JACKET RATING
FX8HP* ¹ NLS* ² N* ³ nnn	50/125 OM3	OFNP
FX8HL* ¹ NLS* ² N* ³ nnn		LSZH
FZ8HP* ¹ NLS* ² N* ³ nnn	50/125 OM4	OFNP
FZ8HL* ¹ NLS* ² N* ³ nnn		LSZH

*¹ - MPO GENDER: 5=FEMALE, 6=MALE
 *² - PERFORMANCE: Q=STANDARD, V=OPTIMIZED
 *³nnn - U.O.M.: M=METERS, F=FEET, nnn=LENGTH

NOTES:

- ALL PURCHASED ITEMS CONFORM TO C2-0834 PANDUIT SPECIFICATION FOR CHEMICAL SUBSTANCES TO BE CONTROLLED IN PRODUCT AND PACKAGING.
- ALSO AVAILABLE WITH BREAKOUT LENGTHS OF 18", 24", 36" AND 39".

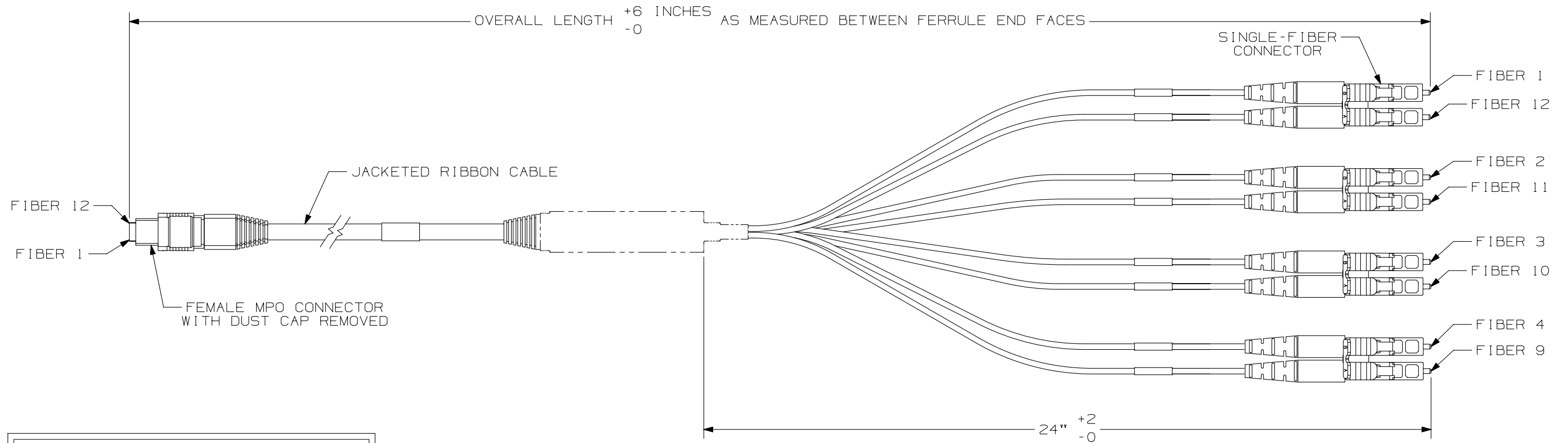

DUST CAPS HAVE BEEN REMOVED FOR CLARITY

TABLE 2
FIBER POLARITY

MPO FIBER POSITION	FIBER COLOR	FIBER LABEL
1	BLUE	TX-1
2	ORANGE	TX-2
3	GREEN	TX-3
4	BROWN	TX-4
9	YELLOW	RX-4
10	VIOLET	RX-3
11	ROSE	RX-2
12	AQUA	RX-1

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
2	08-26-13	MC	WMA	SFDO	RELEASED TO PRODUCTION	M02680FQ-DC

PART NUMBER SEE TABLE 1		PRODUCT SPEC/PKG SPEC N/A	
I.T. NUMBER N/A		WORK INSTRUCTION N/A	
TITLE 8-FIBER MPO TO DUPLEX LC CONNECTOR MIGRATION HARNESS CUSTOMER DRAWING			
ITEM REVISION NAME M02680FQ/01		PANDUIT	
DATASET FILE NAME M02680FQ_DS/01A			
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [mm]			
.x ± .1 [2.54]		.xxx ± .005 [.127]	
.xx ± .01 [.25]		ANGLES ± 5°	
DRAWN BY SAT		DATE 03-19-13	
CHK WMA		SCALE NONE	
DRAWING NUMBER: M02680FQ-DC		SHT 1 OF 1	
SIZE B			