



### IEEE Universal Beam Grounding Clamp



- Universal, fits on a wide range of standard (angled) and wide flange (parallel) structural steel beams
- Provide a mounting pad suitable for a two-hole compression lug
- Install quickly and easily with standard 1/4" key hex wrench tooling
- UL 467 Listed and CSA 22.2 Certified for grounding and bonding suitable for direct burial in earth or concrete
- Comply with vibration tests per MIL-STD-202G (METHOD 201A)
- For the complete line of StructuredGround™ Direct Burial Compression Grounding System, visit [www.panduit.com](http://www.panduit.com)

Part Number	Copper Conductor Size Range AWG	Flange Thickness In.	Stud Size In.	Hole Spacing In.	Thread Size	Figure Dimensions In.			Std. Pkg. Qty.
						L	W	H	
GUBC500-6	#6 – 500	0.250 – 0.675	1/2	1.75	1/2 – 13	3.15	2.13	2.50	1



### Auxiliary Cable Brackets and Jumpers

- Bonds ladder rack, wire basket and Panduit® Wyr-Grid® System sections together without drilling holes
- Supports grounding conductors in the telecommunications room, allows separation of grounding conductors from other cables
- Holds up to four conductors in sizes up to 750 kcmil
- Bonds to all 1" and 2" ladder rack rails
- Paint piercing teeth provide electrical continuity between cable pathway sections while minimizing debris
- Front and back mounting screw options allow easy installation and visual inspection
- GACB-2 and GACB-3 can be mounted above or below the cable pathway system for flexibility
- Brackets Meet TIA-607-B




GACB





GACB-2



GACB-3

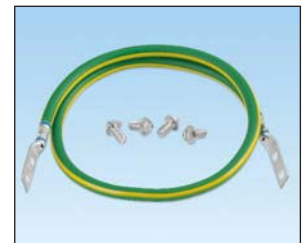

GACBJ618U

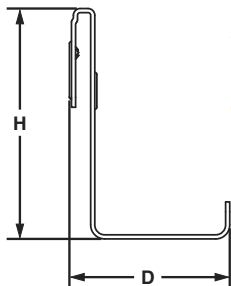 

Part Number	Part Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Auxiliary Cable Brackets</b>			
GACB-1	Auxiliary cable bracket; 1.25" (31.8mm) width; 7.00" (177.8mm) height; 4.87" (123.7mm) depth; provided with one mounting screw.	1	10
GACB-2	Auxiliary cable bracket; 1.63" (41.4mm) width, 3.95" (100.3mm) height, 5.22" (132.6mm) depth; provided with one mounting screw.	1	10
GACB-3	Auxiliary cable bracket; 1.88" (47.6mm) width, 4.58" (116.3mm) height, 5.29" (134.4mm) depth; provided with one mounting screw.	1	10
<b>Bonding Jumper Kits</b>			
GACBJ68U	Auxiliary cable bracket jumper for bonding pathway sections; #6 AWG (16mm <sup>2</sup> ); 8.0" (203mm) length; factory terminated on both ends with straight, two-hole, long barrel compression lugs; provided with .16 oz. (5cc) of antioxidant and four mounting screws.	1	—
GACBJ612U	Auxiliary cable bracket jumper for bonding pathway sections; #6 AWG (16mm <sup>2</sup> ); 12.0" (305mm) length; factory terminated on both ends with straight, two-hole, long barrel compression lugs; provided with .16 oz. (5cc) of antioxidant and four mounting screws.	1	—
GACBJ618U	Auxiliary cable bracket jumper for bonding pathway sections; #6 AWG (16mm <sup>2</sup> ); 18.0" (457mm) length; factory terminated on both ends with straight, two-hole, long barrel compression lugs; provided with .16 oz. (5cc) of antioxidant and four mounting screws.	1	—