


## Component Labels for GP6™ PLUS Category 6 Standard Density Bases and GP6™ PLUS Standard Density Tower Kit

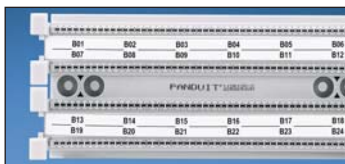

### Suggested Label Solutions for TIA/EIA-606-A Compliance

Punchdown System Part Number	Laser/Ink Jet Desktop Printer Label	TDP43ME Thermal Transfer Desktop Printer Label	PanTher™ LS8E Hand-Held Printer Label	Cougar™ LS9 Hand-Held Printer Label
All GP Kits on pages C1.33 – C1.36	C788X050Y1J	C788X050Y1T	C788X050Y1C	T100X000VPC-BK‡

For complete labeling solutions and product information, reference charts on pages O.1 – O.22.

‡For non-adhesive labeling solution, do not remove liner from label.

## UL LISTED SF CERTIFIED GP6™ PLUS Patch Connectors

- Patch into GP6™ PLUS Connecting Blocks
- Field terminable
- Cable clamp on cover facilitates easier wiring
- IDCs provide reliable, gas-tight connections
- Strain relief reduces stress on cable
- Contain two-piece, snap-together housing
- Polarized to prevent reverse installation to connector block
- Clear polycarbonate cover keeps conductors visible after termination
- Cover also provides proper wiring sequence



GPC5E1-XY



GPC5E2-XY

Part Number	Part Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>GPC5E1-XY</b>	Terminates 1-pair 24 AWL solid or stranded cable.	10	100
<b>GPC5E2-XY</b>	Terminates 2-pair 24 AWL solid or stranded cable.	10	100

To ensure optimal performance, Panduit recommends use with other Panduit Category 6 components.