


cUL[®] US C E Panduct[®] Type HS Hinged Cover Solid Wall Raceway

Specifications

- Base and covers sold separately
- Material: Lead-free PVC
- Rated for continuous use temperature: 122°F (50°C)
- UL94 flammability rating V-0
- Conforms with NFPA 79-2007 section 13.3.1 requirement for flame retardant material
- Base and cover length is 6 feet

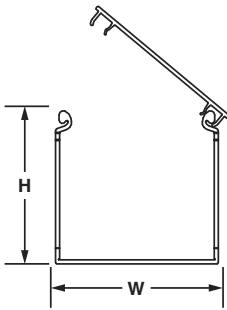

Base Part Number	Duct Size (W x H)		Cover Part Number	Std. Pkg. Qty. (Ft.)	Base Ctn. Qty. (Ft.)	Cover Ctn. Qty. (Ft.)
	In.	mm				
HS1.5X2LG6NM	1.75 x 1.98	44.5 x 50.3	HC1.5LG6	6	120	120
HS1.5X3LG6NM	1.75 x 3.06	44.5 x 77.7	HC1.5LG6	6	60	120
HS2X2LG6NM	2.17 x 1.98	55.1 x 50.3	HC2LG6	6	120	120
HS2X3LG6NM	2.17 x 3.06	55.1 x 77.7	HC2LG6	6	60	120
HS2X4LG6NM	2.17 x 4.10	55.1 x 104.1	HC2LG6	6	60	120
HS3X3LG6NM	3.25 x 3.06	82.6 x 77.7	HC3LG6	6	60	120
HS3X4LG6NM	3.25 x 4.10	82.6 x 104.1	HC3LG6	6	60	120
HS4X4LG6NM	4.25 x 4.10	108.0 x 104.1	HC4LG6	6	60	60

Part numbers shown available in LG (Light Gray) and WH (White). 2 x 2 and 4 x 4 sizes available in BL (Black) colors.
 Base and cover sold separately.
 Height dimension includes duct with cover.
 Order number of feet required, in multiples of 6' or Standard Carton Quantity.

A.
System
Overview

B.
Copper
Systems

C.
Fiber
Optic
Systems

D.
Power
over
Ethernet

E.
Zone
Cabling

F.
Wireless

G.
Outlets

H.
Media
Distribution

I.
Physical
Infrastructure
Management

J.
Overhead &
Underfloor
Routing

K.
Surface
Raceway

L.
Cabinets,
Racks &
Cable
Management

M.
Grounding &
Bonding

N.
Industrial

O.
Labeling &
Identification

P.
Cable
Management
Accessories

Q.
Index