
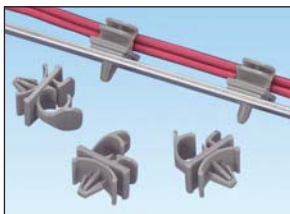


Latching Wire Clips

- Route and secure cords and cables
- Convenient releasable latch
- Available in six sizes with releasable latch
- Push barb parts are for use with a max panel thickness of .11" (2.7mm) and a hole diameter of .22" (5.6mm)
- For indoor use only
- Material: Nylon 6.6

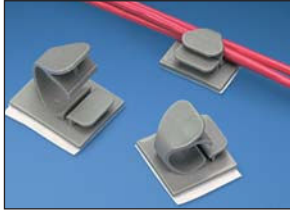

Part Number	Max. Bundle Diameter		Length		Width		Color	Std. Pkg. Qty.	Std. Ctn. Qty.
	In.	mm	In.	mm	In.	mm			
Adhesive Backed									
LWC19-A-C	.19	4.8	.85	21.6	.61	15.5	Natural	100	1000
LWC19-A-C14							Gray	100	1000
LWC19-A-C20							Black	100	1000
LWC25-A-C	.25	6.4	.88	22.4	1.00	25.4	Natural	100	1000
LWC25-A-C14							Gray	100	1000
LWC25-A-C20							Black	100	1000
LWC38-A-C	.38	9.5	1.00	25.4	1.00	25.4	Natural	100	1000
LWC38-A-C14							Gray	100	1000
LWC38-A-C20							Black	100	1000
LWC50-A-L	.50	12.7	1.26	32.0	1.00	25.4	Natural	50	500
LWC50-A-L14							Gray	50	500
LWC50-A-L20							Black	50	500
LWC75-A-L	.75	19.1	1.48	37.6	1.24	31.5	Natural	50	500
LWC75-A-L14							Gray	50	500
LWC75-A-L20							Black	50	500
LWC100-A-L	1.00	25.4	2.21	56.1	1.97	50.0	Natural	50	500
LWC100-A-L14							Gray	50	500
LWC100-A-L20							Black	50	500
Push Mount									
LWC19-H25-C	.19	4.8	.85	21.6	.51	12.8	Natural	100	1000
LWC19-H25-C14							Gray	100	1000
LWC25-H25-C	.25	6.4	.86	21.8	.58	14.7	Natural	100	1000
LWC25-H25-C14							Gray	100	1000
LWC25-H25-C20	.25	6.4	.86	21.8	.58	14.7	Black	100	1000
LWC38-H25-C							Natural	100	1000
LWC38-H25-C14	.38	9.5	.94	23.9	.58	14.7	Gray	100	1000
LWC50-H25-L							Natural	50	500
LWC50-H25-L14	.50	12.7	1.25	31.8	.76	19.3	Gray	50	500
LWC50-H25-L20							Black	50	500
LWC75-H25-L	.75	19.1	1.45	36.8	.87	22.1	Natural	50	500
LWC75-H25-L14							Gray	50	500
LWC75-H25-L20							Black	50	500
LWC100-H25-L	1.00	25.4	1.89	47.9	.99	25.2	Natural	50	500
LWC100-H25-L14							Gray	50	500
LWC100-H25-L20							Black	50	500