



PANDUIT P/N	WEIGHT
P24B29M	9.6kg

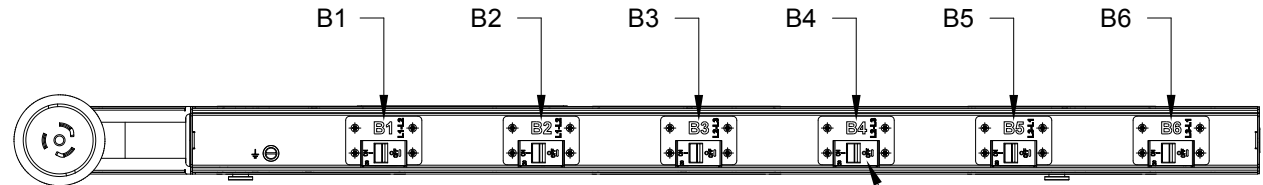


REAR VIEW


20 AMP, DOUBLE - POLE
ELECTRO MECHANICAL
SWITCH / BREAKER (6) PLACES

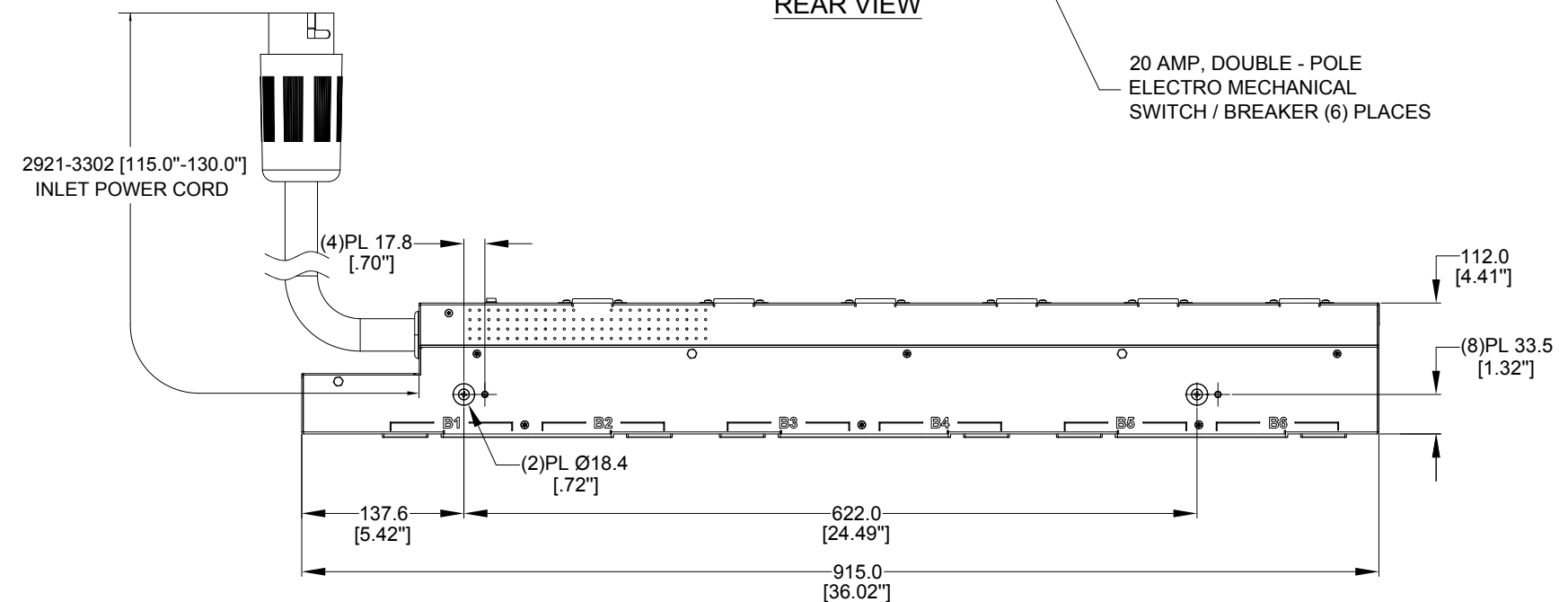

TOP VIEW

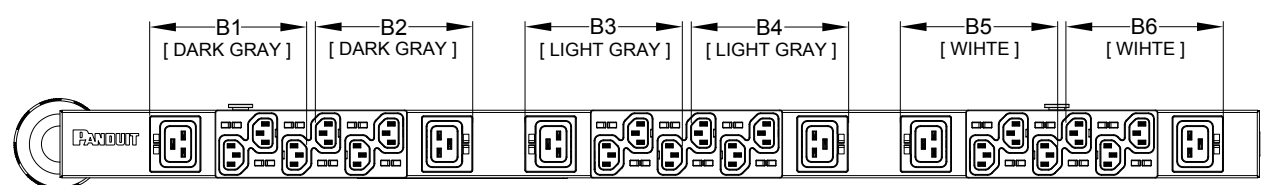


FRONT VIEW

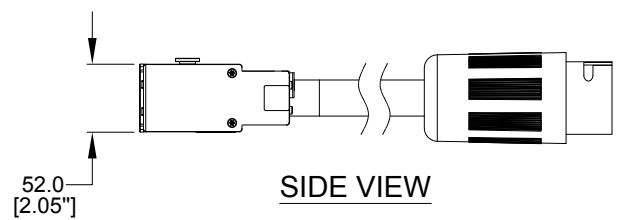


SIDE VIEW

NOTES:


- IDENTIFICATION:
 - UNIT TYPE: BASIC
 - ORIENTATION: VERTICAL, 0U HALF, 2-SIDED
 - OUTLET QTY&TYPE: (18) C13, (6) C19
 - BREAKER QTY&TYPE: (6) 20AMP, DOUBLE-POLE
 - INPUT VOLTAGE: 200-240VAC, DELTA
 - INPUT CURRENT: 50A (40A DERATED)
 - INPUT PHASE: THREE-PHASE DELTA
 - RATED POWER: 14.4kVA
 - INPUT PLUG: HUBBELL CS8365C
 - INPUT CORD LENGTH: 3m [10']
- ACCESSORIES:
 - POCKET GUIDE
- RoHS COMPLIANT
- VISIT PANDUIT'S ON-LINE CATALOG AT WWW.PANDUIT.COM FOR ADDITIONAL PRODUCT INFORMATION CONTAINED IN THE SPECIFICATION SHEET AS WELL AS A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
- MAXIMUM ALLOWABLE INPUT POWER = 14.4kW
- INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES

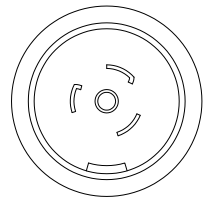

PLUG
50 AMP, 250V x 3~ DELTA
TWIST LOCK
NEMA CS-8365C

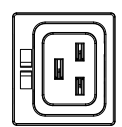

**SIX (6)
RECEPTACLES**
16 AMP, 250V
STRAIGHT BLADE
IEC 60320/C19

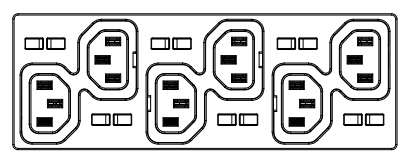

**EIGHTEEN (18)
RECEPTACLES**
10 AMP, 250V
STRAIGHT BLADE
IEC 60320/C13

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
01B	08/21/2017	KUN	MIM	EDM	REVISED TOLERANCES	P24B29M
01A	06/28/2017	KUN	MIM	EDM	INITIAL RELEASE	P24B29M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY		SIGN
		DATE
		PRINT
TITLE: BASIC SERIES PDU P24B29M CUSTOMER DRAWING		
ITEM REVISION NAME:		PANDUIT
DATASHEET FILE NAME:		
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN]		MATERIAL/COLOR: N/A
Tolerance(mm) 04<L<50 ±0.5 50<L<250 ±1.0 250<L<500 ±1.5 500<L<1000 ±2.5 1000<L<2000 ±4.0		DRAWING NUMBER: P24B29M_DC
THIRD ANGLE PROJECTION	DRAWN BY: KUN DATE: 05/24/2017 CHK: SEAN SCALE: NONE	SHT 1 OF 1 SCALE: B