



PANDUIT P/N	WEIGHT
P48B33M	12.3kg

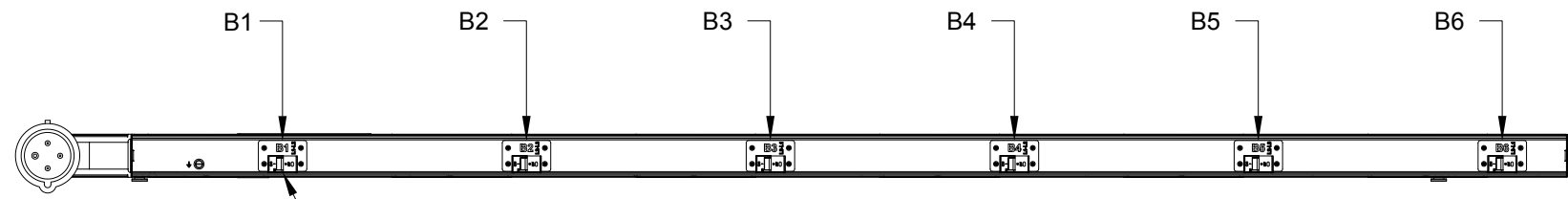


REAR VIEW

20 AMP, DOUBLE - POLE
ELECTRO MECHANICAL
SWITCH / BREAKER (6) PLACES

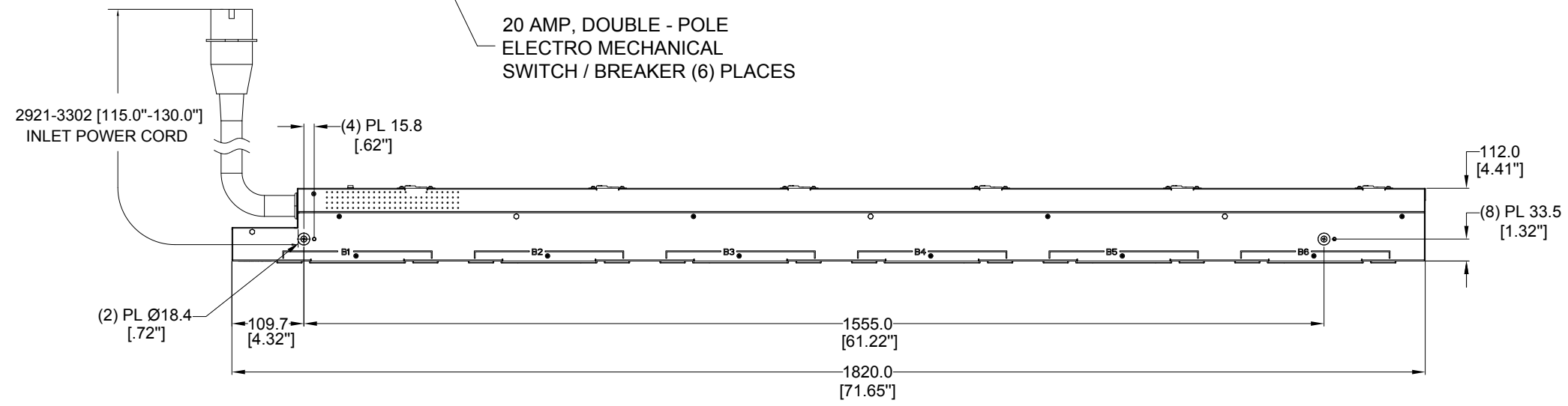


TOP VIEW

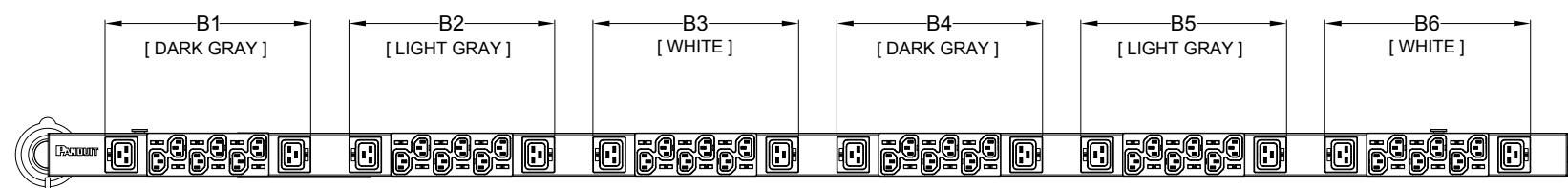

FRONT VIEW

NOTES:

 - IDENTIFICATION:
 - UNIT TYPE: BASIC
 - ORIENTATION: VERTICAL, 0U FULL, 2-SIDED
 - OUTLET QTY&TYPE: (36) C13 AND (12) C19
 - BREAKER QTY&TYPE: (6) 20AMP, DOUBLE-POLE
 - INPUT VOLTAGE: 200-240VAC, DELTA
 - INPUT CURRENT: 60A (48A DERATED)
 - INPUT PHASE: THREE-PHASE DELTA
 - RATED POWER: 17.3kVA
 - INPUT PLUG: IEC 60309 3P+E 9H 60A
 - INPUT CORD LENGTH: 3m [10']
- ACCESSORIES:
 - POCKET GUIDE
- RoHS COMPLIANT
- VISIT PANDUIT'S ON-LINE CATALOG AT WWW.PANDUIT.COM FOR ADDITIONAL PRODUCT INFORMATION CONTAINED IN THE SPECIFICATION SHEET AS WELL AS A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
- MAXIMUM ALLOWABLE INPUT POWER = 17.3kW
- INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES



SIDE VIEW

PLUG
60 AMP, 250V x 3~ DELTA
3P/4W
IEC 60309, SPLASHPROOF, IP44
2G (S); 2W (W), 9H;

TWELVE (12) RECEPTACLES
16 AMP, 250V
STRAIGHT BLADE
IEC 60320/C19

THIRTY-SIX (36) RECEPTACLES
10 AMP, 250V
STRAIGHT BLADE
IEC 60320/C13

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
01B	08/21/2017	KUN	MIM	EDM	REVISED TOLERANCES	P48B33M
01A	06/28/2017	KUN	MIM	EDM	INITIAL RELEASE	P48B33M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY		SIGN
		DATE
		PRINT
TITLE: BASIC SERIES PDU P48B33M CUSTOMER DRAWING		
ITEM REVISION NAME:		PANDUIT
DATASHEET FILE NAME:		
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN]		MATERIAL/COLOR: N/A
Tolerance(mm) 04<L<50 ±0.5 50<L<250 ±1.0 250<L<500 ±1.5 500<L<1000 ±2.5 1000<L<2000 ±4.0		DRAWING NUMBER: P48B33M_DC
THIRD ANGLE PROJECTION	DRAWN BY: KUN	SCALE: NONE
	DATE: 05/24/2017	CHK: SEAN
		SHT 1 OF 1
		SCALE: B