



(1)

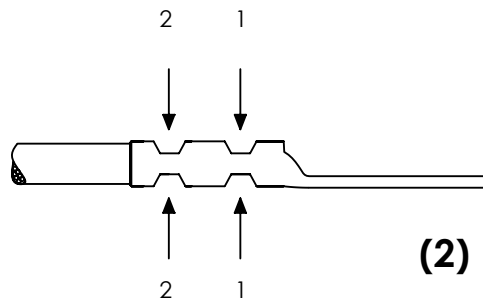

(2)

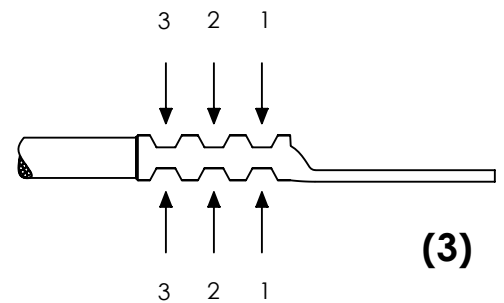

(3)

**Tool Chart for Compression Connectors Type S-R with Copper Cable**

			PANDUIT Tool Part Number				
			Color & Die Index Number (Crimps Per Wire)				
Panduit Part Number	Standard Wire Size	L Wire Strip Length (in.)	CT-700 CT-1700	CT-720	CT-930, CT-930CH CT-930LPCH, CT-920, CT-920CH CT-2920, CT-940CH* CT-2940*, CT-2930 CT-2931	CT-980 CT-980CH CT-980LPCH CT-2950 CT-2980 CT-2981	CT-2001 CT-2002 CT-3001 CT-3001/E
S8-R	#8 AWG	7/16	CD-700-8-2 RED P21 (2)	CD-720-1 RED P21 (1)	CD-920-8 RED P21 (1)	---	CD-2001-8 RED P21 (1)
S6-R	#6 AWG	1/2	CD-700-8-2 BLUE P24 (2)	CD-720-1 BLUE P24 (1)	CD-920-6 BLUE P24 (1)	---	CD-2001-6 BLUE P24 (1)
S4-R	#4 AWG	1/2	CD-700-8-2 GREY P29 (2)	CD-720-1 GREY P29 (1)	CD-920-4 GREY P29 (1)	STD (1)	CD-2001-4 GREY P29 (1)
S2-R	#2 & #1 AWG	5/8	CD-700-1-1/0 GREEN P37 (3)	CD-720-2 GREEN P37 (1)	CD-920-1 GREEN P37 (1)	STD (1)	CD-2001-1 GREEN P37 (1)
S1/0-R	1/0 AWG	5/8	CD-700-1-1/0 PINK P42 (3)	CD-720-2 PINK P42 (1)	CD-920-1/0 PINK P42 (1)	STD (1)	CD-2001-1/0 PINK P42 (1)
S2/0-R	2/0 AWG	11/16	---	CD-720-2 BLACK P45 (2)	CD-920-2/0 BLACK P45 (1)	STD (1)	CD-2001-2/0 BLACK P45 (2)
S3/0-R	3/0 AWG	7/8	---	CD-720-2 ORANGE P50 (2)	CD-920-3/0 ORANGE P50 (1)	STD (1)	CD-2001-3/0 ORANGE P50 (2)
S4/0-R	4/0 AWG	15/16	---	CD-720-3 PURPLE P54 (2)	CD-920-4/0 PURPLE P54 (1)	STD (1)	CD-2001-4/0 PURPLE P54 (2)
S250-R	250 kcmil	1-1/16	---	CD-720-2 YELLOW P62 (2)	CD-920-250 YELLOW P62 (1)	STD (1)	CD-2001-250 YELLOW P62 (2)

\* CD-920 dies can be used with CT-940CH and CT-2940 tools with CD-940 DA Die adapter.



For Instructions in Local Languages  
and Technical Support:



E-mail:  
cs@panduit.com

www.panduit.com/resources/install\_maintain.asp

www.panduit.com

Fax:  
708-444-6993