
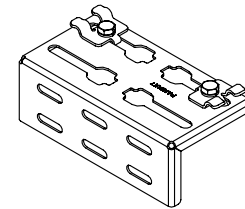
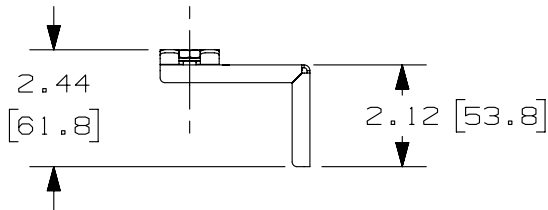
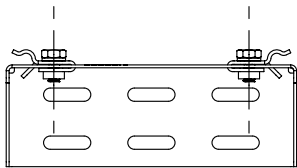


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

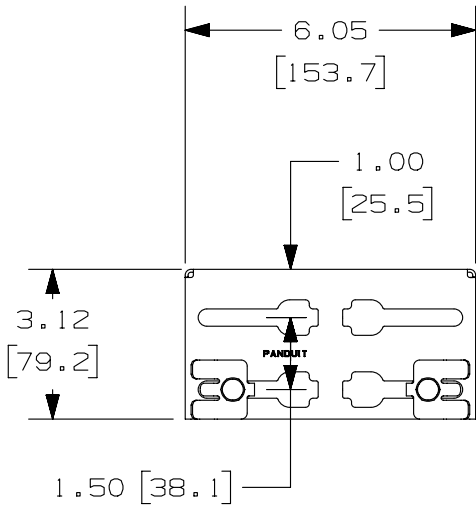

PANDUIT PART NUMBER	WEIGHT
WGWMTB8	.57 LBS (259 g)

NOTES 1

- SEE CURRENT CATALOG FOR PART NUMBER DESIGNATION FOR TYPE AND COLOR.
- WYR-GRID WALL MOUNT BRACKET MOUNTS TO A VERTICAL SURFACE, SUCH AS A WALL, TO SUPPORT WYR-GRID PATHWAY.
- EACH PACKAGE CONSISTS OF:
 - (1) WYR-GRID WALL MOUNT BRACKET
 - (2) WYR-GRID QUICK LOCK CLIP
 - (2) 1/4-20x1/2 HEX HEAD CAP SCREW
 - (2) 1/4 HELICAL SPRING LOCKWASHER
- DIMENSIONS IN PARENTHESES ARE METRIC.

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
R	12-05-13	SSP	DWW	RN	RELEASED TO PRODUCTION	09D017IR-DC

TITLE		WYR-GRID 8" WALL MOUNT TERMINATION BRACKET (WGWMTB8)	
		CUSTOMER DRAWING	
ITEM REVISION NAME		09D017IR/00	
DATASET FILE NAME		09D017IR_DC/00A WGWMTB8	
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN (mm)		PANDUIT	
.X ± .XX ± .05 [1.3] .XXX ± ANGLES ± 5 °			
DRAWN BY: SSP		DATE: 12-05-13	
CHK: DWW		SCALE: NONE	
MATERIAL: STEEL		DRAWING NUMBER: 09D017IR-DC	
THIRD ANGLE PROJECTION		SHT 1 OF 1	
SIZE: A			

D10100DA/16