

Multi-Purpose Zone Enclosures

The Multi-Purpose Zone Enclosure solution provides a versatile, inclusive, and cost-effective structured cabling option suitable for both commercial and residential deployments.

Multi-Purpose In-Ceiling Enclosure



MSICE24

- Open mounting pattern allows placement of equipment across the entire base of the enclosure using a 1 in. grid pattern for customizable mounting options, greater flexibility, and maximum use of available space
- Hinged lockable door protects against physical damage, vandalism, and tampering
- Simple deployment of cable knockout openings and gland plate allow cables to easily enter and exit the enclosure providing easier cable routing, quicker installation, and increased density
- Equipment mounting plate is removable, allowing the user to install the accessories/equipment before mounting the enclosure in the ceiling
- Power knockouts provisions included to mount one 2-gang outlet box to bring power to the box facilitating the ability to connect active devices in the enclosure
- Enclosure comes fully assembled with base and hinged door, and is comprised of 18 gauge steel
- Grounding kit properly bond the door to the base to protect network equipment and maximize uptime (sold separate)

Part Number	Description
MSICE24	2' x 2' In-Ceiling Enclosure with Hinged Door

Multi-Purpose Wall Mountable Enclosure



MS28EHDS

- Open mounting pattern allows placement of equipment across the entire base of the enclosure using a 1 in. grid pattern for customizable mounting options, greater flexibility, and maximum use of available space
- Reversible hinge door allows door to be installed on the left or right providing flexibility for placement of enclosure installation
- Cable knockout openings and gland plate cables to easily enter and exit the enclosure providing easier cable routing, quicker installation, and increased density
- Power knockouts provisions included to mount one 2-gang outlet box to bring power to the box facilitating the ability to connect active devices in the enclosure
- Enclosure comes fully assembled with the following components the base, hinged locking door, and mud guard, and is comprised of 18 gauge steel
- Grounding kit properly bonds the door to the base to protect network equipment and maximize uptime (sold separately)


MS14EHDS	14" Wall Mountable Enclosure with Hinged Reversible Door
MS28EHDS	28" Wall Mountable Enclosure with Hinged Reversible Door
MS42EHDS	42" Wall Mountable Enclosure with Hinged Reversible Door

Accessories

Opticom® PON SC-APC Splitter Cassettes

FC29N-04-3G1X04	1X4 Splitter Cassette
FC29N-04-3G2X04	2X4 Splitter Cassette
FC29N-08-3G1X08	1X8 Splitter Cassette
FC29N-08-3G2X08	2X8 Splitter Cassette

Multi-Purpose Enclosure Accessories

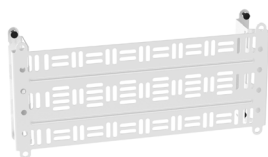

MSSHLF



MSBRKT

MSSHLF	Device Shelf for use with Multi-Purpose Enclosures
MSBRKT	Strap Bracket Kit for use with Multi-Purpose Enclosures
MS8PPB	8-Port Patch Panel for use with Multi-Purpose Enclosures
MSFCB2	Multi-Purpose Enclosure Opticom Fiber Cassette Adapter Bracket for 2 Cassettes
MSGK	Grounding Jumper Kit for use with Multi-Purpose Enclosures
MSICECB	Cool Boot for use with Multi-Purpose In-Ceiling Enclosure
FMS1	Fiber Slack Spool



MS8PPB



MSFCB2



MSICECB

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com
Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

PANDUIT®

© 2023 Panduit Corp.
ALL RIGHTS RESERVED.
RKSG9-SA-ENG
11/2023