

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT P/N	WEIGHT
P24D33M-XXYZ	SEE SHEET 2

**SPECIFICATION:**

**1. STANDARD:**

UNIT TYPE:	MONITORED INPUT
ORIENTATION:	VERTICAL, 0U HALF, 2-SIDED
OUTLET QTY&TYPE:	(18) C13, (6) C19
INPUT VOLTAGE:	200-240VAC
INPUT CURRENT:	60A (48A DERATED)
BREAKER QTY&TYPE:	(6) 20AMP, DOUBLE-POLE
INPUT PHASE:	THREE-PHASE, DELTA
RATED POWER:	17.3kVA
INPUT PLUG:	IEC 60309 3P+E 9H 60A
INPUT POWER CORD:	SEE SHEET 2 FOR PART NUMBER TABLE
REGULATORY STANDARD:	RoHS COMPLIANT

**2. ADDITIONAL:**

NONE

**3. ACCESSORIES:**

(1) QUICK-START GUIDE


**NOTES:**

1. PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSION ARE IN [ INCHES ]
2. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES
3. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
4. FOR FULL PRODUCT FUNCTIONALITY REFER TO USER MANUAL
5. DRAWING VIEWS SHOW THE INPUT CORD IN THE "TOP END FED" CONFIGURATION


**IDENTIFICATION**

FOR FINISHED GOOD PART NUMBER & DESCRIPTION TABLE SEE SHEET 2 CONFIGURABLE PART NUMBERS: P24D33M-XX Y Z


XX: FINISHED GOOD COLOR BL=BLACK YL=YELLOW RD=RED BU=BLUE WH=WHITE GN=GREEN	Y: INPUT FEED TYPE 1=TOP-END FED 2=BOTTOM-END FED	Z: INPUT CORD LENGTH A=1 METER B=2 METER C=3 METER
--	---	---

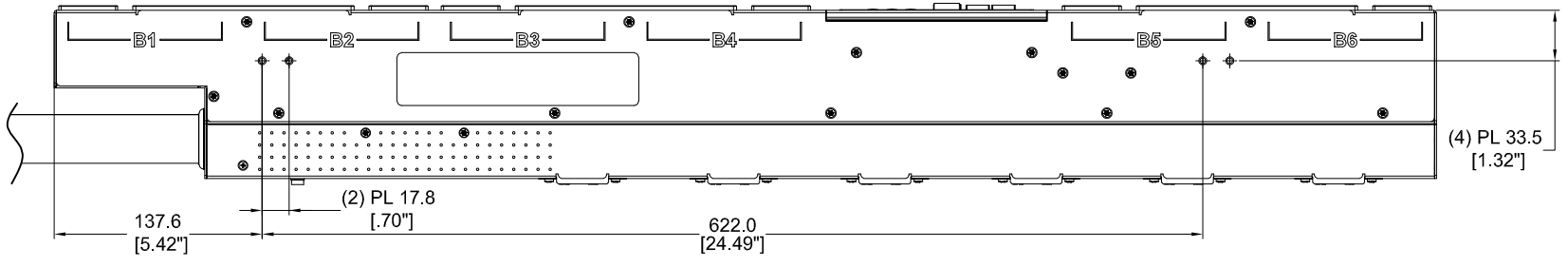

LEFT VIEW

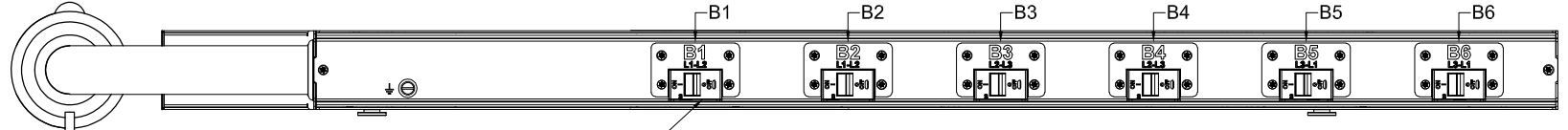


REAR VIEW

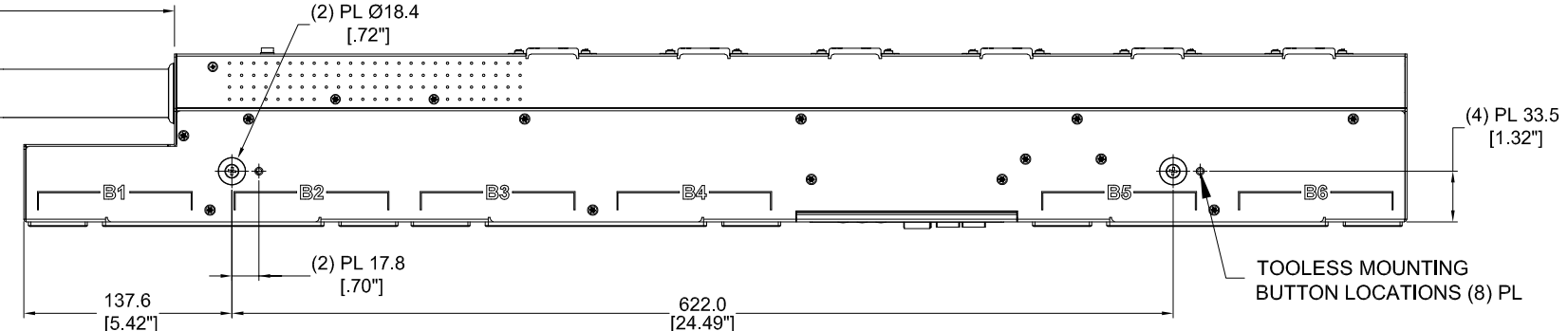


RIGHT VIEW

FOR LENGTH SEE SHEET 2 PART NUMBER TABLE.

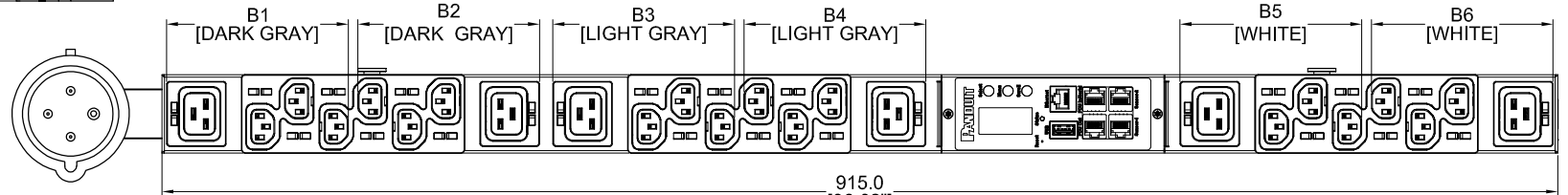


FRONT VIEW

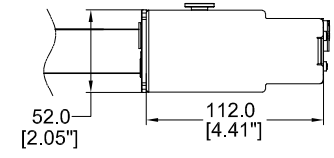


BOTTOM VIEW


**PLUG/RECEPTACLE BLOCK**



 PLUG  
IEC 60309, 3P 4W, 9H  
IP44 (SPLASHPROOF)  
60A, 250V, 3-PHASE MAX RATED INPUT  
48A DERATED



RECEPTACLES  
IEC 60320/C19  
16A, 250V MAX RATED OUTPUT



RECEPTACLES  
IEC 60320/C13  
10A, 250V MAX RATED OUTPUT

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION DE-CODER UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24D33M
01A	09/22/2017	GEORGE	MIM	EDM	INITIAL RELEASE	P24D33M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY

SIGN \_\_\_\_\_  
DATE \_\_\_\_\_  
PRINT \_\_\_\_\_

TITLE: INTELLIGENT SERIES PDU  
P24D33M-XXYZ  
CUSTOMER DRAWING

ITEM REVISION NAME: \_\_\_\_\_  
DATASHEET FILE NAME: \_\_\_\_\_

UNLESS OTHERWISE SPECIFIED  
DIMENSIONAL TOLERANCE ARE: mm [IN]

Tolerance(mm)  
0-1.50 ±0.5  
1.50-2.50 ±1.0  
2.50-5.00 ±1.5  
5.00-10.00 ±2.5  
10.00-20.00 ±4.0

THIRD ANGLE PROJECTION

MATERIAL/COLOR: N/A

DRAWING NUMBER: P24D33M\_DC

DRAWN BY: GEORGE DATE: 09/22/2017 CHK: SEAN SCALE: NONE

SHT 1 OF 2 SCALE: B

2



1

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

FINISHED GOOD PART NUMBER	FINISHED GOOD DESCRIPTION	COLOR	INPUT CORD LENGTH	WEIGHT
P24D33M	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-BL1A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-BL1B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-RD1A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-RD1B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-RD1C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-WH1A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-WH1B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-WH1C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-YL1A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-YL1B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-YL1C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-BU1A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-BU1B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-BU1C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-GN1A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-GN1B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-GN1C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-BL2A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-BL2B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-BL2C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-RD2A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-RD2B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-RD2C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-WH2A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-WH2B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-WH2C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-YL2A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-YL2B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-YL2C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-BU2A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-BU2B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-BU2C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg
P24D33M-GN2A	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3'[+3.5"-1.75"]	10.2kg
P24D33M-GN2B	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5'[+7"-3.5"]	11.5kg
P24D33M-GN2C	VERTICAL,(18) C13,(6) C19,MONITORED INPUT, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10'[+10"-5"]	12.8kg

B

B

A

A

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY		SIGN
		DATE
		PRINT
TITLE INTELLIGENT SERIES PDU P24D33M-XXYZ CUSTOMER DRAWING		
ITEM REVISION NAME		
DATASHEET FILE NAME:		
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN]		MATERIAL/COLOR: N/A
 THIRD ANGLE PROJECTION		DRAWING NUMBER: P24D33M_DC
DRAWN BY GEORGE	DATE 09/22/2017	CHK SEAN
SCALE NONE		SHT 2 OF 2
		SCALE B

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION DE-CODER UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24D33M
01A	09/22/2017	GEORGE	MIM	EDM	INITIAL RELEASE	P24D33M

2



1