



DETAIL A  
SCALE 1:2

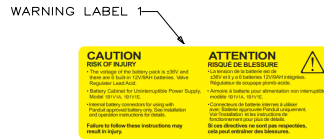

DETAIL B  
SCALE 1:2

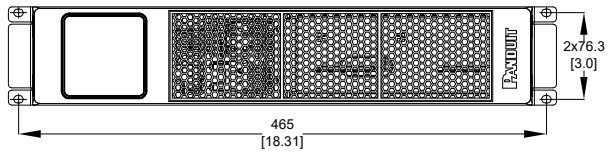

1. STANDARD:

- USE WITH UPS CAPACITY: 1 KVA
- BATTERY TYPE: VALVE REGULATED LEAD ACID-NON SPILLABLE
- NOMINAL INPUT/OUTPUT VOLTAGE: 36VDC
- BREAKER TYPE: 63A/1P
- WEIGHT OF Pb(LEAD): 10.2KG
- WEIGHT OF H2SO4(SULFURIC ACID): 2.4KG

2. ADDITIONAL:

NONE

3. ACCESSORY COMPONENTS:

- STABILIZER BRACKET, QTY:(4)
- INSTALLATION EARS, QTY:(2)
- SAFETY WARNING SHEET,QTY:(1)
- INCLUDES P/N:URMKIT2 INSTALLATION RAIL KIT, QTY:(1)
- REFER TO ASSOCIATED DRAWINGS FOR PHYSICAL DIMENSIONS AND SPECIFICATIONS
- EBP POWER CABLE, QTY:(1)
- INCLUDES P/N:UVDO36 BATTERY CARTRIDGE SET,QTY:(1)

NOTES:

1. PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSIONS ARE IN INCHES
2. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES
3. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
4. ALL PURCHASED ITEMS CONFORM TO C2-0834 PANDUIT SPECIFICATION FOR CHEMICAL SUBSTANCES TO BE CONTROLLED IN PRODUCT AND PACKAGING

IDENTIFICATION:

PART NUMBER	DESCRIPTION	SHIPPING WEIGHT (KG)
UVP036	VRLA EXTERNAL BATTERY PACK (EBP) 2*3PCS 36V (3AH BATTERIES) CHASSIS, BATTERIES, AND RAIL KIT INCLUDED, FOR 1KVA UPS ONLY	29.40

REV	DATE	BY	CHK	DESCRIPTION	ECN	DATE	BY	CHK	DESCRIPTION	ECN
01A	08/17/2022	DL	ZRZ	GLM/DJ8						
00A	08/17/2021	DL	ZRZ	GLM/DJ8						
REV	DATE	BY	CHK	DESCRIPTION	ECN	DATE	BY	CHK	DESCRIPTION	ECN

WE ASK THAT YOU CHECK AGAIN THE SUBSTITUTIONS AND WITH THE CLIENT THE USE AND THE PROPER WEIGHT OF THE BATTERY PACK AS IT MAY AFFECT THE OUTPUT.	
FILE	
EXTERNAL BATTERY PACK UVP036	
CUSTOMER DRAWING	
REV NUMBER AND UVP036-01	UVP036-DC/01A
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE IN (MM)	N/A
THIRD ANGLE PROJECTION	UVP036-DC
DATE	08/17/2022
SCALE	VARIOUS
SHEET	1 OF 2

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

**PANDUIT** NOM LISTED NYCE CE UK CA UL US FC  
 18900 PANDUIT DRIVE, 60487, USA  
 WWW.PANDUIT.COM

BATTERY POWER SYSTEMS  
 MODEL NUMBER: 2B0V0N  
 CAPACITY: 9 Ah  
 BATTERY: 36 V --- 50 A


BATTERY TYPE: VALVE REGULATED LEAD ACID  
 Protective Class: I

PROHIBIDO SU USO EN EXTERIORES

MADE IN CHINA  
 HECHO EN CHINA

P/N: UVP036  
 UPC# 6 111 19 531 6 22 30 14

EXTERNAL BATTERY PACK:  
 UVP036

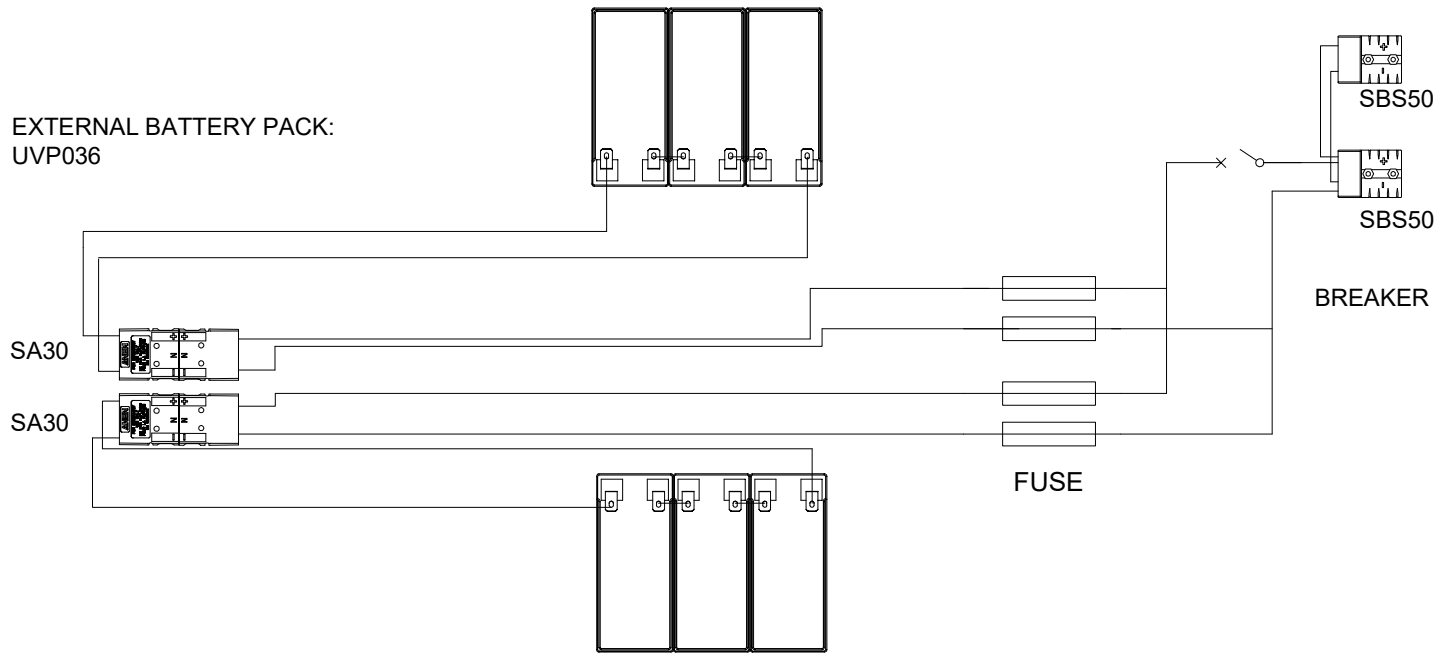

LEGEND

SYMBOL	DESCRIPTION	SYMBOL	DESCRIPTION	SYMBOL	DESCRIPTION
	CIRCUIT BREAKER		AIR-DC CONVERTER		SA 30
	RELAY		DIGITAL INVERTER		MS 50
	DC CIRCUIT BREAKER		BATTERY SYMBOL		FUSE
	DC-DC CONVERTER		DIGITAL INVERTER		BATTERY UNIT

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	DATE	BY	CHK	APR	DESCRIPTION	ECN
01A	08/17/2022	DAL	ZRZ	GLM/DJB	A ADDED NOTE BELOW VIEW B, KIT WAS URMKTTI. UPDATED DESCRIPTION. D, NOTCH REMOVED IN METAL.	UVP036						
00A	08/17/2021	DAL	ZRZ	GLM/DJB	RELEASE TO PRODUCTION	UVP036						

EXTERNAL BATTERY PACK UVP036											
CUSTOMER DRAWING											
REVISED TIME: UVP036/01											
REVISED TIME: UVP036-DC/01A											
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE MM (IN)											
THIRD ANGLE PROJECTION											
UVP036-DC											
SHT 1 OF 2											