

NetKey™ Category 6A UTP Patch Cords – APAC

specifications

Category 6A/Class E_A UTP patch cords are constructed of 26 AWG twisted pair stranded copper cable with a UTP modular plug on each end. Patch cords are offered in off white, blue, and red UTP cable for design flexibility. All patch cords are wired to be compatible with both T568A and T568B wiring schemes.



technical information

Category 6A/Class E_A performance:	Exceeds ANSI/TIA-568.2-D Category 6A and ISO 11801 Class E channel requirements at swept frequencies up to 250 MHz Meets ANSI/TIA-568.2-D and ISO 11801 Category 6 component requirements at swept frequencies up to 500 MHz
Cable diameter:	5.9mm
FCC compliance:	Complies with ANSI/TIA-1096-A (formerly FCC Part 68); contacts plated with 50 microinches of gold
IEC compliance:	Meets IEC 60603-7
PoE compliance:	Supports IEEE 802.3af/802.3at and 802.3bt type 3 and type 4 PoE applications
Safety compliance:	cULus Listed; UL 1863 and CAN/CSA-C22.2 (UL File E129886)
RoHS compliance:	Compliant
Flammability rating:	CM rated

key features and benefits

Performance tested	Confidence that each patch cord delivers specified performance
Slender strain relief boot	Provides easy access in high-density applications
Common colors and lengths available	Meets common length and color coding requirements

applications

Applications include:

- Ethernet 10BASE-T, 100BASE-T (Fast Ethernet), and 1000BASE-T (Gigabit Ethernet)
- 155 Mb/s ATM, 622 Mb/s ATM, 1.2 Gb/s ATM
- Token Ring 4/16
- Voice over Internet Protocol (VoIP)

NetKey™ Category 6A Patch Cords

Meter lengths: NKU6APC^M*

NetKey™ Category 6A Jack Modules

PD style module: NK6X88M**

NetKey™ Patch Panels with Labels

24-port, 1 RU, with 6 NK4MFL: NKFPL24

48-port, 2 RU, with 12 NK4MFL: NKFPL48

NetKey™ Patch Panels without Labels

24-port, 1 RU, with 6 NK4MF: NKFPA24Y

48-port, 2 RU, with 12 NK4MF: NKFPA48Y

NetKey™ Angled Patch Panels without Labels

24-port, 1 RU, with 6 NK4MF: NKFPA24

48-port, 2 RU, with 12 NK4MF: NKFPA48

Strain Relief Bars

Straight: SRBS19BL-XY

Extended 2": SRB19BLY

With hook and loop ties: SRBM19BLY

With adjustable clips: SRBWCY

Deep, 5": SRB19D5BLY

Deep, 7": SRB19D7BLY


Multi-depth: SRB19MDBL

^Denotes length in meters (1-5, 7, 10).

* To designate a color, add suffix BU (Blue), RD (Red), or leave blank for Off White.

**To designate a color, add suffix IW (Off White), WH (White), AW (Arctic White), EI (Electric Ivory), IG (Int'l Gray), BL (Black), OR (Orange), RD (Red), BU (Blue), GR (Green), VL (Violet), or YL (Yellow).

NetKey™ Category 6A UTP Patch Cords – APAC

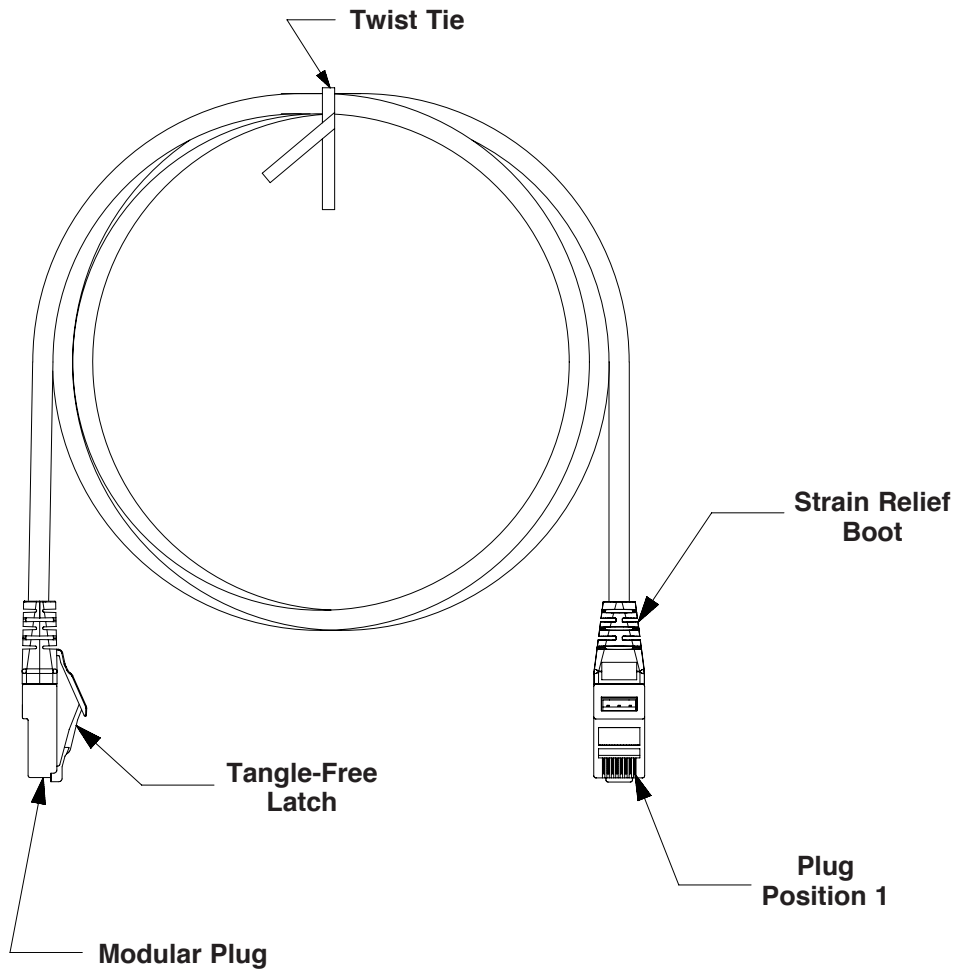

T568B Wiring Scheme	
Plug Position	Cable Wire
1	White/Orange
2	Orange
3	White/Green
4	Blue
5	White/Blue
6	Green
7	White/Brown
8	Brown

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty



For more information
Visit us at www.panduit.com
 Contact Customer Service by email: cs@panduit.com
 or by phone: 800.777.3300

© 2021 Panduit Corp.
 ALL RIGHTS RESERVED.
 NKDS67--WW-ENG
 4/2021