
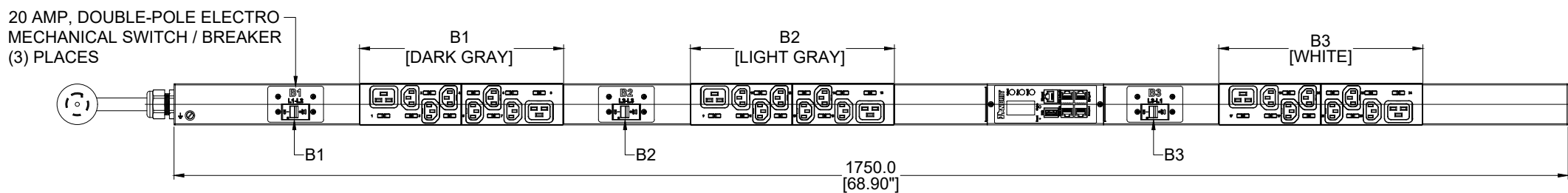
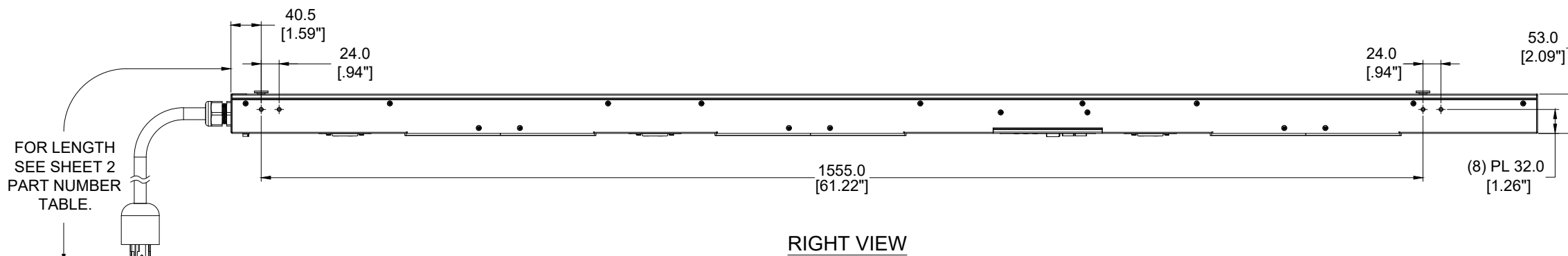
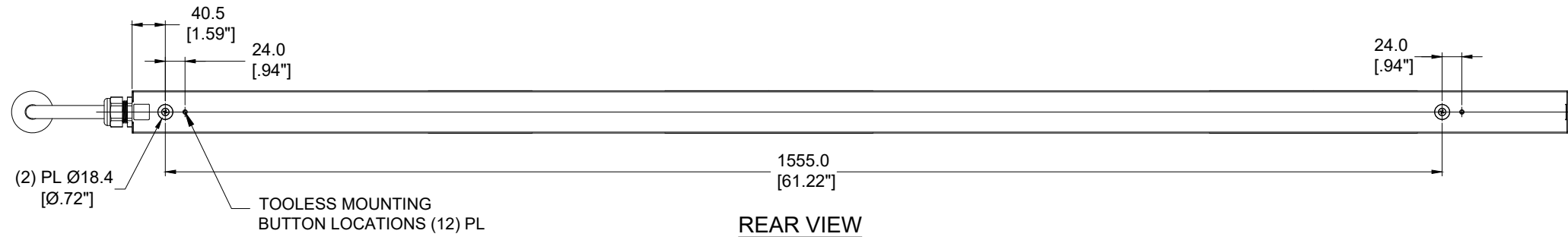


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT P/N	WEIGHT
P24F03M-XXYZ	SEE SHEET 2

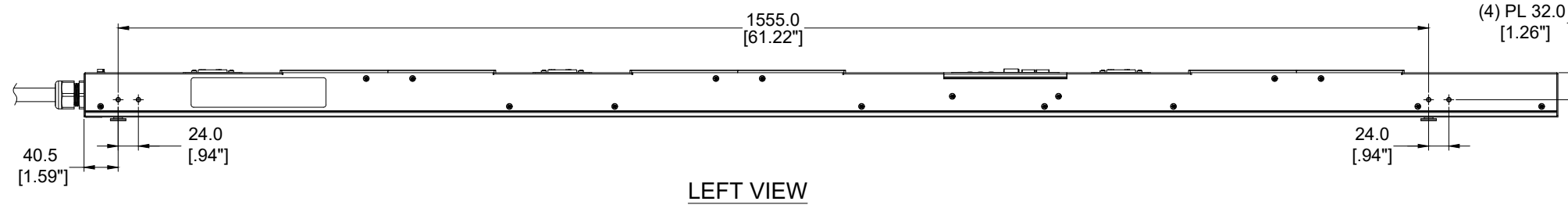


SPECIFICATION:

1. STANDARD:
- UNIT TYPE: MONITORED OUTLET
 - ORIENTATION: VERTICAL, 0U FULL
 - OUTLET QTY & TYPE: (18)C13, (6)C19
 - INPUT VOLTAGE: 100-120/200-240VAC
 - INPUT CURRENT: 30A (24A DERATED)
 - BREAKER QTY & TYPE: (3) 20AMP, DOUBLE-POLE THREE-PHASE, WYE
 - INPUT PHASE: 8.6 KVA
 - RATED POWER: NEMA L21-30P
 - INPUT PLUG: SEE SHEET 2 FOR PART NUMBER TABLE
 - INPUT POWER CORD: RoHS COMPLIANT
- REGULATORY STANDARD:
2. ADDITIONAL: NONE
3. ACCESSORIES: (1) QUICK-START GUIDE

NOTES:

- PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSION ARE IN [INCHES]
 - INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES
 - VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
 - FOR FULL PRODUCT FUNCTIONALITY REFER TO USER MANUAL
 - DRAWING VIEWS SHOW THE INPUT CORD IN THE "TOP END FED" CONFIGURATION
 - OUTLETS ARE WIRED LINE TO LINE (208V)
- IDENTIFICATION**
FOR FINISHED GOOD PART NUMBER & DESCRIPTION TABLE SEE SHEET 2 CONFIGURABLE PART NUMBERS: P24F03M-XX Y Z

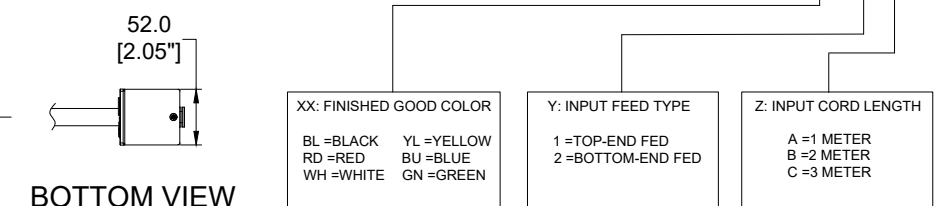

PLUG/RECEPTACLE BLOCK

PLUG
NEMA L21 - 30P, 4P 5W
30A, 120/208V MAX RATED INPUT
24A DERATED

RECEPTACLES
IEC 60320/C19
16A, 250V MAX RATED OUTPUT

RECEPTACLES
IEC 60320/C13
10A, 250V MAX RATED OUTPUT

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
03B	04/12/2022	LWB	MIM	JAWI	ADDED*OUTLETS ARE WIRED LINE TO LINE (208V)*IN NOTE 6	P24F03M
03A	06/11/2020	CWW	MIM	JAWI	UPDATED THE OUTLET DESIGN	P24F03M
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION 'DE-CODER' UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24F03M
01A	10/09/2017	WSJ	MIM	EDM	INITIAL RELEASE	P24F03M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY

SIGN _____
DATE _____
PRINT _____

TITLE: INTELLIGENT SERIES PDU
P24F03M-XXYZ
CUSTOMER DRAWING

ITEM REVISION NAME: _____
DATASHEET FILE NAME: _____

UNLESS OTHERWISE SPECIFIED
DIMENSIONAL TOLERANCE ARE: mm [IN]

Tolerance(mm)	
0<L<50	±0.5
50<L<250	±1.0
250<L<500	±1.5
500<L<1000	±2.5
1000<L<2000	±4.0

MATERIAL/COLOR: N/A

DRAWING NUMBER: P24F03M_DC

DRAWN BY: WSJ | DATE: 10/09/2017 | CHK: SEAN | SCALE: NONE

SHT 1 OF 2 | SCALE: B

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

FINISHED GOOD PART NUMBER	FINISHED GOOD DESCRIPTION	COLOR	INPUT CORD LENGTH	WEIGHT
P24F03M	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-BL1A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-BL1B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-RD1A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-RD1B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-RD1C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-WH1A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-WH1B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-WH1C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-YL1A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-YL1B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-YL1C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-BU1A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-BU1B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-BU1C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-GN1A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-GN1B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-GN1C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-BL2A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-BL2B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-BL2C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-RD2A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-RD2B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-RD2C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-WH2A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-WH2B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-WH2C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-YL2A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-YL2B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-YL2C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-BU2A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-BU2B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-BU2C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg
P24F03M-GN2A	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3'[+3.5"/-1.75"]	8.2kg
P24F03M-GN2B	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5'[+7"/-3.5"]	8.8kg
P24F03M-GN2C	VERTICAL,(18) C13,(6) C19,MONITORED OUTLET, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10'[+10"/-5"]	9.4kg

B

B

A

A

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX.
THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY

SIGN _____
DATE _____
PRINT _____

TITLE
INTELLIGENT SERIES PDU
P24F03M-XYZ
CUSTOMER DRAWING

ITEM REVISION NAME
DATASHEET FILE NAME:

UNLESS OTHERWISE SPECIFIED
DIMENSIONAL TOLERANCE ARE: mm [IN]

Tolerance(mm)
0<L<50 ±0.5
50<L<250 ±1.0
250<L<500 ±1.5
500<L<1000 ±2.5
1000<L<2000 ±4.0

MATERIAL/COLOR:
N/A

DRAWING NUMBER:
P24F03M_DC

THIRD ANGLE PROJECTION

DRAWN BY: WSJ DATE: 10/09/2017 CHK: SEAN SCALE: NONE

SHT 2 OF 2 SCALE: B

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
03B	04/12/2022	LWB	MIM	JAWI	ADDED*OUTLETS ARE WIRED LINE TO LINE (208V)*IN NOTE 6	P24F03M
03A	06/11/2020	CWW	MIM	JAWI	UPDATED THE OUTLET DESIGN	P24F03M
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION 'DE-CODER' UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24F03M
01A	10/09/2017	WSJ	MIM	EDM	INITIAL RELEASE	P24F03M