


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

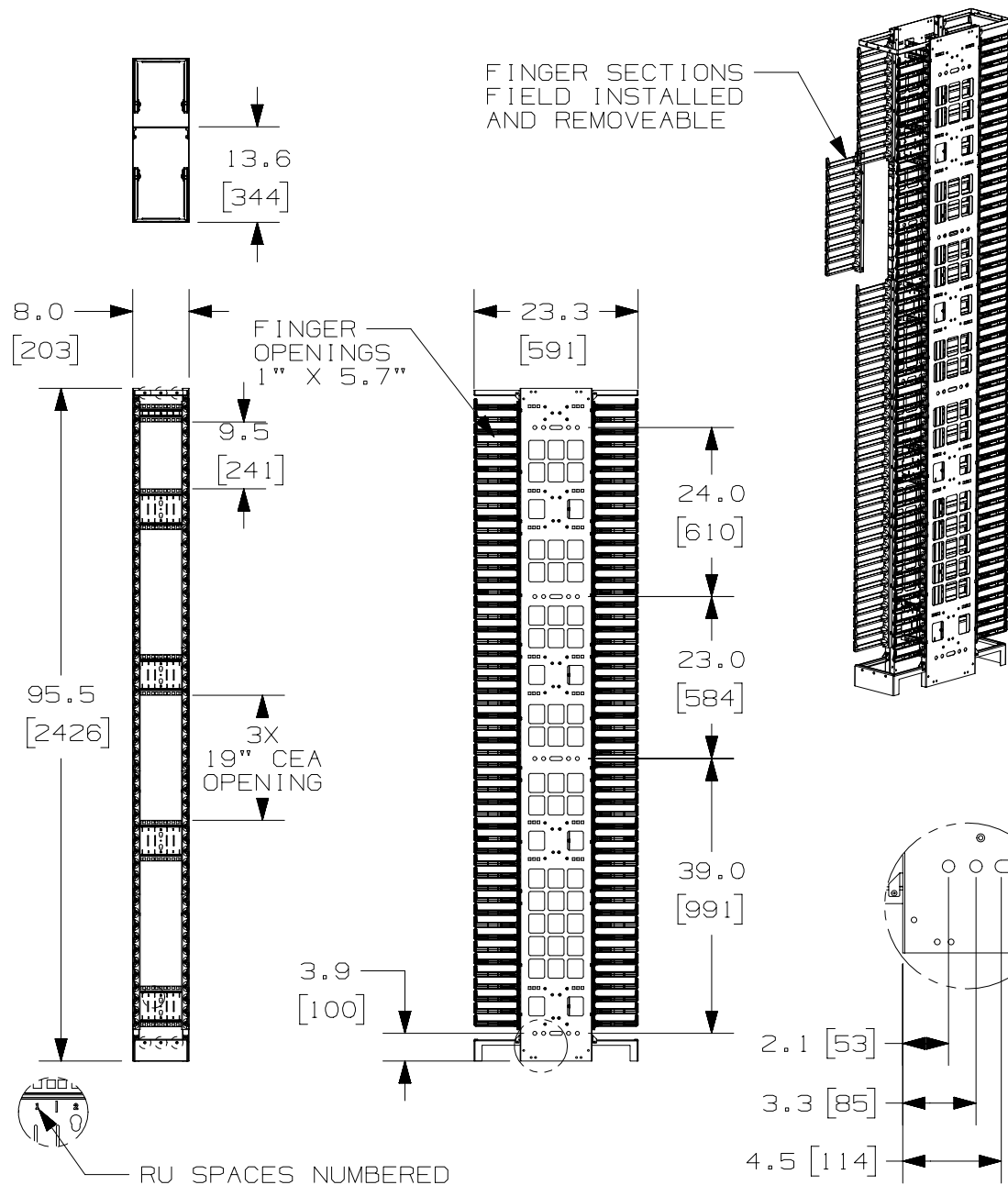

PANDUIT P/N	WEIGHT
PEV896	60.2 LBS/EACH (27.4 kg/EACH)

NOTES:

- VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART.
- COMPONENTS: (1) 8FT TALL 8" DUAL-SIDE VERTICAL MANAGER
(1) HARDWARE KIT
(2) LEFT PEV96 FINGER KITS
(2) RIGHT PEV96 FINGER KITS
(4) DOOR BRACKET BASES
- CAN BE USED WITH ANY 19 OR 23 INCH EIA STANDARD RACK.
- 3 ROWS OF 2RU 19" CEA OPENINGS (6 TOTAL RU)
- 8FT TALL 8" DOOR SOLD SEPARATELY (P/N: PED896B1)
- DIMENSIONS IN PARENTHESIS ARE METRIC.
- ALL DIMENSIONS ARE REFERENCE ONLY.

TITLE	
PATCHRUNNER HIGH CAPACITY VERTICAL MANAGER 8FT TALL 8" WIDE, DUAL-SIDED (PEV896)	
CONTROL DRAWING	
ITEM REVISION NAME	10V179AB/03
DATASET FILE NAME	10V179AB_DC/03A
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN (mm)	MATERIAL: BACKBONE - STEEL FINGERS - ABS
THIRD ANGLE PROJECTION	DRAWING NUMBER: 10V179AB
DRAWN BY BAME	DATE 7-13-11
CHK	SCALE NONE
ECN	SHT 1 OF 1
	SIZE A

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
03A	3-2-17	TWV	KZU	JEFK	REPLACED P/N PED896 WITH PED896B1 IN NOTE #5	10V179AB-DC
02A	7-21-16	AMF	KZU	KRKE	REMOVED DOOR BRACKETS	10V179AB-DC