

PanPlug® TX5e™ 24-26 AWG UTP Modular Plug

SPECIFICATIONS

Category 5e/Class D, 8-position, 8-wire, UTP modular plug shall terminate most 4-pair, 24-26 AWG, 100 ohm, solid or stranded, unshielded twisted pair cable with maximum conductor insulation diameter of 0.040 inches (1.02mm). Simplified termination method shall require no load bar. Guide ramp shall facilitate easy conductor insertion and termination. Modular plug shall terminate to T568A and T568B wiring schemes.



TECHNICAL INFORMATION

IEC compliance:	IEC 60603-7
RoHS compliance:	Compliant
UL listed:	UL 1863
CSA listed:	CSA Standard C22.2
Conductor termination:	Compatible most with 24-26 AWG solid or stranded cable with conductor insulation diameters between 0.035 in. - 0.040 in. (0.889mm - 1.016mm)
Operating temperature:	14°F to 140°F (-10°C to 60°C)
Storage temperature:	-40°F to 158°F (-40°C to 70°C)
Plug housing:	UL94V-0 rated clear Polycarbonate
Contacts:	Gold plated phosphor bronze

KEY FEATURES AND BENEFITS

Patented tangle-free latch:	Prevents snags and provides easy release, saving time and providing reliability on frequent moves, adds, and changes
Robust construction:	Rated to 2500 mating cycles

APPLICATIONS

Category 5e plugs can be used in applications such as high-performance workstations, 155 Mb/s ATM, 622 Mb/s ATM, 1.2 Gb/s ATM, Token Ring 4/16, digital video and broadband/baseband analog video, and Voice over IP.

TX5e 24-26 AWG UTP Modular Plug

10 pack:	MP588-X
50 pack:	MP588-L
100 pack:	MP588-C
100 pack:	MP588-M

Tools and Accessories

Crimp tool:	MPT5-8AS
Standard RJ45 plug lock-in device (Red):	PSL-DCPLE^
Recessed RJ45 plug lock-in device (Red):	PSL-DCPLRE^

^Colors other than Red: BL (Black), BU (Blue), GR (Green), YL (Yellow), OR (Orange), IW (International White), or IG (International Gray)


-C indicates 100 pieces per package to reduce single-use plastic.



All Part Numbers Compliant with the U.S. Trade Agreements Act (TAA) for purchases shipped to the United States.

PanPlug® TX5e™ 24-26 AWG UTP Modular Plug

ENGINEERING DRAWING

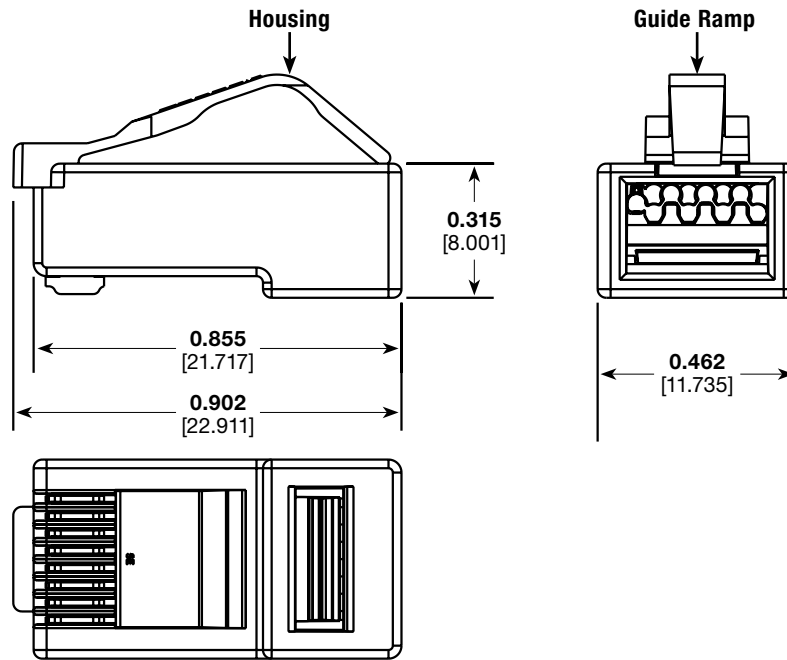

Dimensions are in inches. [Dimensions in brackets are metric].

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com
Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

PANDUIT®

© 2023 Panduit Corp.
ALL RIGHTS RESERVED.
COSP294-WW-ENG
11/2023