



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

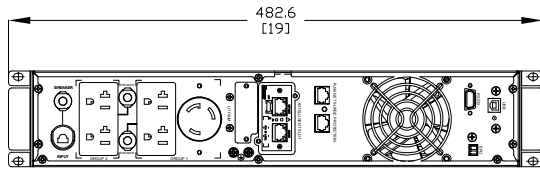

VIEW ROTATED 180°

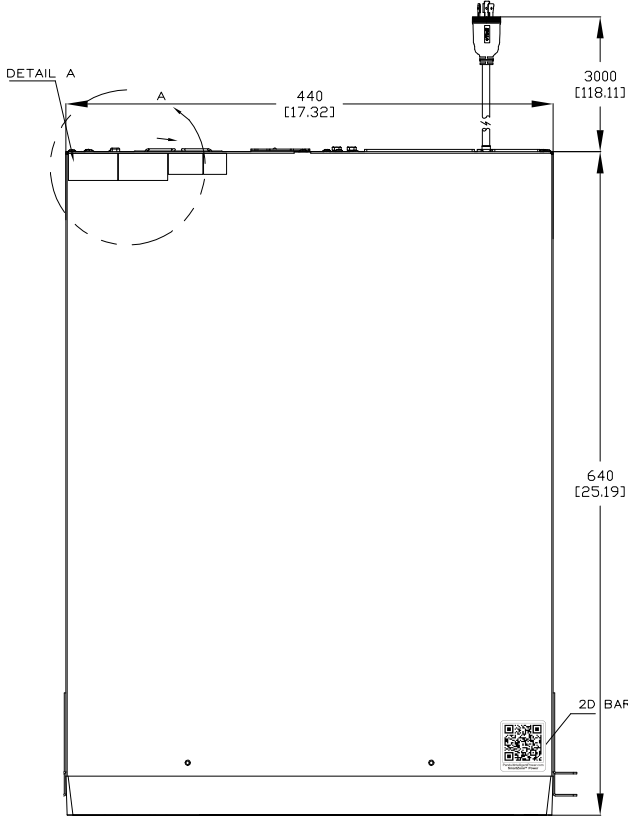

 
COMPLIANCE LABEL

CAUTION LABEL 1 CAUTION LABEL 2



DETAIL A
SCALE 1: 3

2D BARCODE LABEL



SPECIFICATION:

1. STANDARD:

UPS TOPOLOGY:	LINE INTERACTIVE
KVA:	3
BATTERY TYPE:	LITHIUM-ION
INPUT PLUG:	NEMA L5-30P
NOMINAL INPUT VOLTAGE:	100/110/115/120/125VAC
INPUT PHASE:	SINGLE
OUTPUT PHASE:	SINGLE
NOMINAL OUTPUT VOLTAGE:	100/110/115/120/125VAC
OUTLET TYPE AND QTY:	NEMA L5-30R(1),NEMA 5-20R(1)
DISPLAY TYPE:	2.8 INCH,4 BUTTON
PARALLEL PORT SUPPORT:	NO
INPUT BREAKER TYPE:	30A PUSH BUTTON
OUTPUT BREAKER TYPE:	(2)20A PUSH BUTTON

2. ADDITIONAL:

NONE

3. ACCESSORY COMPONENTS:

P/N U03N11L CONTAINS AN INTELLIGENT NETWORK CARD,(INSTALLED)
STABILIZER BRACKET, QTY:(4)
INSTALLATION EARS, QTY:(2)
SAFTY WARNING SHEET,QTY:(1)
SELECTION GUIDE(POCKET GUIDE),QTY:(1)
DB9/DB9 RS232 1.5M COMMUNICATION CABLE, QTY:(1)
USB-A/USB-B 1.2M SERIAL COMMUNICATION CABLE, QTY:(1)
INCLUDES P/N:ULC372 INTERNAL BATTERY CARTRIDGE, QTY (1),(INSTALLED)
INCLUDES P/N:URMKIT2 INSTALLATION RAIL KIT, QTY (1),(U03N11L ONLY)
REFER TO ASSOCIATED DRAWINGS FOR PHYSICAL DIMENSIONS AND SPECIFICATIONS
EPO PLUG WITH SHORTING WIRE,QTY:(1),(INSTALLED)


NOTES:

1. PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSIONS ARE IN INCHES.
2. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES.
3. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PRODUCT.
4. ALL PURCHASED ITEMS CONFORM TO C2-0834 PANDUIT SPECIFICATION FOR CHEMICAL SUBSTANCES TO BE CONTROLLED IN PRODUCT AND PACKAGING.

IDENTIFICATION:

PART NUMBER	DESCRIPTION	SHIPPING WEIGHT (KG)
U03S11L	SMARTZONE UPS, 3kVA, 2U, 120V, SINGLE PHASE, LITHIUM-ION POWER PROTECTION	32.2
U03N11L	SMARTZONE UPS, 3kVA, 2U, 120V, SINGLE PHASE, LITHIUM-ION POWER PROTECTION WITH INTELLIGENT NETWORK CARD	35.5

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

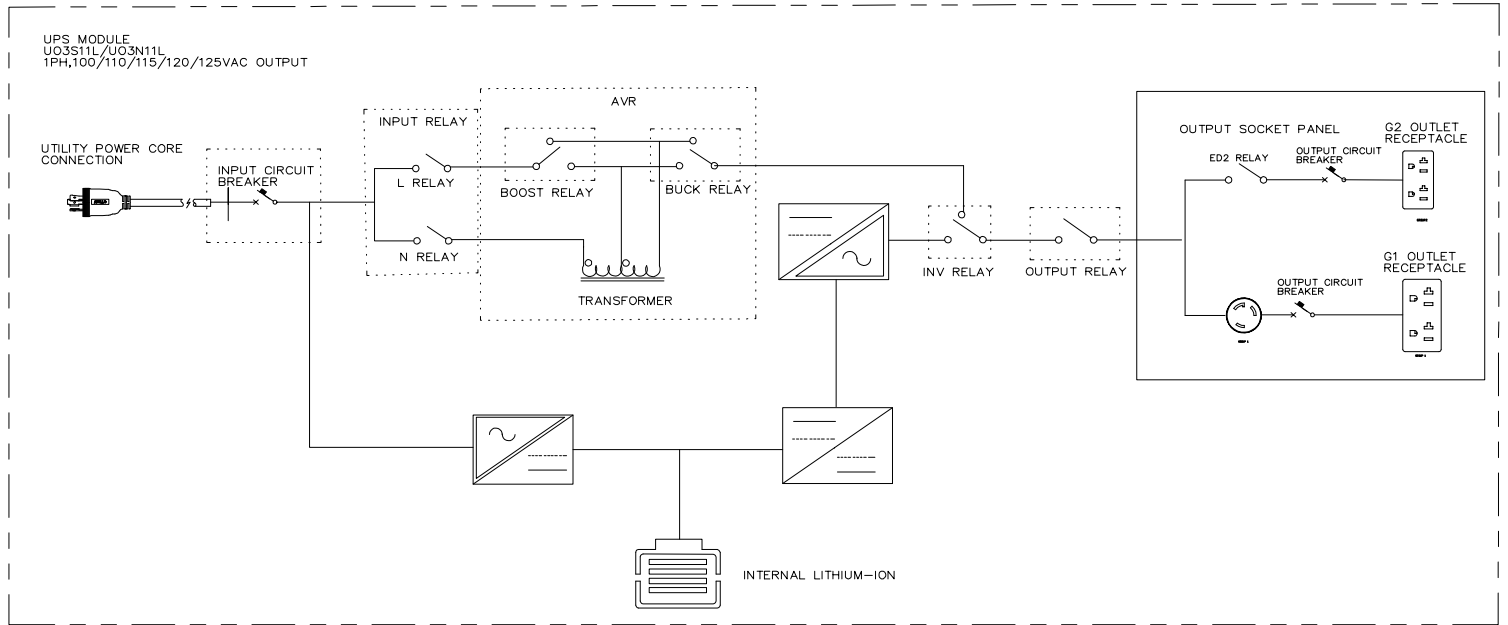

CORE FIRMWARE PART NUMBER: 3040-6390
CORE FIRMWARE VERSION: V001B0000000

LEGEND			
SYMBOL	DESCRIPTION	SYMBOL	DESCRIPTION
	CIRCUIT BREAKER		AC-DC CONVERTER
	RELAY		DC-DC CONVERTER
	DC-DC CONVERTER		AC-DC CHARGER
			BATTERY

										SMARTZONE UPS U03511L/U03N11L	
										CUSTOMER DRAWING	
										U03511L/U03N11L/01	
										U03511L/U03N11L-DA/01A	
										PANDUIT	
										UNLESS OTHERWISE SPECIFIED CONFORM TO STANDARDS [m]	
										REVISION: N/A	
										U03N11L	
										U03N11L	
										U03N11L-DC	
										01/11/2022	
										MFG VARIOUS	
										SHT 1 OF 2	
										5	