
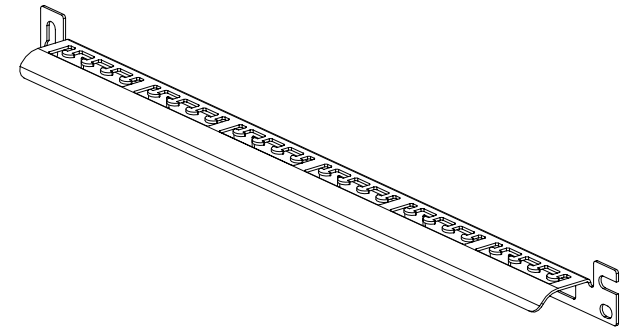


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT P/N	WEIGHT
SRBCT	.55 LB/EACH PC (249.6 g/EACH PC)

NOTES:

- SEE CURRENT CATALOG FOR ADDITIONAL PART NUMBER SUFFIXES TO INDICATE COLOR AND OR PACKAGE QUANTITY.
- SEE CATALOG FOR COMPLETE LIST OF PARTS APPLICABLE FOR USE WITH THIS PART.
- DIMENSIONS IN PARENTHESES ARE IN METRIC.
- PART INCLUDES:
1- STRAIN RELIEF BAR
24- CABLE TIE
1- #12-24 SCREW KIT

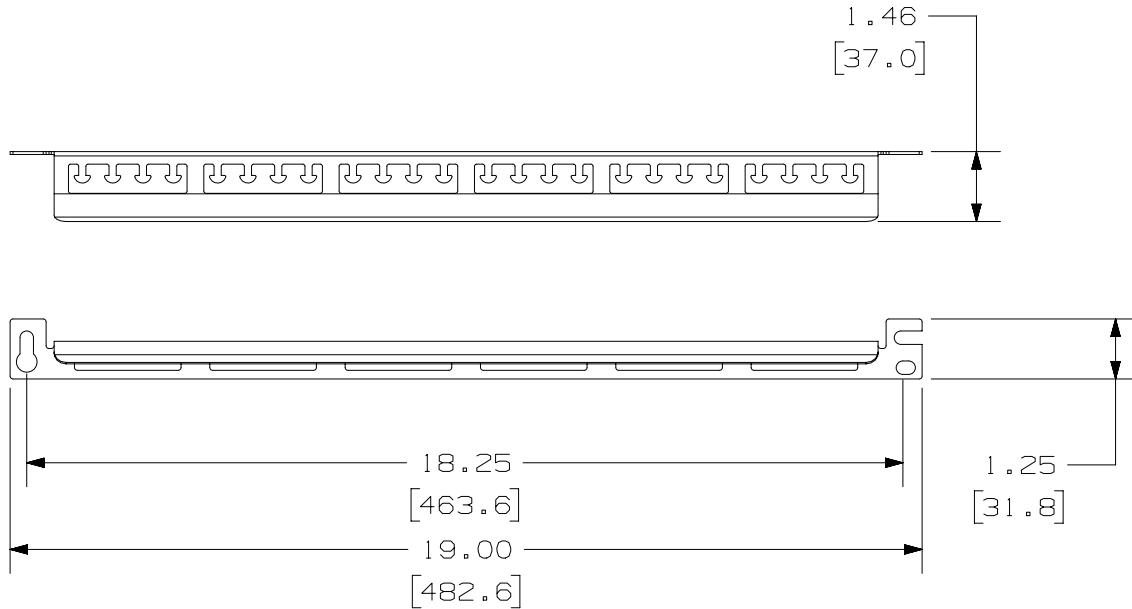

PART NUMBER		SRBCT	
TITLE			
STRAIN RELIEF BAR WITH CABLE TIES			
CUSTOMER DRAWING			
ITEM REVISION NAME		M02077BD/06	
DATASET FILE NAME		M02077BD_DC/06A	
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN (mm)		MATERIAL:	
.x ± .xxx ± .010 (.3)		STRAIN RELIEF BAR: 16 GAGE C.R.S.	
.xx ± .03 (.8) ANGLES ±		DRAWING NUMBER:	
THIRD ANGLE PROJECTION		02077-13	
DRAWN BY	DATE	CHK	SCALE
JSP	3-15-06	MJD	NONE
SHT 1 OF 1			SIZE
			A

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
2	11-30-18	BAME	KRKE	MMR	A. REMOVED METRIC SCREWS	02077-13
1	4-28-14	BJN	JSP	MMR	REVSIED & REDRAWN PREVIOUS REVISIONS REMVD FOR CLARITY	02077-13

D101000DA/14