
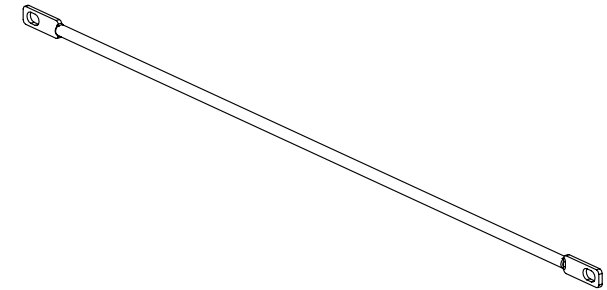


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.


PANDUIT P/N	WEIGHT
SRBS19BL-XY	1.36 LB/10 PCS (616.9 g/10 PCS)

NOTES:

- SEE CURRENT CATALOG FOR ADDITIONAL PART NUMBER SUFFIXES TO INDICATE COLOR AND OR PACKAGE QUANTITY.
- SEE CATALOG FOR COMPLETE LIST OF PARTS APPLICABLE FOR USE WITH THIS PART.
- DIMENSIONS IN PARENTHESES ARE IN METRIC.
- PART INCLUDES:  
1- STRAIGHT STRAIN RELIEF BAR  
2- MOUNTING SCREW

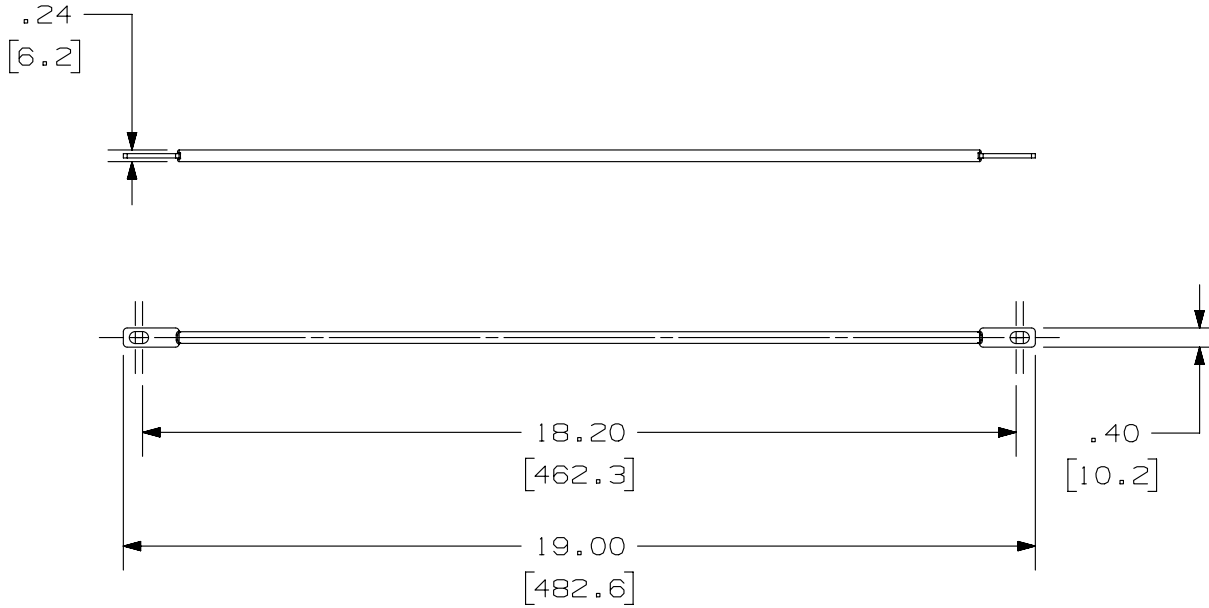

PART NUMBER		SRBS19BL - XY	
TITLE			
STRAIGHT STRAIN RELIEF BAR			
CUSTOMER DRAWING			
ITEM REVISION NAME		M02479DU/03	
DATASET FILE NAME		M02479DU_DC101/03A	
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [ mm ]		MATERIAL:	
.x ± .xx ± .03 [ .8 ]		STEEL BAR STOCK	
.xxx ± .010 [ .3 ]		DRAWING NUMBER:	
ANGLES ±		02479-101	
THIRD ANGLE PROJECTION		SHT 1 OF 1	
DRAWN BY	DATE	CHK	SCALE
JSP	4-18-06	MJD	NONE
REV	DATE	BY	CHK
1	4-25-14	BJN	JSP
APR	DESCRIPTION		ECN
	REVISED & REDRAWN PREVIOUS REVISIONS REMVD FOR CLARITY		02479-101

 

D10100DA/14

2

1

2

1