



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.


PANDUIT P/N	WEIGHT
P30D02M-XXYZ	SEE SHEET 2

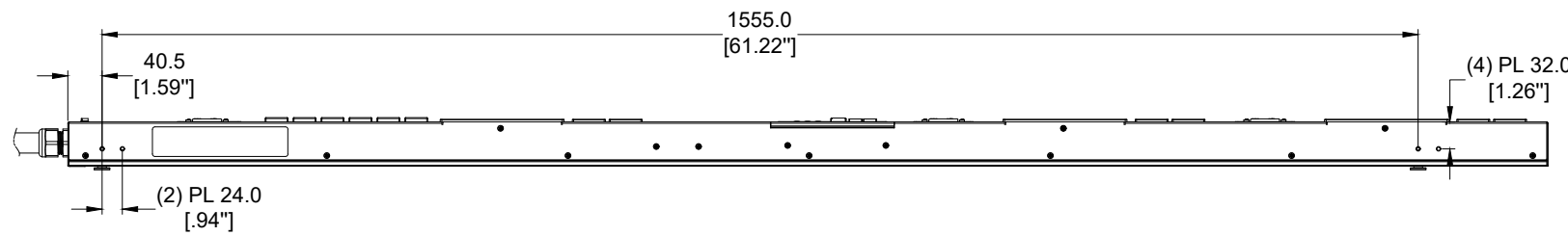


LEFT VIEW

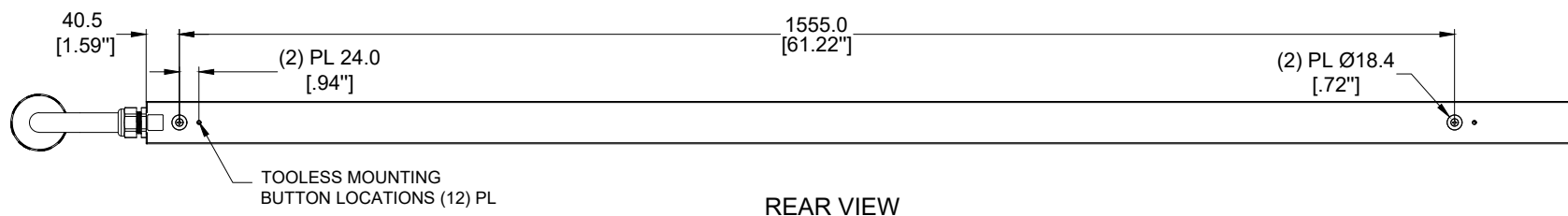


REAR VIEW

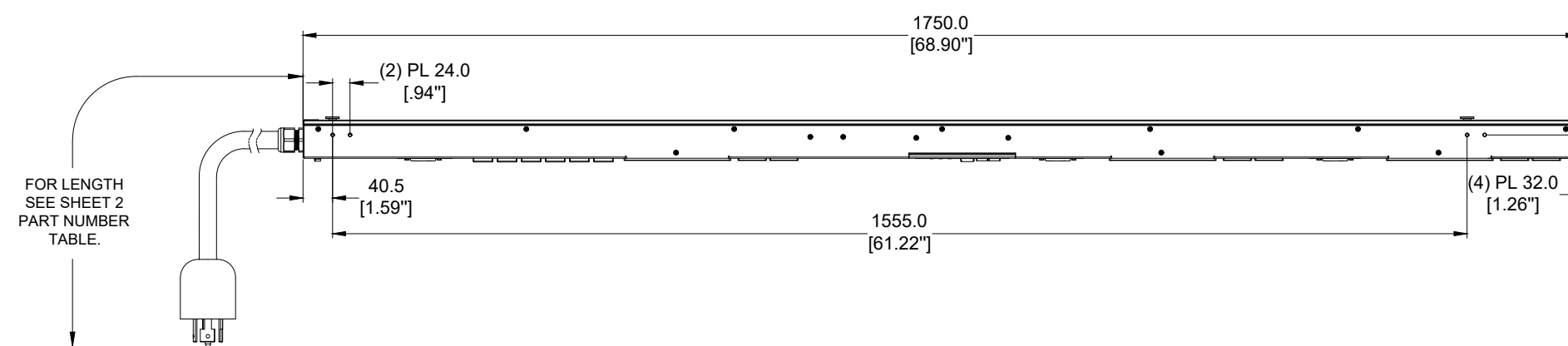

RIGHT VIEW

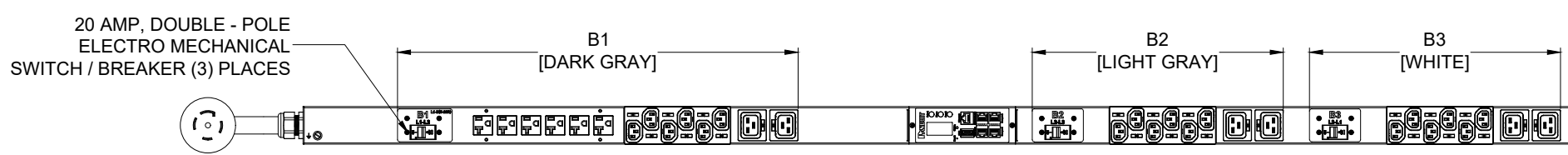

FRONT VIEW

 

BOTTOM VIEW

SPECIFICATION:

- 1. STANDARD:**
- | | |
|----------------------|-----------------------------------|
| UNIT TYPE: | MONITORED INPUT |
| ORIENTATION: | VERTICAL, 0U FULL |
| OUTLET QTY&TYPE: | (18) C13, (6) C19, (6) 5-20R |
| INPUT VOLTAGE: | 100-120/200-240VAC |
| INPUT CURRENT: | 30A (24A DERATED) |
| BREAKER QTY&TYPE: | (3) 20AMP, DOUBLE-POLE |
| INPUT PHASE: | THREE-PHASE WYE |
| RATED POWER: | 8.6kVA |
| INPUT PLUG: | NEMA L21-30P |
| INPUT POWER CORD: | SEE SHEET 2 FOR PART NUMBER TABLE |
| REGULATORY STANDARD: | RoHS COMPLIANT |
- 2. ADDITIONAL:**
NONE
- 3. ACCESSORIES:**
(1) QUICK-START GUIDE

NOTES:

- PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSION ARE IN [INCHES]
- INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES
- VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
- FOR FULL PRODUCT FUNCTIONALITY REFER TO USER MANUAL
- DRAWING VIEWS SHOW THE INPUT CORD IN THE "TOP END FED" CONFIGURATION
- OUTLETS ARE WIRED LINE TO LINE (208V)

IDENTIFICATION

FOR FINISHED GOOD PART NUMBER & DESCRIPTION TABLE SEE SHEET 2 CONFIGURABLE PART NUMBERS: **P30D02M-XX Y Z**

XX: FINISHED GOOD COLOR BL=BLACK YL=YELLOW RD=RED BU=BLUE WH=WHITE GN=GREEN	Y: INPUT FEED TYPE 1=TOP-END FED 2=BOTTOM-END FED	Z: INPUT CORD LENGTH A=1 METER B=2 METER C=3 METER
--	---	---

PLUG/RECEPTACLE BLOCK

	PLUG NEMA L21-30P, 4P 5W 30A, 120/208V MAX RATED INPUT 24A DERATED
	RECEPTACLES IEC 60320/C19 16A, 250V MAX RATED OUTPUT
	RECEPTACLES NEMA 5-20R 20A, 125V MAX RATED OUTPUT
	RECEPTACLES IEC 60320/C13 10A, 250V MAX RATED OUTPUT

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
03B	04/08/2022	CWW	MIM	JAWI	ADDED *OUTLETS ARE WIRED LINE TO LINE (208V)*IN NOTE 6	P30D02M
03A	07/16/2020	CWW	MIM	JAWI	UPDATED THE OUTLET DESIGN	P30D02M
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION 'DE-CODER'	P30D02M
01A	07/27/2017	GEORGE	MIM	EDM	INITIAL RELEASE	P30D02M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY

SIGN _____
DATE _____
PRINT _____

TITLE: INTELLIGENT SERIES PDU
P30D02M-XXYZ
CUSTOMER DRAWING

ITEM REVISION NAME: _____
DATASHEET FILE NAME: _____

UNLESS OTHERWISE SPECIFIED
DIMENSIONAL TOLERANCE ARE: mm [IN]

Tolerance(mm)	
0<L<50	±0.5
50<L<250	±1.0
250<L<500	±1.5
500<L<1000	±2.5
1000<L<2000	±4.0

MATERIAL/COLOR: N/A

DRAWING NUMBER: P30D02M_DC

DRAWN BY: GEORGE DATE: 07/27/2017 CHK: SEAN SCALE: NONE

SHT 1 OF 2 SCALE: B

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

FINISHED GOOD PART NUMBER	FINISHED GOOD DESCRIPTION	COLOR	INPUT CORD LENGTH	WEIGHT
P30D02M	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-BL1A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-BL1B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-RD1A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-RD1B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-RD1C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-WH1A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-WH1B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-WH1C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-YL1A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-YL1B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-YL1C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-BU1A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-BU1B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-BU1C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-GN1A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-GN1B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-GN1C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , TOP-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-BL2A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-BL2B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-BL2C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-RD2A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-RD2B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-RD2C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-WH2A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-WH2B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-WH2C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-YL2A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-YL2B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-YL2C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-BU2A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-BU2B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-BU2C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg
P30D02M-GN2A	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	6.7kg
P30D02M-GN2B	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	7.3kg
P30D02M-GN2C	VERTICAL,(18) C13,(6) C19,(6) 5-20R, MONITORED INPUT, 100-120/200-240V/30A/3 PHASE WYE , BOTTOM-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10' [+10"/-5"]	7.9kg

B

B

A

A

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY		SIGN
		DATE
		PRINT
TITLE INTELLIGENT SERIES PDU P30D02M-XXYZ CUSTOMER DRAWING		
ITEM REVISION NAME:		
DATASHEET FILE NAME:		
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN]		MATERIAL/COLOR:
Tolerance(mm) 0<L<50 ±0.5 50<L<250 ±1.0 250<L<500 ±1.5 500<L<1000 ±2.5 1000<L<2000 ±4.0		N/A
THIRD ANGLE PROJECTION		DRAWING NUMBER: P30D02M_DC
DRAWN BY GEORGE	DATE 07/27/2017	CHK SEAN
SCALE NONE		SCALE B
SHT 2 OF 2		

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
03B	04/08/2022	CWW	MIM	JAWI	ADDED *OUTLETS ARE WIRED LINE TO LINE (208V)*IN NOTE 6	P30D02M
03A	07/16/2020	CWW	MIM	JAWI	UPDATED THE OUTLET DESIGN	P30D02M
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION 'DE-CODER'	P30D02M
01A	07/27/2017	GEORGE	MIM	EDM	INITIAL RELEASE	P30D02M