

# Security Lock Solutions Padlocks, Hasps, and Cables for Perimeter and Property

Panduit offers a broad range of security lock solutions in a variety of styles, colors, and keying configurations for nearly every application or environment.



## Key Features

## Benefits



### Harsh Environment Padlocks

Best for oil and gas, mining, and electrical contractor markets for use with equipment, outdoor security gates, enclosures, and more.

<b>Non-corrosive materials</b>	Brass bodies paired with brass or stainless steel shackles provide ultimate protection against corrosion caused by weather or harsh chemicals
<b>Protective jackets</b>	Protective jackets provide an extra layer of protection to ensure reliability remains even in the toughest conditions
<b>Customization</b>	Padlocks can be custom keyed depending on facility need; keyed different, keyed alike and master keyed available



### General Security Padlocks

Best for ship building, MRO, Industrial Construction markets for use with storage sheds, gates, tool boxes, trailers, enclosures, and more.

<b>Built to last</b>	Precision engineering, quality materials and innovative concepts built to withstand the test of time
<b>Secure</b>	Manufactured to high testing standards giving users confidence in their reliability
<b>Customization</b>	Padlocks can be custom keyed depending on facility need; keyed different, keyed alike and master keyed available



### Security Hasps and Cables

Versatile for a variety of uses in any market to secure equipment, enclosures, gates, and more.

<b>Strength</b>	Hasps and cables are made using high quality materials providing superior strength against physical attack
<b>Versatility</b>	Hasps and cables are both available in a variety of different sizes

## Keying Systems



**Keyed Different:**  
Each padlock has its own unique key.



**Keyed Alike:**  
Each padlock can be opened with the same key.



**Keyed Different with Master Key:**  
Each padlock has its own key. The master key can open all padlocks.



## Ordering Information

### Weatherproof Padlock


- Solid brass body to stand up to the harshest environments
- Sealed lock body with cover seal and drainage channels to protect against water and dirt
- Inner components made from non-corrosive materials
- Standard locks are keyed differently. Also available in keyed alike and master keyed options (contact customer service for further details).



Part Number	Color	Body Width		Shackle Clearance Height		Shackle Clearance Width		Shackle Diameter		Pins in Cyl.	Shackle Material	Std. Pkg. Qty.
		in.	mm	in.	mm	in.	mm	in.	mm			
PSL-14ABL	Black	1 21/64	34	31/32	24.5	17/32	13.5	1/4	6.5	4	Steel	1
PSL-14BYL	Yellow	1 3/4	49	7/8	25	13/16	20	9/32	8	5	Steel	1
PSL-14BYL-LS	Yellow	1 3/4	49	2 1/2	63	13/16	20	9/32	8	5	Steel	1
PSL-15ABU	Blue	1 3/4	49	7/8	25	13/16	20	9/32	8	5	Stainless	1
PSL-15ABU-LS	Blue	1 3/4	49	2 1/2	63	13/16	20	9/32	8	5	Stainless	1
PSL-15BBU	Blue	1 5/32	55	1 3/64	26.5	59/64	23.5	23/64	9	5	Stainless	1

### Non-Sparking Brass Padlock

- Shackle and body made from solid brass
- Inner components made from non-corrosive materials
- Color: Black
- Standard locks are keyed differently. Also available in keyed alike and master keyed options (contact customer service for further details).

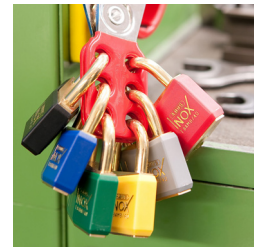

Part Number	Body Width		Shackle Clearance Height		Shackle Clearance Width		Shackle Diameter		Pins in Cyl.	Std. Pkg. Qty.
	in.	mm	in.	mm	in.	mm	in.	mm		
PSL-17ABL	1 11/16	43	13/16	21	13/16	20	1/4	6	4	1
PSL-17BBL	2	53	15/16	24	1	25	9/32	7	5	1

Available in other colors by special order

### Brass Weatherproof Combination Padlock

- Forged brass body with stainless steel shackle
- 4-digit resettable code
- Inner components made from non-corrosive materials
- Resettable combination (comes with resettable tool)
- Color: Brass



Part Number	Body Width		Shackle Clearance Height		Shackle Clearance Width		Shackle Diameter		Std. Pkg. Qty.
	in.	mm	in.	mm	in.	mm	in.	mm	
PSL-18	2	53	1	25	1	25	5/16	8	1
PSL-18-LS	2	53	2 1/2	63	1	25	5/16	8	1



## Ordering Information

### TITALIUM™ Padlock

- TITALIUM™ aluminum alloy lock body; light, yet secure
- Shackle made of hardened steel with NANO PROTECT™ coating for extra corrosion resistance
- Color: Gray
- Standard locks are keyed differently. Also available in keyed alike options (contact customer service for further details).



Part Number	Body Width		Shackle Clearance Height		Shackle Clearance Width		Shackle Diameter		Pins in Cyl.	Std. Pkg. Qty.
	in.	mm	in.	mm	in.	mm	in.	mm		
PSL-13A	25/32	20	29/64	11.5	3/8	9.5	9/64	3.5	3	1
PSL-13B	31/32	24.5	17/32	13.5	33/64	13	5/32	4	4	1
PSL-13C	1 3/16	30	43/64	17	5/8	16	13/64	5	4	1
PSL-13D	1 9/16	40	29/32	23	7/8	22	15/64	6	5	1
PSL-13D-LS	1 9/16	40	1 37/64	40	7/8	22	15/64	6	5	1
PSL-13E	1 31/32	50	1 9/64	29	1 7/64	28	5/16	8	5	1

### Brass Padlock


- Solid brass body for extra corrosion resistance
- Shackle made from hardened steel
- Color: Brass
- Standard locks are keyed differently. Also available in keyed alike options (contact customer service for further details).



Part Number	Body Width		Shackle Clearance Height		Shackle Clearance Width		Shackle Diameter		Pins in Cyl.	Std. Pkg. Qty.
	in.	mm	in.	mm	in.	mm	in.	mm		
PSL-16A	15/16	24	7/16	11	15/32	12	5/32	4	3	1
PSL-16B	1 9/64	29	33/64	13	19/32	15	13/64	5	3	1
PSL-16C	1 1/2	38	7/8	22	53/64	21	15/64	6.5	4	1
PSL-16C-LS	1 1/2	38	2 1/2	63	53/64	21	15/64	6.5	4	1
PSL-16D	1 3/4	43	15/16	24	15/16	24	1/4	6	4	1
PSL-16E	1 7/8	48	15/16	24	63/64	25	9/32	7	5	1
PSL-16F	2 9/32	58	1 1/4	32	1 1/4	32	5/16	8	5	1

### Laminated Steel Padlock

- Laminated steel with ETERNA™ coating on each laminate for extreme corrosion resistance
- Tough, countersunk rivets for extra strength
- High-precision 5-pin tumbler, drilling and pulling protected
- Color: Blue
- Standard locks are keyed differently. Also available in keyed alike options (contact customer service for further details).

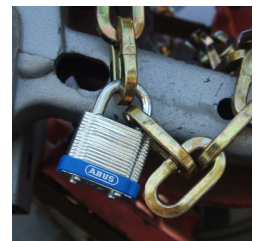


Part Number	Body Width		Shackle Clearance Height		Shackle Clearance Width		Shackle Diameter		Pins in Cyl.	Std. Pkg. Qty.
	in.	mm	in.	mm	in.	mm	in.	mm		
PSL-6ABU	1 1/4	35	5/8	15	19/32	15	3/16	5	4/5	1
PSL-6ABU-LS	1 1/4	25	2	50	19/32	15	3/16	5	4/5	1
PSL-6BU	1 1/2	44	3/4	20	13/16	18	1/4	7	4/5	1
PSL-6BU-LS	1 1/2	44	2	50	13/16	18	1/4	7	4/5	1
PSL-6CBU	1 59/64	49	29/32	23	25/32	20	5/16	8	4/5	1
PSL-6CBU-LS	1 59/64	49	2	50	25/32	20	5/16	8	4/5	1
PSL-6DBU	2	53	1	25	15/16	23	11/32	9	4/5	1
PSL-6DBU-LS	2	53	2	50	15/16	23	11/32	9	4/5	1

# Security Hasps and Cables

## Ordering Information

### Steel Hasp

- Hardened steel construction for extra strength
- Hidden screws and hinge pins for extra security
- Corrosion protected galvanized finish
- Color: Silver
- Available in 5 different sizes

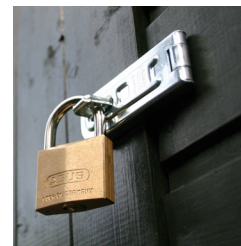

Part Number	Eye Loop Diameter		Length		Std. Pkg. Qty.
	in.	mm	in.	mm	
PSL-PH1	23/64	9	3	75	1
PSL-PH2	33/64	13.4	3 3/4	95	1
PSL-PH3	33/64	13.4	4 1/2	115	1
PSL-PH4	33/64	13.4	5 1/4	135	1
PSL-PH5	33/64	13.4	6 1/2	155	1

### Braided Steel Cable

- Flexible poly-coated braided steel cable
- The cable loops can be intertwined and locked with a padlock
- Color: Black
- Available in a variety of diameters and lengths



Part Number	Diameter		Length		Std. Pkg. Qty.
	in.	mm	ft.	cm	
PSL-PC31-6	5/16	8	6	200	1
PSL-PC31-10	5/16	8	10	250	1
PSL-PC38-6	3/8	10	6	200	1
PSL-PC38-16	3/8	10	16	500	1
PSL-PC38-33	3/8	10	33	1000	1

### Lockout/Tagout Devices

Panduit has a line of versatile and innovative Lockout/Tagout devices, tags, and safety padlocks to isolate and lockout energy sources.




### Facility Identification

Panduit has a broad array of identification products, including customer preprinted, and print on-demand solutions. Solutions for identification of Lockout/Tagout areas, identification of Arc Flash hazards, and required personal protective equipment (PPE).



### VeriSafe™ Absence of Voltage Tester

VeriSafe™ is designed to minimize risk to electrical hazards by verifying the absence of voltage before equipment is accessed, making it easier for qualified electrical workers to determine an electrically safe environment in a fraction of the time compared to hand-held portable test instruments.

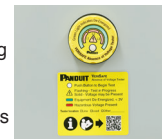

#### WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT CANADA  
Markham, Ontario  
cs-cdn@panduit.com  
Phone: 800.777.3300

PANDUIT EUROPE LTD.  
London, UK  
cs-emea@panduit.com  
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.  
Republic of Singapore  
cs-ap@panduit.com  
Phone: 65.6305.7575

PANDUIT JAPAN  
Tokyo, Japan  
cs-japan@panduit.com  
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA  
Guadalajara, Mexico  
cs-la@panduit.com  
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.  
Victoria, Australia  
cs-aus@panduit.com  
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to [www.panduit.com/warranty](http://www.panduit.com/warranty)

# PANDUIT®

For more information  
Visit us at [www.panduit.com](http://www.panduit.com)

Contact Customer Service by email: [cs@panduit.com](mailto:cs@panduit.com)  
or by phone: 800-777-3300

© 2018 Panduit Corp.  
ALL RIGHTS RESERVED.  
SFCB10- -SA-ENG  
02/2018