


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

Part Number	Wire Type	Wire Length in.(mm)	Strip length in.(mm)	Pc per bag	Description	Weight lb.(kg)	Wire Insulation Color
SGPS12-8FT-L10	12 AWG STRANDED	8(203)	0.63(16)	50	12 AWG Stranded 8" Flanged Spade Terminal, Stripped 5/8"	0.9 (0.4)	WHITE
SGPS12-8FT-L20	12 AWG STRANDED	8(203)	0.63(16)	50	12 AWG Stranded 8" Flanged Spade Terminal, Stripped 5/8"	0.9 (0.4)	BLACK
SGPS12-8FT-L2	12 AWG STRANDED	8(203)	0.63(16)	50	12 AWG Stranded 8" Flanged Spade Terminal, Stripped 5/8"	0.9 (0.4)	RED

NOTES:

1. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A LIST OF CURRENT PARTS APPLICABLE FOR USE WITH THIS PRODUCT.
2. ALL MATERIALS AND COMPONENTS USED MEET THE MATERIAL RESTRICTIONS OF RoHS (EUROPEAN DIRECTIVE 2011/65/EU ON THE RESTRICTION OF HAZARDOUS SUBSTANCES) AS PROPOSED BY THE RoHS TECHNICAL ADAPTATION COMMITTEE.
3. THE FLANGED SPADE TERMINAL IS COMPATIBLE WITH #10-32 SCREW.
4. ALL WIRES ARE THHN WIRE. THE FLANGED TERMINAL IS MADE OF BRASS.
5. SEE TABLE FOR THE WIRE INSULATION COLOR.
6. VOLTAGE RATING: 600V
7. TEMPERATURE RATING: 105 °C

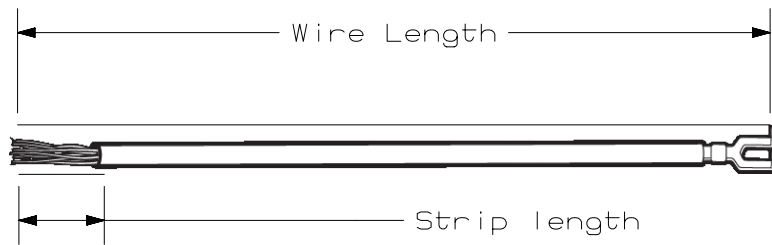

PROCESSED WIRE

TITLE									
Stronghold Processed Wire Customer Drawing									
CUSTOMER DRAWING									
ITEM REVISION NAME					00354EBH/02				
DATASET FILE NAME					00354EBH_DC/02				
					PANDUIT THIRD ANGLE PROJECTION				
					DRAWING NUMBER				
					00354EBH_DC				
DRAWN BY		DATE		CHK		SCALE		SIZE	
JSUN		10/05/2018		RAKL		NONE		A	
SHEET 1 OF 1									

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
02	01/15/2019	JSUN	RAKL	JADE	REMOVE COLOR FROM DESCRIPTION	041337/2
01	01/03/2019	JSUN	RAKL	JADE	ADD SGPS12-8FT-L2	041337/1
00	10/5/2018	JSUN	RAKL	JADE	INITIAL RELEASE	041337/0

A-SIZE CUSTOMER