
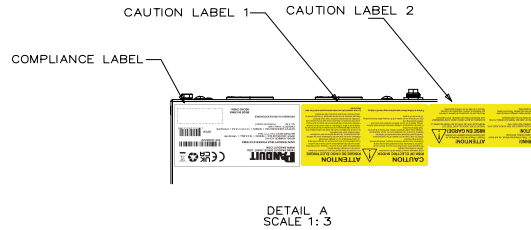
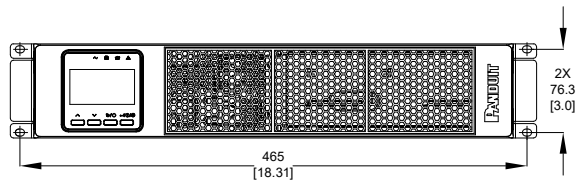
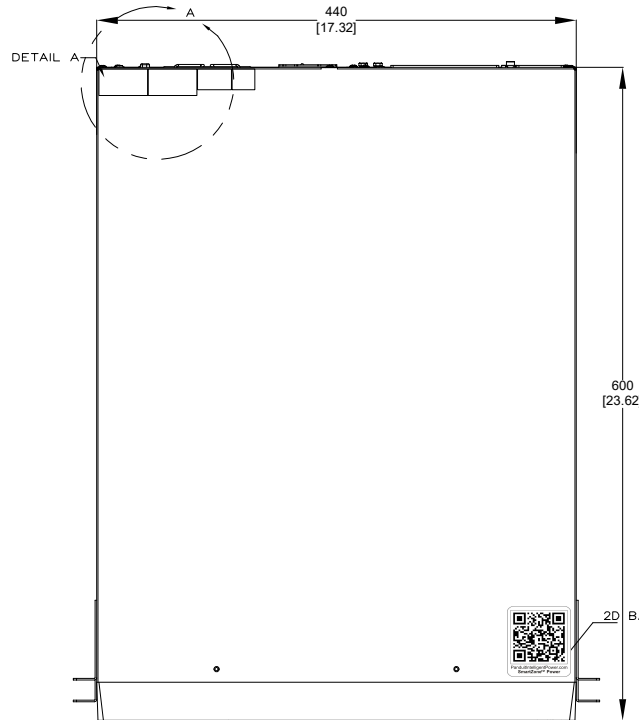


THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

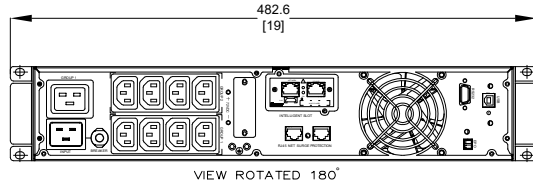

SPECIFICATION:

1. STANDARD:
- | | |
|---------------------------------|--------------------------------------|
| UPS TOPOLOGY: | DOUBLE CONVERSION |
| KVA: | 3 |
| BATTERY TYPE: | VALVE REGULATED LEAD ACID |
| INPUT PLUG: | SCHUKO CEE 7/7 (EU1-16P) AND BS1363A |
| NOMINAL INPUT VOLTAGE: | 220/230/240VAC |
| INPUT PHASE: | SINGLE |
| OUTPUT PHASE: | SINGLE |
| NOMINAL OUTPUT VOLTAGE: | 220/230/240VAC |
| OUTLET TYPE AND QTY: | IEC-C13(8)+IEC-C19(1) SOCKET |
| DISPLAY TYPE: | 2.8 INCH,4 BUTTON |
| PARALLEL PORT SUPPORT: | NO |
| INPUT BREAKER TYPE: | 25A PUSH BUTTON |
| OUTPUT BREAKER TYPE: | N/A |
| WEIGHT OF Pb(LEAD): | 10.2KG |
| WEIGHT OF H2SO4(SULFURIC ACID): | 2.4KG |

2. ADDITIONAL:
NONE

3. ACCESSORY COMPONENTS:
- P/N U03N12V CONTAINS AN INTELLIGENT NETWORK CARD,(INSTALLED)
 - STABILIZER BRACKET,QTY:(4)
 - INSTALLATION EARS,QTY:(2)
 - SAFTY WARNING SHEET,QTY:(1)
 - SELECTION GUIDE(POCKET GUIDE),QTY:(1)
 - DB9/DB9 RS232 1.5M COMMUNICATION CABLE,QTY:(1)
 - USB-A/USB-B 1.2M SERIAL COMMUNICATION CABLE,QTY:(1)
 - INCLUDES P/N:UVC072 INTERNAL BATTERY CARTRIDGE,QTY:(1),(INSTALLED)
 - INCLUDES P/N:URMKIT2 INSTALLATION RAIL KIT, QTY:(1),(U03N12V ONLY)
 - REFER TO ASSOCIATED DRAWINGS FOR PHISICAL DIMENSIONS AND SPECIFICATIONS
 - EPO PLUG WITH SHORTING WIRE,QTY:(1),(INSTALLED)

NOTES:

1. PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSIONS ARE IN INCHES
2. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL,STATE,AND LOCAL CODES
3. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PRODUCT
4. ALL PURCHASED ITEMS CONFORM TO C2-0834 PANDUIT SPECIFICATION FOR CHEMICAL SUBSTANCES TO BE CONTROLLED IN PRODUCT AND PACKAGING

IDENTIFICATION:

PART NUMBER	DESCRIPTION	SHIPPING WEIGHT (KG)
U03S12V	SMARTZONE IRUPS, 3kVA, 2U, 230V, SINGLE PHASE, DOUBLE-CONVERSION ON-LINE POWER PROTECTION	30.5
U03N12V	SMARTZONE IRUPS, 3kVA, 2U, 230V, SINGLE PHASE, DOUBLE-CONVERSION ON-LINE POWER PROTECTION WITH INTELLIGENT NETWORK CARD	35.5

DATE	BY	CHK	APR	DESCRIPTION	ECN
------	----	-----	-----	-------------	-----

SMARTZONE UPS U03S12V/U03N12V CUSTOMER DRAWING					
U03N12V/01 U03N12V-DC/01A					
UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: MM (IN)					
N/A					
THIRD ANGLE PROJECTION					
U03N12V-DC					
DATE	BY	CHK	APR	DESCRIPTION	ECN
08/17/2021	D.A.	ZRK	GJM/DJB	RELEASE TO PRODUCTION	U03N12V
08/17/2021	D.A.	ZRK	GJM/DJB	RELEASE TO PRODUCTION	U03N12V
08/17/2021	D.A.	ZRK	GJM/DJB	RELEASE TO PRODUCTION	U03N12V

PANDUIT

