

Net-Verse™ Cabinets

Versatility Made Simple

BIG DATA

Universal Design Converts Quickly to a Network or Server Cabinet

Net-Verse™ Cabinets

Net-Verse™ Cabinets are the preferred choice for applications that require maximum flexibility in data center, enterprise or colocation deployment.

Data centers are under immense pressure to increase their operational efficiencies and overall operating OpeX ensuring that the data center is operating 24/7 without fail. With increased pressure for premium cabinet solutions within Data Center, Enterprise, and Colocations, there is a need to have a simple cost-effective cabinet solution.

Net-Verse™ Cabinets provides a 16 model offering matching current IT applications. This standard offering matches server, switch and network applications with flexible mounting options.


Fill your data center with versatile cabinets – in the most efficient and cost-effective way – Look no further than Panduit® Net-Verse™ Cabinets.

Features and Benefits:

- Fully adjustable e-rail offers application flexibility
- Optional in-cabinet blanking panels are fully compatible with Panduit Universal Aisle Containment System maximizing airflow and thermal efficiency
- Multi-point locking doors and locking side panels provides enhanced security
- 2 full height multi purpose PDU/cable management brackets for mounting PDUs or lashing cables.
- Load ratings: static – 3000 lbs. (1360 kg); rolling – 1100 lbs. (500 kg)
- Cabinet sizes available: Width: 600mm, 800mm; Depth: 1000mm, 1200mm; Height: 42 RU, 45 RU, 48 RU
- Available in black or white



Integral vertical blanking panels in the 800mm wide cabinet offers 4 zero RU vertical openings that improve floor space utilization by up to 10%

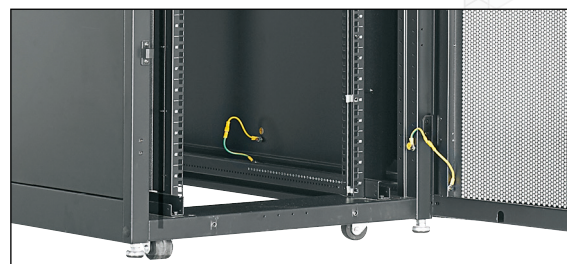

Bonded doors and side panels provide a complete bonded cabinet for protection of equipment and personnel



Fully adjustable equipment rails with easy to read horizontal markings offer application flexibility, allowing you to make a network or server cabinet.



Large brush cable entry minimizes hot air recirculation and allows for large bundles of cables

Data Center

Enterprise

Colocation

Net-Verse™ Cabinet Overview

Class	Net-Verse™ Cabinets
Offering	Fixed
Height	42 RU / 45 RU / 48 RU
Width	600/800mm
Depth	1000/1200mm
Color Options	Black, White
Load Rating	3,000 lbs. 1,360 kg static 1,100 lbs. 500 kg rolling
Doors	69% air flow rate Single hinge front door Split hinge rear doors Two point lock – front door Three point lock – rear door
Lockable Side Panels	Horizontal split side panels for easy secured access
E-rail Mounting	Cage nuts
Hardware	Cage nuts and screws (40 pcs)
Cable Management	Fingers are offered as an accessory for the 800mm wide cabinet
Grounding	Bonding jumpers
Thermal Management Options	Universal aisle containment
Casters	Supplied
PDU Brackets	Supplied for both sides
Roof	Brush cable entry to minimize hot air recirculation

	Net-Verse™ Cabinets	800mm Width	600mm Width	
With Side Panels	42 RU	DN8212*	DN6212*	1000mm Depth
	45 RU	DN8512*	DN6512*	
	48 RU	DN8812*	DN6812*	
	42 RU	DN8222*	DN6222*	1200mm Depth
	45 RU	DN8522*	DN6522*	
	48 RU	DN8822*	DN6822*	
Without Side Panels	42 RU	DN8219*	DN6219*	1000mm Depth
	45 RU	DN8519*	DN6519*	
	48 RU	DN8819*	DN6819*	
	42 RU	DN8229*	DN6229*	1200mm Depth
	45 RU	DN8529*	DN6529*	
	48 RU	DN8829*	DN6829*	

*Available in Black (B) or White (W)

Data Center


Enterprise

Colocation

For service and technical support, call 1-800-PANDUIT. 3

Accessorize

Our line of Net-Verse™ Accessories are designed to supply end users with the options necessary to allow for more cable management and thermal solutions.

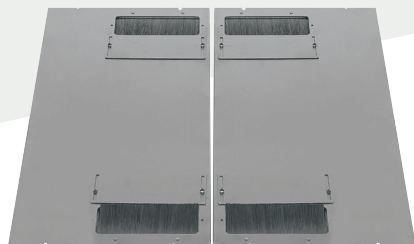

Bottom Cover Plates




Cable Management Fingers and Mounting Brackets for 800mm Cabinet



Vertical Blanking Panels



Side Panels

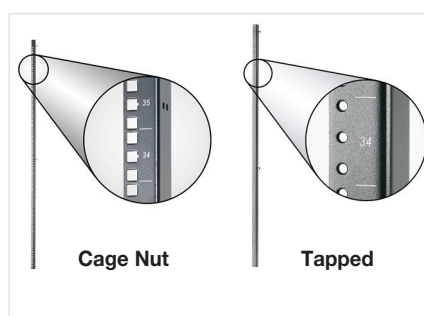

Fully Adjustable Equipment Rails



Front Door



Split Rear Door

Accessories	
Front Door	
42 RU x 600mm	D62FD*
45 RU x 600mm	D65FD*
48 RU x 600mm	D68FD*
42 RU x 800mm	D82FD*
45 RU x 800mm	D85FD*
48 RU x 800mm	D88FD*
Rear Door	
42 RU x 600mm	D62RD*
45 RU x 600mm	D65RD*
48 RU x 600mm	D68RD*
42 RU x 800mm	D82RD*
45 RU x 800mm	D85RD*
48 RU x 800mm	D88RD*
Side Panels	
42 RU x 1000mm	D21SP*
42 RU x 1200mm	D22SP*
45 RU x 1000mm	D51SP*
45 RU x 1200mm	D52SP*
48 RU x 1000mm	D81SP*
48 RU x 1200mm	D82SP*

*Available in Black (B) or White (W)

Accessories	
Bottom Cover Plates	
600mm wide x 1000mm depth	D61BCP*
600mm wide x 1200mm depth	D62BCP*
800mm wide x 1000mm depth	D81BCP*
Cage Nut Equipment Rails	
42 RU – cage nut	D2ER*
45 RU – cage nut	D5ER*
48 RU – cage nut	D8ER*
42 RU – 12-24 tapped	D2ERT*
45 RU – 12-24 tapped	D5ERT*
48 RU – 12-24 tapped	D8ERT*
PDU/Cable Management Bracket	
42 RU	D2CM*
45 RU	D5CM*
48 RU	D8CM*
Cable Management Fingers with Mounting Brackets for 800mm Wide Cabinet	
42 RU	D12FB*
45 RU	D15FB*
48 RU	D18FB*
Vertical Blanking Panels	
600mm	D6VBP*
800mm	D8VBP*