


TG-Style Tools

Some of the most common products manufactured for networking projects are connectors – mainly jacks and plugs. Each module is 100% factory tested for continuity. TG-Style termination eliminates the need for a punchdown termination tool. Each jack is individually serialized for traceability and is compatible with Mini-Com® Modular Patch Panels and Faceplates. Select connectors are offered in bulk packages of 10, 24, and 100 unit packs for faster installation and to reduce single-use plastic.

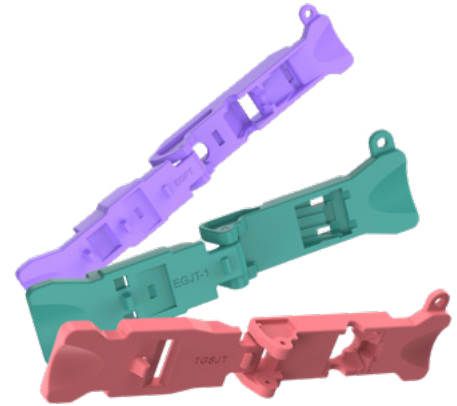

Panduit TG-Style Termination Tool Guide

EGPT Tool	Category 6A	Category 6	Category 5e
Unshielded angled up/down field term plug:	FPUD6X88MTG	–	–
Unshielded straight field term plug:	FP6X88MTG	–	–
Shielded straight field term plug:	FPS6X88MTG	–	–
Unshielded field term splice connector:	FC-ISC	–	–
Tool:	EGPT (Violet)	–	–



EGPT

EGJT-1 Tool	Category 6A	Category 6	Category 5e
Unshielded straight field term plug:	FP6X88MTG	–	–
Unshielded standard TG jack:	CJ6X88TG*	CJ688TG*	CJ5E88TG*
Unshielded shuttered TG jack:	CJH6X88TG*	CJH688TG*	CJH5E88TG*
Unshielded keyed TG jack:	CJK6X88TG*	CJK688TG*	–
Unshielded 28AWG TG jack:	CJT6X88TG*	CJT688TG*	CJT5E88TG*
Unshielded corrosion resistant TG jack:	CJE6X88TG*	–	–
Shielded standard TG jack:	CJS6X88TG*Y	CJS688TG*Y	CJS5E88TGY
Shielded shuttered TG jack:	CJSH6X88TG*Y	CJSH688TG*Y	CJSH5E88TGY
Shielded keyed TG jack:	CJSK6X88TG*	–	–
Shielded 28AWG TG jack:	CJST6X88TG*Y	–	–
Tool:	EGJT-1 (Green)	EGJT-1 (Green)	EGJT-1 (Green)



EGPT

*Color: IW (Off White), WH (White), EI (Electric Ivory), IG (International Gray), AW (Arctic White), BL (Black), BU (Blue), RD (Red), YL (Yellow), GR (Green), OR (Orange) or VL (Violet). For shielded jacks with no designation, color is black (i.e., CJS6X88TGY).

Note: Products may not be available in every color. For more information visit www.panduit.com

Note: All products are backwards compatible to lower performance levels

Note: Visit Panduit.com for bulk pack options to reduce single-use plastic

TG-Style Tools Guide

Panduit TG-Style Termination Tool Guide (continued)

TGSJT Tool	Category 6A	Category 6	Category 5e
<i>Unshielded angled left/right TG jack:</i>	CJLR6X88TG*	–	–
<i>Unshielded angled up/down TG jack:</i>	CJUD6X88TG*	–	–
<i>Unshielded angled left/right wire cap:</i>	CJLRCAPBU-X	CJLRCAPIW-X	–
<i>Unshielded angled up/down wire cap:</i>	CJUDCAPBU-X	CJUDCAPIW-X	–
<i>Shielded angled left/right TG jack:</i>	CJSLR6X88TGY	–	–
<i>Shielded angled up/down TG jack:</i>	CJSUD6X88TGY	–	–
<i>Shielded angled left/right wire cap:</i>	CJSLRCAPBU-X	CJSLRCAPIW-X	–
<i>Shielded angled up/down wire cap:</i>	CJSUDCAPBU-X	CJSUDCAPIW-X	–
Tool:	TGSJT (Red)	TGSJT (Red)	–



TGSJT

*Color: IW (Off White), WH (White), EI (Electric Ivory), IG (International Gray), AW (Arctic White), BL (Black), BU (Blue), RD (Red), YL (Yellow), GR (Green), OR (Orange) or VL (Violet). For shielded jacks with no designation, color is black (i.e., CJS6X88TGY).

Note: Products may not be available in every color. For more information visit www.panduit.com

Note: All products are backwards compatible to lower performance levels

Note: Visit Panduit.com for bulk pack options to reduce single-use plastic

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com

Contact Customer Service by email: cs@panduit.com

or by phone: 800.777.3300

PANDUIT[®]

© 2023 Panduit Corp.
ALL RIGHTS RESERVED.
COFL55-SA-ENG
10/2023