



THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.



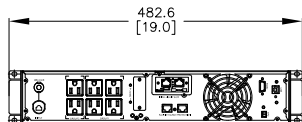


VIEW ROTATED 180°

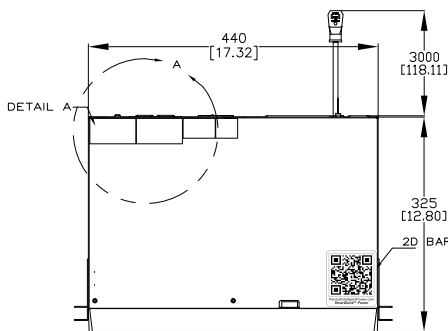

DETAIL A

2D BARCODE LABEL

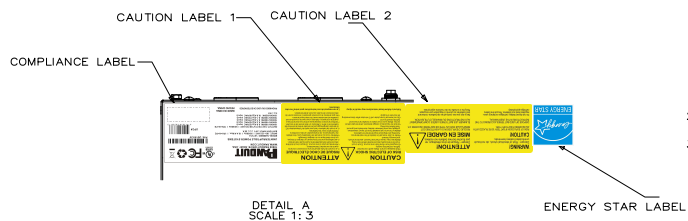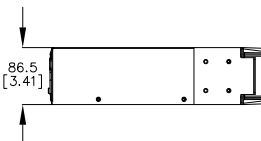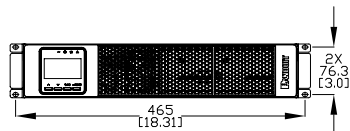

DETAIL A
SCALE 1:3

SPECIFICATION:

- STANDARD:
 - UPS TOPOLOGY: DOUBLE CONVERSION
 - KVA: 1
 - BATTERY TYPE: VALVE REGULATED LEAD ACID
 - FULL-LOAD RUN TIME (MIN): 2.7 MINUTES
 - INPUT PLUG: NEMA 5-15P
 - NOMINAL INPUT VOLTAGE: 100/110/115/120/125VAC
 - INPUT PHASE: SINGLE
 - OUTPUT PHASE: SINGLE
 - NOMINAL OUTPUT VOLTAGE: 100/110/115/120/125VAC
 - OUTLET TYPE AND QTY: NEMA 5-15R(6)
 - DISPLAY TYPE: 2.8 INCH,4 BUTTON
 - PARALLEL PORT SUPPORT: NO
 - INPUT BREAKER TYPE: 16A PUSH BUTTON
 - OUTPUT BREAKER TYPE: N/A
 - WEIGHT OF Pb(LEAD): 3.4KG
 - WEIGHT OF H2SO4(SULFURIC ACID): 0.8KG
- ADDITIONAL: NONE
- ACCESSORY COMPONENTS:
 - P/N U01N13V CONTAINS AN INTELLIGENT NETWORK CARD,(INSTALLED)
 - STABILIZER BRACKET, QTY:(4)
 - INSTALLATION EARS, QTY:(2)
 - SAFETY WARNING SHEET,QTY:(1)
 - SELECTION GUIDE(POCKET GUIDE),QTY:(1)
 - DB9/DB9 RS232 1.5M COMMUNICATION CABLE, QTY:(1)
 - USB-A/USB-B 1.2M SERIAL COMMUNICATION CABLE, QTY:(1)
 - INCLUDES P/N:UVVC024 INTERNAL BATTERY CARTRIDGE, QTY:(1),(INSTALLED)
 - INCLUDES P/N:URMKIT1 INSTALLATION RAIL KIT, QTY:(1),(U01N13V ONLY)
 - REFER TO ASSOCIATED DRAWINGS FOR PHYSICAL DIMENSIONS AND SPECIFICATIONS
 - EPO PLUG WITH SHORTING WIRE,QTY:(1),(INSTALLED)

NOTES:

- PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSIONS ARE IN INCHES
- INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL,STATE,AND LOCAL CODES
- VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PRODUCT
- ALL PURCHASED ITEMS CONFORM TO C2-0834 PANDUIT SPECIFICATION FOR CHEMICAL SUBSTANCES TO BE CONTROLLED IN PRODUCT AND PACKAGING.

IDENTIFICATION:

PART NUMBER	DESCRIPTION	SHIPPING WEIGHT (KG)
U01S13V	SMARTZONE IRUPS, 1000VA, 2U, 120V, SINGLE PHASE, DOUBLE-CONVERSION ON-LINE POWER PROTECTION	17.32
U01N13V	SMARTZONE IRUPS, 1000VA, 2U, 120V, SINGLE PHASE, DOUBLE-CONVERSION ON-LINE POWER PROTECTION WITH INTELLIGENT NETWORK CARD,RAIL KIT,INSTALLATION EARS	20.6

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	DATE	BY	CHK	APR	DESCRIPTION	ECN	DATE	BY	CHK	APR	DESCRIPTION	ECN	
00A	08/17/2021				RELEASE TO PRODUCTION	U01N13V	08/17/2021						08/17/2021						

TITLE: SMARTZONE UPS U01S13V/U01N13V CUSTOMER DRAWING U01S13V/U01N13V/00 U01S13V/U01N13V-DC/00A DIMENSIONAL TOLERANCES SPECIFIED IN (mm)		PANDUIT N/A
00A 08/17/2021 REV DATE BY CHK APR DESCRIPTION ECN	08/17/2021 MLD VARIOUS	U01N13V-DC SHIT 1 OF 2

