

MP75

PXE™ SERIES Mobile Printer

Product Bulletin

Cost-Effective Network and Electrical Functionality



PANDUIT™

EPSON
EXCEED YOUR VISION

PORTABLE LABEL PRINTER PARTNER

PXE™ SERIES Mobile Printers

Do your job smarter, faster and easier with PXE Series Mobile Printers. This full line of advanced identification printers combine Panduit's industry-leading performance and field-tested durability with Epson's world-class printing technology.



MP75 Mobile Label Printer

A reliable and affordable printer for network, electrical, and other industrial applications.

FEATURES:

- Shared MP Cassette Platform
- 180 dpi print resolution
- Custom Application Specific Label Modes
- Large Library of Barcodes and Custom Symbols
- Prints up to 0.75 in wide labels
- Fast 0.25 in/sec Print Speed
- Continuous Label Cassette
- Qwerty Keyboard
- Backlit LCD Screen
- Manual Push Button Cutter

Dimensions

Compact and Lightweight

- Width: 4.33 in (110 mm)
- Depth: 6.70 in (170 mm)
- Height: 2.20 in (56 mm)

Weight: 14 oz (400 g)
(excluding batteries, tape cartridge)

Ordering Information

Part Number	Description
MP75	Compact entry level industrial printer that features custom label modes, a qwerty keyboard, backlit LCD screen, and a large library of barcodes and custom symbols. Includes the lightweight printer, one T075X000VPM-BK continuous label cassette and quick reference card
PTR-CLN	Printer cleaning kit - contains (1) cleaning pen, (8) cleaning solution soaked wipes, (8) foam swabs pre-saturated with cleaning solution, MSDS, and cleaning instructions

PANDUIT™

EPSON

EXCEED YOUR VISION

PORTABLE LABEL PRINTER PARTNER

Epson™ Print Technology

Epson is a global technology leader dedicated to connecting people, things and information with efficient, compact and precision technologies.

Panduit™ Labeling and Software Expertise


Panduit creates leading-edge labeling solutions for electrical and network environments, from the data center to the telecom room, the jobsite to the plant floor.

Ordering Information



Non-Laminated Label Cassettes


- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Non-laminated adhesive labels for wire/cable identification

 Nylon Cloth (C1M)

 -65°F to 275°F (-54°C to 135°C)


Part Number	Part Description	Printer Compatibility				Print-On Area Color	Height		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
T050X000C1M-BK	MP Cassette, Continuous Tape, Nylon Cloth, 0.50" W x 19' L, Black on White	Y	N	Y	Y	Black on White	0.465	11.82	19	6	1	5
T075X000C1M-BK	MP Cassette, Continuous Tape, Nylon Cloth, 0.75" W x 19' L, Black on White						0.702	17.82				

Representative offering only, visit www.panduit.com for complete listing of products.

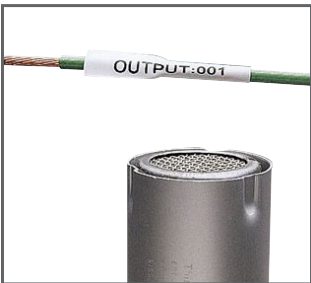

Continuous Heat Shrink Labels

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Non-adhesive flattened heat shrinkable polyolefin for wire/cable identification

 Heat Shrinkable Polyolefin 3:1 Heat Shrink Ratio (H1, H2)

 -40°F to 257°F (-40°C to 125°C)

Part Number	Part Description	Shrink Ratio	Mil Spec	Printer Compatibility				Ribbon & Material Color	Width		Length		Min. Cable O.D.		Max. Cable O.D.		Wire/Cable Size Range	Std. Pkg. Qty.	Std. Ctn. Qty.
				MP75	MP100	MP200	MP300		In.	mm	Ft.	m	In.	mm	In.	mm			
H000X025H1M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .25" W x 8' L, White	3:1	Y	Y	Y	Y	Y	Black on White	0.27	6.8	8.2	2.5	0.06	1.4	0.16	4.1	22 - 18 AWG	1	5
H000X025H2M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .25" W x 8' L, Yellow							Black on Yellow											
H000X034H1M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .34" W x 8' L, White							Black on White	0.37	9.3	0.07	1.9	0.22	5.7	18 - 12 AWG				
H000X034H2M	MP Cassette, Continuous Heat Shrink Tubing, Mil Grade Polyolefin, .34" W x 8' L, Yellow							Black on Yellow											

 
Representative offering only, visit www.panduit.com for complete listing of products.

Ordering Information



Continuous Terminal Block Label Cassettes

- Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Print terminal block labels ranging in size from 0.24 inches to 0.38 inches






Part Number	Part Description	Printer Compatibility				Print-On Area Color	Height		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
T024X000FJM-BK	MP Cassette, Continuous Tape, Polyolefin, 0.24" W x 23' L, Black on White	Y	Y	Y	Y	Black on White	0.229	5.82	23	7	1	5
T038X000FJM-BK	MP Cassette, Continuous Tape, Polyolefin, 0.38" W x 23' L, Black on White						0.347	8.82				

Representative offering only, visit www.panduit.com for complete listing of products.



Continuous Tape Cassettes

   - Fast-loading Label Cassette includes both label material and ribbon to make changing labels easy
- Print custom pipe markers, voltage markers, signs, bin markers, and network ID labels on demand
- For flat label applications only



Part Number	Part Description	Printer Compatibility				Ribbon & Material Color	Width		Length		Std. Pkg. Qty.	Std. Ctn. Qty.
		MP75	MP100	MP200	MP300		In.	mm	Ft.	m		
T038X000VPM-BK	MP Cassette, Continuous Tape, Vinyl, 0.38" W x 23' L, Black on White.	Y	Y	Y	Y	Black on White	0.354	9.0	23	7.0	1	5
T038X000VXM-BK	MP Cassette, Continuous Tape, Vinyl, 0.38" W x 23' L, Black on Yellow.					Black on Yellow						
T038X000YKM-BK	MP Cassette, Continuous Tape, Polyester, 0.38" W x 30' L, Black on Clear.					Black on Clear						
T038X000BYM-WH	MP Cassette, Continuous Tape, Polyester, 0.38" W x 30' L, White on Black.					White on Black						
T050X000VPM-BK	MP Cassette, Continuous Tape, Vinyl, 0.50" W x 23' L, Black on White.					Black on White						
T050X000VXM-BK	MP Cassette, Continuous Tape, Vinyl, 0.50" W x 23' L, Black on Yellow.					Black on Yellow						
T050X000YKM-BK	MP Cassette, Continuous Tape, Polyester, 0.50" W x 30' L, Black on Clear.					Black on Clear						
T050X000BYM-WH	MP Cassette, Continuous Tape, Polyester, 0.50" W x 30' L, White on Black.					White on Black						
T075X000VPM-BK	MP Cassette, Continuous Tape, Vinyl, 0.75" W x 23' L, Black on White.					Black on White	0.710	18.0	23	7.0		
T075X000VXM-BK	MP Cassette, Continuous Tape, Vinyl, 0.75" W x 23' L, Black on Yellow.					Black on Yellow						
T075X000YKM-BK	MP Cassette, Continuous Tape, Polyester, 0.75" W x 30' L, Black on Clear.					Black on Clear						
T075X000BYM-WH	MP Cassette, Continuous Tape, Polyester, 0.75" W x 30' L, White on Black.					White on Black						



Entry-Level Mobile Printer Comparison



FEATURES	MP75	BMP21-PLUS	PT-E110
Price	\$	\$\$	\$
Label Width	0.75 in.	0.75 in.	0.47 in.
Label Offering	★★★★	★★★★★	★★★
Cutter	Manual	Manual	Manual
Barcode, Symbols & File Storage	★★★★★	★★	★
Weight	0.9 lbs.	1.66 lbs.	0.9 lbs.

Competitive comparison based on published specifications.

PXE SERIES

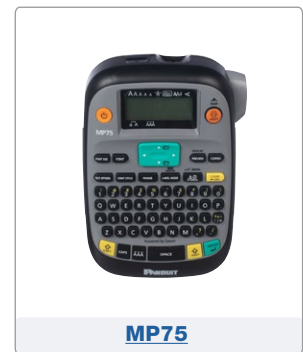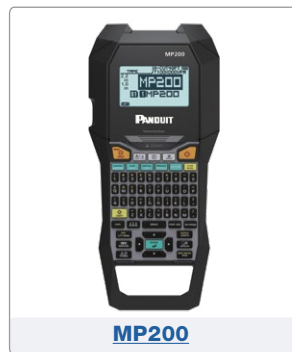

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT CANADA
Markham, Ontario
cs-cdn@panduit.com
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
cs-emea@panduit.com
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
cs-ap@panduit.com
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
cs-japan@panduit.com
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
cs-la@panduit.com
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
cs-aus@panduit.com
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty



For more information
Visit us at www.panduit.com
Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

© 2022 Panduit Corp.
ALL RIGHTS RESERVED.
Printed in the U.S.A.
LITERATURE # IDCB94-SA-ENG
08/2022