

## Industrial Electrical Infrastructure

Preferred Parts – ASEAN

**PANDUIT**<sup>™</sup>

infrastructure for a connected world

# Industrial Electrical Infrastructure

Partner with a company committed to meeting the challenges you face when designing, installing and maintaining cabling infrastructures within heavy-duty industrial environments. Our global distribution, manufacturing, sales and technical support teams make Panduit solutions readily accessible, allowing the right products to be delivered when and where they are needed.

This catalog features the most common offering for heavy-duty industrial environments. For the complete offering, please contact your local Panduit representative or visit us at [www.panduit.com/buildnow](http://www.panduit.com/buildnow).



## Table of Contents

<b>Power Connectors</b> .....	<b>3</b>
<b>Terminals</b> .....	<b>3 – 5</b>
<b>Cable Ties</b> .....	<b>6 – 7</b>
<b>Cable Accessories</b> .....	<b>8</b>
<b>Stainless Steel and Permanent Identification</b> .....	<b>8 – 9</b>
<b>Safety Products</b> .....	<b>9</b>
<b>Computer Printables</b> .....	<b>10</b>
<b>Labeling Systems</b> .....	<b>10</b>
<b>Abrasion Protection</b> .....	<b>11</b>
<b>Wiring Duct</b> .....	<b>11</b>

## Power Connectors



One-Hole Standard Barrel Lug



Two-Hole Long Barrel Lug



One-Hole Aluminum Mechanical Lug



CT-930

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>One-Hole Standard Barrel Lug</b>			
LCMA6-6-C	Copper compression metric lug, one-hole, 4 – 6mm <sup>2</sup> wire, M6 stud.	100	—
LCMA6-8-C	Copper compression metric lug, one-hole, 4 – 6mm <sup>2</sup> wire, M8 stud.	100	—
LCMA10-6-C	Copper compression metric lug, one-hole, 10mm <sup>2</sup> wire, M6 stud.	100	—
LCMA16-6-C	Copper compression metric lug, one-hole, 16mm <sup>2</sup> wire, M6 stud.	100	—
LCMA16-8-C	Copper compression metric lug, one-hole, 16mm <sup>2</sup> wire, M8 stud.	100	—
LCMA16-10-C	Copper compression metric lug, one-hole, 16mm <sup>2</sup> wire, M10 stud.	100	—
LCMA25-6-C	Copper compression metric lug, one-hole, 25mm <sup>2</sup> wire, M6 stud.	100	—
LCMA25-8-C	Copper compression metric lug, one-hole, 25mm <sup>2</sup> wire, M8 stud.	100	—
LCMA25-10-C	Copper compression metric lug, one-hole, 25mm <sup>2</sup> wire, M10 stud.	100	—
LCMA35-10-C	Copper compression metric lug, one-hole, 35mm <sup>2</sup> wire, M10 stud.	100	—
LCMA70-8-L	Copper compression metric lug, one-hole, 70mm <sup>2</sup> wire, M8 stud.	50	—
LCMA70-10-L	Copper compression metric lug, one-hole, 70mm <sup>2</sup> wire, M10 stud.	50	—
LCMA70-12-L	Copper compression metric lug, one-hole, 70mm <sup>2</sup> wire, M12 stud.	50	—
LCMA95-10-L	Copper compression metric lug, one-hole, 95mm <sup>2</sup> wire, M10 stud.	50	—
LCMA120-12-L	Copper compression metric lug, one-hole, 120mm <sup>2</sup> wire, M12 stud.	50	—
LCMA150-12-X	Copper compression metric lug, one-hole, 150mm <sup>2</sup> wire, M12 stud.	10	—
<b>One-Hole Short Barrel Lug</b>			
LCAS6-14-L	Copper compression lug, one-hole, #6 AWG, short barrel, 1/4" (6.4mm) stud.	50	—
LCAS6-14F-L	Copper compression lug, one-hole, #6 AWG, short barrel, 1/4" (6.4mm) stud, 90° bent.	50	—
<b>Two-Hole Standard Barrel Lug</b>			
LCD6-14A-L	Copper compression lug standard barrel, two-hole, #6 AWG, 1/4" (6.4mm) stud, 0.63" (16mm) hole spacing.	50	—
LCD6-14AF-L	Copper compression lug standard barrel, two-hole, #6 AWG, 1/4" (6.4mm) stud, 90° bent.	50	—
LCD1/0-14A-X	Copper compression lug standard barrel, two-hole, 1/0 AWG, 1/4" (6.4mm) stud, 0.63" (16mm) hole spacing.	10	—
<b>Two-Hole Long Barrel Lug</b>			
LCC4-14AWH-L	Copper compression lug, two-hole, #4 – #3 AWG STR, #2 AWG SOL, 1/4" (6.4mm) stud, 45° bent.	50	—
LCC750-12-6	Copper compression lug, two-hole, 750 kcmil, 1/2" (12.7mm) Stud, 1.75" (44.5mm) hole spacing.	6	—
<b>Aluminum Mechanical Lug</b>			
LAMA6-14-QY	Aluminum mechanical lug, one-hole, one barrel, #14 – #6 AWG, 1/4" (6.4mm) stud.	25	—
<b>Installation Tool</b>			
CT-930	Manual hydraulic crimping tool, die type, 14 ton.	1	—

## Terminals



Butt Splice Vinyl Insulated

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Butt Splices</b>			
BSN14-C	Butt splice, nylon insulated, 16 – 14 AWG	100	1000
BSV18X-MY	Butt splice, vinyl insulated, 22 – 18 AWG.	1000	—
BSV14X-M	Butt splice, vinyl insulated, 16 – 14 AWG.	1000	6000

(continued on page 4)

Terminals (continued)



Disconnects

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Disconnects</b>			
DNF18-111FIB-M	Female disconnect, nylon fully insulated, 22 – 18 AWG, 0.110 x 0.020 tab size, funnel entry.	1000	6000
DNF18-187FIB-M	Female disconnect, nylon fully insulated, 22 – 18 AWG, 0.187 x 0.032 tab size, funnel entry.	1000	—
DNF18-205FIB-M	Female disconnect, nylon fully insulated, 22 – 18 AWG, 0.187/.205 x 0.032 tab size, funnel entry.	1000	6000
DNF18-206FIB-M	Female disconnect, nylon fully insulated, 22 – 18 AWG, 0.187/.205 x 0.020 tab size, funnel entry.	1000	6000
DNF18-250FIB-M	Female disconnect, nylon fully insulated, 22 – 18 AWG, 0.250 x 0.032 tab size, funnel entry.	1000	—
DNF14-187FIB-M	Female disconnect, nylon fully insulated, 16 – 14 AWG, 0.187 x 0.032 tab size, funnel entry.	1000	—
DNF14-250FIB-M	Female disconnect, nylon fully insulated, 16 – 14 AWG, 0.250 x 0.032 tab size, funnel entry.	1000	—
DNF10-250FI-D	Female disconnect, nylon fully insulated, metal sleeve, 12 – 10 AWG, 0.250 x 0.032 tab size, funnel entry.	500	3000
DNF10-250FIB-D	Female disconnect, nylon fully insulated, 12 – 10 AWG, 0.250 x 0.032 tab size, funnel entry.	500	—
DPF18-250FIB-M	Female disconnect, premium nylon fully insulated, 22 – 18 AWG, 0.250 x 0.032 tab size, funnel entry.	1000	6000
DPF14-250FIB-M	Female disconnect, premium nylon fully insulated, 16 – 14 AWG, 0.250 x 0.032 tab size, funnel entry.	1000	—
DNFR18-206FIB-M	Female disconnect, right angle, nylon fully insulated, 22 – 18 AWG, 0.187/.205 x 0.020 tab size, funnel entry.	1000	6000
DNFR18-250FIB-M	Female disconnect, right angle, nylon fully insulated, 22 – 18 AWG, 0.250 x 0.032 tab size, funnel entry.	1000	6000
DNFR14-250FIB-M	Female disconnect, right angle, nylon fully insulated, 16 – 14 AWG, 0.250 x 0.032 tab size, funnel entry.	1000	6000
DNF18-250FIM-M	Male disconnect, nylon fully insulated, 22 – 18 AWG, 0.250 x 0.032 tab size.	1000	6000
DNF14-250FIM-M	Male disconnect, nylon fully insulated, 16 – 14 AWG, 0.250 x 0.032 tab size.	1000	—



Fork Terminals

<b>Fork Terminals</b>			
PN18-6F-M	Fork terminal, nylon insulated, 22 – 18 AWG, #6 stud size.	1000	—
PV18-8LF-MY	Locking fork terminal, vinyl insulated, 22 – 18 AWG, #8 stud size, funnel entry.	1000	—
PV14-6F-M	Fork terminal, vinyl insulated, 16 – 14 AWG, #6 stud size, funnel entry.	1000	6000
PV14-6FN-M	Fork terminal, narrow tongue, vinyl insulated, 16 – 14 AWG, #6 stud size, funnel entry.	1000	—
PV14-6LFW-M	Locking fork terminal, wide tongue, vinyl insulated, 18 – 14 AWG, #6 stud size, funnel entry.	1000	6000



Insulated Ferrules

<b>Insulated Ferrules</b>			
FSD74-8-D	Insulated ferrule, single wire, 22 AWG (0.34mm <sup>2</sup> ), 0.31" (8.0mm) pin length, Turquoise DIN end sleeve.	500	—
FSD76-8-D	Insulated ferrule, single wire, 18 AWG (1.0mm <sup>2</sup> ), 0.31" (8.0mm) pin length, Gray DIN end sleeve.	500	—
FSD77-8-D	Insulated ferrule, single wire, 18 AWG (1.0mm <sup>2</sup> ), 0.31" (8.0mm) pin length, Red DIN end sleeve.	500	—
FSD77-12-D	Insulated ferrule, single wire, 18 AWG (1.0mm <sup>2</sup> ), 0.47" (12.0mm) pin length, Red DIN end sleeve.	500	—
FSD78-8-D	Insulated ferrule, single wire, 16 AWG (1.5mm <sup>2</sup> ), 0.31" (8.0mm) pin length, Black DIN end sleeve.	500	—
FSD78-12-D	Insulated ferrule, single wire, 16 AWG (1.5mm <sup>2</sup> ), 0.47" (12.0mm) pin length, Black DIN end sleeve.	500	—
FSD80-8-D	Insulated ferrule, single wire, 14 AWG (2.5mm <sup>2</sup> ), 0.31" (8.0mm) pin length, Blue DIN end sleeve.	500	—
FSD80-12-D	Insulated ferrule, single wire, 14 AWG (2.5mm <sup>2</sup> ), 0.47" (12.0mm) pin length, Blue DIN end sleeve.	500	—
FSD81-12-C	Insulated ferrule, single wire, 12 AWG (4.0mm <sup>2</sup> ), 0.47" (12.0mm) pin length, Gray DIN end sleeve.	100	—
FSD82-12-C	Insulated ferrule, single wire, 10 AWG (6.0mm <sup>2</sup> ), 0.47" (12.0mm) pin length, Yellow DIN end sleeve.	100	—
FSD83-12-C	Insulated ferrule, single wire, 8 AWG (10.0mm <sup>2</sup> ), 0.47" (12.0mm) pin length, Red DIN end sleeve.	100	—
FSD84-12-C	Insulated ferrule, single wire, 6 AWG (16.0mm <sup>2</sup> ), 0.47" (12.0mm) pin length, Blue DIN end sleeve.	100	—
FSD85-18-L	Insulated ferrule, single wire, 4 AWG (25.0mm <sup>2</sup> ), 0.71" (18.0mm) pin length, Yellow DIN end sleeve.	50	—

(continued on page 5)

## Terminals (continued)



Pin Terminals



Ring Terminals

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Pin Terminals</b>			
PV18-P47-CY	Pin terminal, vinyl insulated, 22 – 18 AWG, 0.49 pin length.	100	1000
PV14-P47-C	Pin terminal, vinyl insulated, 16 – 14 AWG, 0.49 pin length.	100	1000
PV10-P55-LY	Pin terminal, vinyl insulated, 12 – 10 AWG, 0.55 pin length.	50	500
<b>Ring Terminal</b>			
P10-14R-D	Ring terminal, non-insulated, 14 – 10 AWG, 1/4" stud size.	500	5000
P8-56R-T	Ring terminal, large wire, non-insulated, 8 AWG, 5/16" stud size.	200	—
PN18-6R-C	Ring terminal, nylon insulated, 22 – 18 AWG, #6 stud size.	100	500
PN18-6R-M	Ring terminal, nylon insulated, 22 – 18 AWG, #6 stud size.	1000	—
PN18-8R-M	Ring terminal, nylon insulated, 22 – 18 AWG, #8 stud size.	1000	—
PN18-14R-C	Ring terminal, nylon insulated, 22 – 18 AWG, 1/4" stud size.	100	500
PN14-8R-M	Ring terminal, nylon insulated, 18 – 14 AWG, #8 stud size.	1000	—
PN14-10R-M	Ring terminal, nylon insulated, 18 – 14 AWG, #10 stud size.	1000	—
PN10-8R-D	Ring terminal, nylon insulated, 12 – 10 AWG, #8 stud size.	500	—
PN10-10R-D	Ring terminal, nylon insulated, 12 – 10 AWG, #10 stud size.	500	—
PN10-14R-D	Ring terminal, nylon insulated, 12 – 10 AWG, 1/4" stud size.	500	—
PNF18-8R-M	Ring terminal, nylon insulated, 22 – 18 AWG, #8 stud size, funnel entry.	1000	—
PNF18-10R-M	Ring terminal, nylon insulated, 22 – 18 AWG, #10 stud size, funnel entry.	1000	—
PNF10-10R-D	Ring terminal, nylon insulated, 12 – 10 AWG, #10 stud size, funnel entry.	500	—
PNF10-14R-L	Ring terminal, nylon insulated, 12 – 10 AWG, 1/4" stud size, funnel entry.	50	500
PV18-6R-CY	Ring terminal, vinyl insulated, 22 – 18 AWG, #6 stud size, funnel entry.	100	500
PV18-8R-MY	Ring terminal, vinyl insulated, 22 – 18 AWG, #8 stud size, funnel entry.	1000	—
PV14-6R-M	Ring terminal, vinyl insulated, 16 – 14 AWG, #6 stud size, funnel entry.	1000	6000
PV14-8R-M	Ring terminal, vinyl insulated, 16 – 14 AWG, #8 stud size, funnel entry.	1000	—
PV14-14R-M	Ring terminal, vinyl insulated, 16 – 14 AWG, 1/4" stud size, funnel entry.	1000	6000
PV10-6R-D	Ring terminal, vinyl insulated, 12 – 10 AWG, #6 stud size, funnel entry.	500	—
PV10-8R-D	Ring terminal, vinyl insulated, 12 – 10 AWG, #8 stud size, funnel entry.	500	—
PV10-10R-D	Ring terminal, vinyl insulated, 12 – 10 AWG, #10 stud size, funnel entry.	500	—
PV10-14R-D	Ring terminal, vinyl insulated, 12 – 10 AWG, 1/4" stud size, funnel entry.	500	3000
PV6-14R-T	Ring terminal, large wire, vinyl insulated, 6 AWG, 1/4" stud size.	200	1200
PK10-10R-L	Ring terminal, KYNAR insulated, 12 – 10 AWG, #10 stud size.	50	500

### Installation Tools



CT-100A



CT-1002

CT-100A	Crimp tool, plier type, crimps Panduit terminals, disconnects, and splices. Cuts screws; strips and cuts wire.	1	—
CT-1002	Ferrule crimp tool, controlled cycle, crimps Panduit insulated and non-insulated ferrules.	1	—
CT-1123	Ferrule square profile crimp tool, controlled cycle, crimps Panduit insulated and non-insulated ferrules.	1	—
CT-1525	Crimp tool, controlled cycle, crimps Panduit insulated terminals, disconnects, and splices.	1	—
CT-1550	Crimp tool, controlled cycle, crimps Panduit insulated terminals, disconnects, and splices.	1	—
CT-1570	Crimp tool, controlled cycle, crimps Panduit non-insulated terminals, disconnects, splices and lugs.	1	—

## Cable Ties



Nylon Cable Ties



Weather Resistant Cable Ties

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Subminiature Cable Ties</b>			
PLT.6SM-M	Cable tie, 2.8"L (71mm), Subminiature, nylon, Natural. 1.8mm width.	1000	50000
PLT.6SM-M0	Cable tie, 2.8"L (71mm), Subminiature, weather resistant, Black. 1.8mm width.	1000	50000
<b>Miniature Cable Ties</b>			
PLT.7M-M	Cable tie, 3.1"L (79mm), Miniature, nylon, Natural. 2.3mm width.	1000	50000
PLT.7M-M0	Cable tie, 3.1"L (79mm), Miniature, weather resistant, Black. 2.3mm width.	1000	50000
PLT1M-C0	Cable tie, 3.9"L (99mm), Miniature, weather resistant, Black. 2.5mm width.	100	1000
PLT1M-M	Cable tie, 3.9"L (99mm), Miniature, nylon, Natural. 2.5mm width.	1000	50000
PLT1M-M0	Cable tie, 3.9"L (99mm), Miniature, weather resistant, Black. 2.5mm width.	1000	50000
PLT1M-M00	Cable tie, 3.9"L (99mm), Miniature, Military Specification, weather resistant, Black. 2.5mm width.	1000	50000
PLT1M-M2	Cable tie, 3.9"L (99mm), Miniature, nylon, Red. 2.5mm width.	1000	50000
PLT1M-M6	Cable tie, 3.9"L (99mm), Miniature, nylon, Blue. 2.5mm width.	1000	50000
PLT1M-M8	Cable tie, 3.9"L (99mm), Miniature, nylon, Gray. 2.5mm width.	1000	50000
PLT1.5M-C	Cable tie, 5.6"L (142mm), Miniature, nylon, Natural. 2.5mm width.	100	1000
PLT1.5M-M	Cable tie, 5.6"L (142mm), Miniature, nylon, Natural. 2.5mm width.	1000	50000
PLT1.5M-M0	Cable tie, 5.6"L (142mm), Miniature, weather resistant, Black. 2.5mm width.	1000	50000
PLT1.5M-M20	Cable tie, 5.6"L (142mm), Miniature, nylon, Black. 2.5mm width.	1000	50000
PLT2M-M	Cable tie, 8.0"L (203mm), Miniature, nylon, Natural. 2.5mm width.	1000	25000
PLT2M-M0	Cable tie, 8.0"L (203mm), Miniature, weather resistant, Black. 2.5mm width.	1000	25000
<b>Intermediate Cable Ties</b>			
PLT1.5I-C	Cable tie, 5.6"L (142mm), Intermediate, nylon, Natural. 3.6mm width.	100	1000
PLT1.5I-M	Cable tie, 5.6"L (142mm), Intermediate, nylon, Natural. 3.6mm width.	1000	25000
PLT1.5I-M0	Cable tie, 5.6"L (142mm), Intermediate, weather resistant, Black. 3.6mm width.	1000	25000
PLT1.5I-M20	Cable tie, 5.6"L (142mm), Intermediate, nylon, Black. 3.6mm width.	1000	25000
PLT1.5I-M120	Cable tie, 5.6"L (142mm), Intermediate, nylon 12, Black. 3.6mm width.	1000	25000
PLT2I-M	Cable tie, 8.0"L (203mm), Intermediate, nylon, Natural. 3.6mm width.	1000	25000
PLT2I-M0	Cable tie, 8.0"L (203mm), Intermediate, weather resistant, Black. 3.6mm width.	1000	25000
PLT2I-M20	Cable tie, 8.0"L (203mm), Intermediate, nylon, Black. 3.6mm width.	1000	25000
PLT2.5I-M0	Cable tie, 9.7"L (246mm), Intermediate, weather resistant, Black. 3.7mm width.	1000	10000
PLT3I-M	Cable tie, 11.4"L (290mm), Intermediate, nylon, Natural. 3.7mm width.	1000	10000
PLT3I-M0	Cable tie, 11.4"L (290mm), Intermediate, weather resistant, Black. 3.7mm width.	1000	10000
PLT4I-M	Cable tie, 14.5"L (368mm), Intermediate, nylon, Natural. 3.7mm width.	1000	10000
<b>Standard Cable Ties</b>			
PLT1.5S-M	Cable tie, 6.2"L (157mm), Standard, nylon, Natural. 4.8mm width.	1000	10000
PLT2S-M	Cable tie, 7.4"L (188mm), Standard, nylon, Natural. 4.8mm width.	1000	10000
PLT2S-M0	Cable tie, 7.4"L (188mm), Standard, weather resistant, Black. 4.8mm width.	1000	10000
PLT2S-M00	Cable tie, 7.4"L (188mm), Standard, Military specification, weather resistant, Black. 4.8mm width.	1000	10000
PLT2S-M120	Cable tie, 7.4"L (188mm), Standard, nylon 12, Black. 4.8mm width.	1000	10000
PLT2S-M4Y	Cable tie, 7.4"L (188mm), Standard, nylon, Yellow. 4.8mm width.	1000	10000
PLT2.5S-M	Cable tie, 9.8"L (249mm), Standard, nylon, Natural. 4.8mm width.	1000	10000
PLT2.5S-M0	Cable tie, 9.8"L (249mm), Standard, weather resistant, Black. 4.8mm width.	1000	10000
PLT3S-C	Cable tie, 11.5"L (292mm) Standard, nylon, Natural. 4.8mm width.	100	1000
PLT3S-M	Cable tie, 11.5"L (292mm) Standard, nylon, Natural. 4.8mm width.	1000	10000
PLT3S-M0	Cable tie, 11.5"L (292mm) Standard, weather resistant, Black. 4.8mm width.	1000	10000
PLT3S-M4Y	Cable tie, 11.5"L (292mm) Standard, nylon, Yellow. 4.8mm width.	1000	10000
PLT4S-M	Cable tie, 14.5"L (368mm), Standard, nylon, Natural. 4.8mm width.	1000	5000
PLT4S-M0	Cable tie, 14.5"L (368mm), Standard, weather resistant, Black. 4.8mm width.	1000	5000
<b>Light-Heavy Cable Ties</b>			
PLT4H-TL0	Cable tie, 14.5"L (368mm), Light-Heavy, weather resistant, Black. 7.6mm width.	250	2500
<b>Heavy Cable Tie</b>			
SG450H-L0	Cable tie, SG Series, 18.6"L (471mm), Heavy, weather resistant, Black. 9.7mm width.	50	500
<b>Extra-Heavy Cable Ties</b>			
PLT8EH-Q0	Cable tie, 28.3"L (719mm), Extra-Heavy, weather resistant, Black. 12.7mm width.	25	250

(continued on page 7)

## Cable Ties (continued)

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Heat Stabilized Cable Ties</b>			
PLT1M-M30	Cable tie, 3.9"L (99mm), Miniature, heat stabilized, Black. 2.5mm width.	1000	50000
PLT1M-M300	Cable tie, 3.9"L (99mm), Miniature, heat stabilized, weather resistant, Black. 2.5mm width.	1000	50000
PLT1.5M-M30	Cable tie, 5.6"L (142mm), Miniature, heat stabilized, Black. 2.5mm width.	1000	50000
PLT2M-M30	Cable tie, 8.0"L (203mm), Miniature, heat stabilized, Black. 2.5mm width.	1000	25000
PLT2S-M30	Cable tie, 7.4"L (188mm), Standard, heat stabilized, Black. 4.8mm width.	1000	10000
PLT2S-M300	Cable tie, 7.4"L (188mm), Standard, heat stabilized, weather resistant, Black. 4.8mm width.	1000	10000
PLT2.5S-M30	Cable tie, 9.8"L (249mm), Standard, heat stabilized, Black. 4.8mm width.	1000	10000
PLT4S-M300	Cable Tie, 14.5"L (368mm), Standard, heat stabilized, weather resistant, Black. 4.8mm width.	1000	5000



Polypropylene Cable Ties

<b>Polypropylene Cable Ties</b>			
PLT1M-M109	Cable tie, 3.9"L (99mm), Miniature, polypropylene, Green. 2.5mm width.	1000	50000
PLT2S-M109	Cable tie, 7.4"L (188mm), Standard, polypropylene, Green. 4.8mm width.	1000	10000



Metal Barb Tie

<b>Flame Retardant Cable Ties</b>			
PLT1M-M69	Cable tie, 3.9"L (99mm), Miniature, nylon, flame retardant, Ivory. 2.5mm width.	1000	25000
PLT1.5I-M69	Cable tie, 5.6"L (142mm), Intermediate, flame retardant, Ivory. 3.6mm width.	1000	25000
PLT2I-M69	Cable tie, 8.0"L (203mm), Intermediate, flame retardant, Ivory. 3.6mm width.	1000	25000
PLT2S-M60	Cable tie, 7.4"L (188mm), Standard, flame retardant, Black. 4.8mm width.	1000	10000
PLT2S-M69	Cable tie, 7.4"L (188mm), Standard, flame retardant, Ivory. 4.8mm width.	1000	10000

<b>Metal Barb Ties</b>			
BT1M-M	Cable tie, metal barb, 4.0"L (102mm), Miniature, nylon, Natural. 2.4mm width.	1000	50000
BT1M-M0	Cable tie, metal barb, 4.0"L (102mm), Miniature, weather resistant, Black. 2.4mm width.	1000	50000
BT1.5I-M	Cable tie, metal barb, 6.1"L (155mm), Intermediate, nylon, Natural. 3.6mm width.	1000	25000
BT1.5I-M0	Cable tie, metal barb, 6.1"L (155mm), Intermediate, weather resistant, Black. 3.6mm width.	1000	25000
BT2I-M0	Cable tie, metal barb, 8.0"L (203mm), Intermediate, weather resistant, Black. 3.6mm width.	1000	25000
BT2S-M	Cable tie, metal barb, 8.0"L (203mm), Standard, nylon, Natural. 4.7mm width.	1000	10000
BT2S-M0	Cable tie, metal barb, 8.0"L (203mm), Standard, weather resistant, Black. 4.7mm width.	1000	10000
BT2S-M30	Cable tie, metal barb, 8.0"L (203mm), Standard, heat stabilized, Black. 4.7mm width.	1000	10000
BT4LH-TL0	Cable tie, metal barb, 14.9"L (378mm), Light-Heavy, weather resistant, Black. 7mm width.	250	2500
BT5LH-C0	Cable tie, metal barb, 18.1"L (460mm), Light-Heavy, weather resistant, Black. 7mm width.	100	2000

<b>Clamp Cable Ties</b>			
PLC1M-S4-C	Clamp Tie, 4.3"L (109mm), #4 (M2.5) Screw, Miniature, Nylon, Natural. 2.5mm width.	100	1000
PLC1.5I-S8-M	Clamp Tie, 6.1"L (155mm), #8 (M4) Screw, Intermediate, Nylon, Natural. 3.4mm width.	1000	25000

<b>Marker Cable Ties</b>			
PLM1M-C	Marker Tie, Wrap, 3.9"L (99mm), Miniature, Nylon, Natural. 2.5mm width.	100	1000
PLM1M-M	Marker Tie, Wrap, 3.9"L (99mm), Miniature, Nylon, Natural. 2.5mm width.	1000	25000
PLF1M-C	Marker Tie, Flag, 4.3"L (109mm), Miniature, Nylon, Natural. 2.5mm width.	100	1000
PLF1M-M	Marker Tie, Flag, 4.3"L (109mm), Miniature, Nylon, Natural. 2.5mm width.	1000	25000



Wing Push Mount Cable Tie

<b>Push Mount Ties</b>			
PLP1S-M	Push mount tie, 5.3"L (135mm), Standard, nylon, Natural. 4.6mm width.	1000	10000
PLP2S-M	Push mount tie, 7.9"L (200mm), Standard, nylon, Natural. 4.6mm width.	1000	10000

<b>Wing Push Mount Cable Tie</b>			
PLWP1M-D	Wing push mount tie, 4.3"L (109mm), Miniature, nylon, Natural. 2.5mm width.	500	5000
PLWP1M-D0	Wing push mount tie, 4.3"L (109mm), Miniature, weather resistant, Black. 2.5mm width.	500	5000
PLWP1SB-D	Wing push mount tie, 5.2"L (132mm), Standard, nylon, Natural. 4.8mm width.	500	5000
PLWP1S-D	Wing push mount tie, 5.2"L (132mm), Standard, nylon, Natural. 4.8mm width.	500	5000
PLWP1.5I-D30	Wing push mount tie, 6.0"L (152mm), Intermediate, heat stabilized, Black. 3.4mm width.	500	5000
PLWP1.5I-D	Wing push mount tie, 6.0"L (152mm), Intermediate, nylon, Natural. 3.4mm width.	500	5000
PLWP2S-D	Wing push mount tie, 7.8"L (198mm), Standard, nylon, Natural. 4.8mm width.	500	5000
PRWP1.5S-D	Wing push mount tie, releasable, 6.8"L (173mm), Standard, nylon, Natural. 4.8mm width.	500	5000

<b>Releasable Cable Ties</b>			
PRT1S-M0	Cable tie, releasable, 4.8"L (122mm), Standard, weather resistant, Black. 4.8mm width.	1000	10000
PRT2S-M	Cable tie, releasable, 7.4"L (188mm), Standard, nylon, Natural. 4.8mm width.	1000	10000



GTS

<b>Installation Tools</b>			
GS2B	Cable tie tool for Miniature, Intermediate, Standard ties, adjustable tension.	1	—
GS4H	Cable tie tool for Standard, Heavy-Standard, Light-Heavy, Heavy ties, adjustable tension.	1	—
GTH	Ergonomic cable tie tool for Standard, Heavy-Standard, Light-Heavy, Heavy ties, adjustable tension.	1	—
GTS	Ergonomic cable tie tool for Subminiature, Miniature, Intermediate, Standard ties, adjustable tension.	1	—
GTSL	Ergonomic cable tie tool for Subminiature, Miniature, Intermediate, Standard ties, small handle span, adjustable tension.	1	—

## Cable Accessories



ABM Series



TM Series



PM2H25-M

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Cable Tie Mounts</b>			
ABM1M-A-M	Cable tie mount, adhesive, 0.50" x 0.50" (12.7mm x 12.7mm), White.	1000	5000
ABMM-A-C	Cable tie mount, adhesive, 0.75" x 0.75" (19.1mm x 19.1mm), White.	100	500
ABMM-A-D	Cable tie mount, adhesive, 0.75" x 0.75" (19.1mm x 19.1mm), White.	500	5000
ABM100-A-D	Cable tie mount, adhesive, 1" x 1" (25.4mm x 25.4mm), White.	500	5000
ABM2S-A-D	Cable tie mount, adhesive, 1" x 1" (25.4mm x 25.4mm), White.	500	5000
ABMM-AT-D	Cable tie mount, high temperature adhesive, 0.75" x 0.75" (19.1mm x 19.1mm), White.	500	5000
ABM100-AT-C	Cable tie mount, high temperature adhesive, 1" x 1" (25.4mm x 25.4mm), White.	100	1000
<b>Cable Tie Mounts – TM Series</b>			
TM1S6-M	Cable tie mount, 0.32" (8.1mm) W, #6 screw (M3), nylon.	1000	5000
TM2S6-M0	Cable tie mount, 0.43" (10.9mm) W, #6 screw (M3), weather resistant nylon.	1000	5000
TM2S8-M	Cable tie mount, 0.43" (10.9mm) W, #8 screw (M4), nylon.	1000	5000
TM2S8-M69	Cable tie mount, 0.43" (10.9mm) W, #8 screw (M4), flame retardant nylon.	1000	5000
TM3S10-C	Cable tie mount, 0.62" (15.8mm) W, #10 screw (M5), nylon.	100	500
TM3S10-C0	Cable tie mount, 0.62" (15.8mm) W, #10 screw (M5), weather resistant nylon.	100	500
TM3S10-M	Cable tie mount, 0.62" (15.8mm) W, #10 screw (M5), nylon.	1000	5000
TM3S25-C0	Cable tie mount 0.62" (15.8mm) W, 1/4 screw, weather resistant nylon.	100	500
TM3S25-M	Cable tie mount, 0.62" (15.8mm) W, 1/4 screw, nylon.	1000	5000
TMEH-S10-C0	Cable tie mount, Extra-Heavy, #10 screw (M5), weather resistant nylon.	100	500
TMEH-S25-C0	Cable tie mount, Extra-Heavy, 1/4 screw, weather resistant nylon.	100	500
FCM1-A-C14	Flat cable mount, adhesive, 1" (25.4mm) W cable.	100	500
FCM2-A-C14	Flat cable mount, adhesive, 2" (50.8mm) W cable.	100	500
PM2H25-M	Cable tie mount, push mount, Natural.	1000	5000
PUM-071-M30	Fir tree push mount, 0.25" – 0.28" (6.3mm – 7.1mm) panel hole diameter range, heat stabilized, Black.	1000	5000
PWMS-H25-M	Cable tie mount, winged push mount, Natural.	1000	5000
TA1S8-C	Tie anchor mount, #8 screw (M4).	100	500
TA1S8-M	Tie anchor mount, #8 screw (M4).	1000	5000
AJC31-A-C	Cord clip, adhesive, 0.31" (7.9mm) bundle, Gray.	100	1000
FCC-A-D8	Flat cable clip, adhesive, any width.	500	5000
LC3-A-C8	Latching clip, adhesive, 0.20 (5.1mm) square inch bundle.	100	1000
CCS19-S8-M	Fixed diameter clamp, 0.19" (4.8mm) bundle, #8 screw (M4), White.	1000	5000
CCS25-S8-M	Fixed diameter clamp, 0.25" (6.4mm) bundle, #8 screw (M4), White.	1000	5000

## Stainless Steel Cable Ties and Permanent Identification



Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>I-Series Stainless Steel Strapping</b>			
IMS9.5T35-QR6L	316L stainless steel strapping, 9.5mm (0.37"), 25 meter roll.	1	—
IMS12T35-QR6L	316L stainless steel, strapping 12mm (0.47"), 25 meter roll.	1	—
IMS16T35-QR6L	316L stainless steel, strapping 16mm (0.63"), 25 meter roll.	1	—
IMS19T75-QR6L	316L stainless steel, strapping 19mm (0.75"), 25 meter roll.	1	—
IMSP9.5T35-QR6L	316L stainless steel, strapping epoxy FC, 9.5mm (0.37"), 25 meter roll.	1	—
IMSP12T35-QR6L	316L stainless steel, strapping epoxy FC, 12mm (0.47"), 25 meter roll.	1	—
IMSP16T35-QR6L	316L stainless steel, strapping epoxy FC, 16mm (0.63"), 25 meter roll.	1	—
<b>I-Series Stainless Steel Buckles</b>			
IMSBL9.5-C6L	316L stainless steel buckle, 9.5mm (0.37").	100	1000
IMSBL12-C6L	316L stainless steel buckle, 12mm (0.47").	100	1000
IMSBL16-C6L	316L stainless steel buckle, 16mm (0.63").	100	500
IMSBE19-C6L	316L stainless steel buckle, 19mm (0.75").	100	500
<b>MLT 316 Stainless Steel Ties</b>			
MLT2S-CP316	316L stainless steel, Standard, 201mm (7.9"), 0.25 mm (0.010") thickness.	100	500
MLT4S-CP316	316L stainless steel, Standard, 362mm (14.3"), 0.25 mm (0.010") thickness.	100	500
MLT2H-LP316	316L stainless steel, Heavy, 201mm (7.9"), 0.25 mm (0.010") thickness.	50	250
MLT4H-LP316	316L stainless steel, Heavy, 362mm (14.3"), 0.25 mm (0.010") thickness.	50	250

(continued on page 9)



## Stainless Steel Cable Ties and Permanent Identification (continued)



Permanent Identification



GS4MT



MEHT187

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>MLT 304 Stainless Steel Ties</b>			
MLT1S-CP	304 stainless steel, Standard, 127mm (5.0"), 0.25 mm (0.010") thickness.	100	500
MLT2S-CP	304 stainless steel, Standard, 201mm (7.9"), 0.25 mm (0.010") thickness.	100	500
MLT2.7S-CP	304 stainless steel, Standard, 259mm (10.2"), 0.25 mm (0.010") thickness.	100	500
MLT4S-CP	304 stainless steel, Standard, 362mm (14.3"), 0.25 mm (0.010") thickness.	100	500
MLT4H-LP	304 stainless steel, Heavy, 362mm (14.3"), 0.25 mm (0.010") thickness.	50	250
MLT6H-LP	304 stainless steel, Heavy, 521 mm (20.5"), 0.25 mm (0.010") thickness.	50	250
MLT8H-LP	304 stainless steel, Heavy, 679 mm (26.8"), 0.25 mm (0.010") thickness.	50	250
<b>Strapping</b>			
MSCNW50T15-QR6	Custom strapping, 316 stainless steel, nylon FC, 0.50" (12.7mm) width, 82.5' (25m), 0.015" (.38mm) thickness.	1	—
MSBW50-C6	Individual low profile buckle used with custom length strapping, 0.50" (12.7mm) width, 0.64mm thickness.	100	1000
MSCNW63T15-QR6	Custom strapping, 316 stainless steel, nylon FC, 0.63" (15.9mm) width, 82.5' (25m), 0.015" (.38mm) thickness.	1	—
MSBW63-C6	Individual low profile buckles used with custom length strapping, 0.63" (15.9mm) width, 0.64mm thickness.	100	1000
PCSSH-B-CR	Cushion sleeving, Super-Heavy, 100' (30.5m) x 0.91" (23.1mm) width.	1	—
<b>Permanent Identification</b>			
MMP350-C316	Marker plate, 316 stainless steel, 4-hole 3.5" x 0.75" x 0.010" (89mm x 19mm x 0.25mm) thickness.	100	1000
MMP350H-C316	Marker plate, 316 stainless steel, 4-hole, 3.5" x 0.75" x 0.010" (89mm x 19mm x 0.25mm) thickness.	100	1000
MMP350W38-C316	Marker plate, 316 stainless steel, 4-hole, 3.5" x 0.38" x 0.010" (89mm x 10mm x 0.25mm) thickness.	100	1000
<b>Installation Tools</b>			
GS4MT	Installation tool, MLT ties, controlled tension gun style, Standard, Light-Heavy, Heavy cross section.	1	—
ST2MT	Installation tool, MLT ties, twist cut off, Light-Heavy and Super-Heavy cross section.	1	—
BT2HT	Tool for MSCNW**T15-QR6.	1	—
MEHT187	Metal tape embossing tool.	1	—
METS3-X	Embossing tape, 316 steel, 0.5" X 21' (12.7mm x 6.4m).	10	40
METS4-X	Embossing tape, 304 steel, 0.5" X 21' (12.7mm x 6.4m).	10	40

## Safety Products



PSL-1



PSL-CBNT

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Padlocks</b>			
PSL-1	Hasp, 1" (25.4mm) diameter jaw with tabs.	12	48
PSL-8	Red plastic body padlock.	1	6
PSL-8YL	Yellow plastic body padlock.	1	6
<b>Lockout Devices</b>			
PSL-BV1	Ball valve lockout device, 0.25" – 1.00" (6.35mm – 25.4mm) valve size, Red.	1	10
PSL-CB	Universal circuit breaker lockout device, Red.	1	10
PSL-CBL	Large handle circuit breaker lockout device, 0.80" (20.32mm) thick x 3" (76.2mm) wide, Red.	1	10
PSL-CBNT	"No tool" circuit breaker lockout device, Red.	1	10
PSL-CBILNT	"No tool" I-LINE circuit breaker lockout device, Red.	1	10
PSL-MCBNT	"No tool" miniature circuit breaker lockout.	1	10
PSL-MLD	Multiple lockout hasp with 6' vinyl coated galvanized steel cable with loophole, Red.	1	20
PSL-PCB	PowerLOK™ Circuit Breaker Lockout Device, Red.	1	10
PSL-PCBNT	PowerLOK™ "No Tool", Circuit Breaker Lockout Device, Red.	1	10
PSL-V2A	Gate valve lockout device for 1" – 2.50" (25.4mm – 63.5mm) diameter handle, Red.	1	10
PSL-V9	Gate valve lockout device for 6.5" – 10" (165mm – 254mm) diameter handle, Red.	1	10
PVT-42-Q	Plastic tag, 'Danger Do Not Operate', 25 tags and ties per package, Red Black/White.	1	4

## Computer Printables



Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Laser/Injet Self-Laminating Labels</b>			
S050X150YAJ	Laser/ink jet, self-laminating label, polyester, 0.50"W x 1.50"L (12.7mm x 38.1mm), 0.50" (12.7 mm), print-on area, Clear/White.	5000	25000
S100X125YAJ	Laser/ink jet, self-laminating label, polyester, 1.00" W x 1.25" L, (25.4mm x 31.75mm), 0.38" (9.144mm) print-on area, Clear/White.	2500	10000
S100X150YAJ	Laser/ink jet, self-laminating label, polyester, 1.00"W x 1.50"L, (25.4mm x 38.1mm), 0.50" (12.7mm) print-on area, Clear/White.	2500	10000
S100X225YAJ	Laser/ink jet, self-laminating label, polyester, 1.00"W x 2.25"L, (25.4mm x 57.2mm), 0.75" (19mm) print-on area, Clear/White.	1000	5000
S100X400YAJ	Laser, self-laminating label, polyester, 1.00" W x 4.00" L, (25.4mm x 101.6mm), 1.00" (19.05mm) print-on area, Clear/White.	1000	5000

<b>Thermal Transfer Self-Laminating Labels</b>			
S100X075VA1Y	Thermal transfer, self-laminating label, vinyl, 1.00"W x 0.75"H, (25.4mm x 19.05mm), 0.25" (6.35mm) print-on area, Clear/White, 1" core.	2500	10000
S100X150VATY	Thermal transfer, self-laminating label, vinyl, 1.00"W x 1.50"H, (25.4mm x 38.1), 0.50" (12.7mm) print-on area, Clear/White, 3" core.	5000	20000
S100X225VATY	Thermal transfer, self-laminating label, vinyl, 1.00"W x 2.25"H, (25.4mm x 57.15mm), 0.75" (19.05mm) print-on area, Clear/White, 3" core.	5000	20000
S100X400VA1Y	Thermal transfer, self-laminating label, vinyl, 1.00"W x 4.00"H, (25.4mm x 101.6mm), 1.00" (25.4mm) print-on area, Clear/White, 1" core.	1000	4000
S100X400VATY	Thermal transfer, self-laminating label, vinyl, 1.00"W x 4.00"H, (25.4mm x 101.6mm), 1.00" (25.4mm) print-on area, Clear/White, 3" core.	2500	12500
H200X034H1T	Thermal transfer, heat shrink tubing, Military grade polyolefin, 2.00"W x 0.34"H (50.8mm x 8.636mm), White, 500 pieces.	1	—
M300X050Y6T	Thermal transfer, marker plate, polyester/polyolefin, 3.00"W x 0.50"H, (76.2mm x 12.7mm) Yellow.	1	—
R100X150V1T	Thermal transfer, Turn-Tell™ Vinyl Label, 1.00"W X 1.50"H, (25.4mm x 38.1mm), 0.50" (12.7mm) print-on area, Clear/White, 3" core.	2500	10000
R100X150X1J	Laser printable, Turn-Tell™ Polymer Label, 1.00"W x 1.50"H, (25.4mm x 38.1mm), 0.50" (12.7mm) print-on area, Clear/White.	1000	5000



TDP43ME/E

<b>Ribbon</b>			
RMEH4BL	Ribbon, hybrid, 4.25" (1.29m) wide, 300' long (91.44m), for use with TDP43ME, Black.	1	12
RMER4BL	Ribbon, resin, 4.25" (1.29m) wide, 300' long (91.44m) long, for use with TDP43ME, Black.	1	12

<b>Printers</b>			
TDP43ME/E	300 dpi printer, including Easy-Mark™ Labeling Software and RMEH4BL hybrid ribbon.	1	—
TDP43ME-RS	External label roll stand to rear feed labels, supplied on 3" (76.2mm) cores.	1	—

## Labeling Systems



Heatshrink

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Continuous Heatshrink Tubing</b>			
H000X025H1C	P1™ Cassette, continuous heatshrink tubing, Military grade polyolefin, 8"W x 0.25"H (2.4384m x 6.35mm), White.	1	10

<b>Vinyl Self-Laminating Labels</b>			
R100X150V1C	P1™ Cassette, Turn-Tell™ Self-Laminating Label, vinyl, 1.00"W x 1.50"H, (25.4mm x 38.1mm), 0.50" (12.7mm) print-on area, Clear/White.	1	10
S100X150VAC	P1™ Cassette, self-laminating label, vinyl, 1.00"W x 1.50"H, 25.4mm x 38.1mm), 0.50" (12.7mm) print-on area, Clear/White.	1	10
S100X225VAC	P1™ Cassette, self-laminating label, vinyl, 1.00"W x 2.25"H, (25.4mm x 57.15mm), 0.75" (19.05mm) print-on area, Clear/White.	1	10

<b>Vinyl Cloth Continuous Tape</b>			
T038X000VPC-BK	P1™ Cassette, continuous tape, vinyl, 0.38"W x 25'L (9.652mm x 7.62m), Black on White.	1	10
T100X000VPC-BK	P1™ Cassette, continuous tape, vinyl, 1.00"W x 25'L (25.4mm x 7.62m), Black on White.	1	10
T100X000VXC-BK	P1™ Cassette, continuous tape, vinyl, 1.00"W x 25'L (25.4mm) x 7.62m), Yellow/Black.	1	10



LS8EQ-KIT

<b>Printers</b>			
LS8EQ	QWERTY LS8E, Printer	1	4
LS8EQ-KIT	QWERTY LS8EQ, printer kit.	1	2

## Abrasion Protection




Grommet Edging



Spiral Wrap

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Corrugated Loom Tubing</b>			
CLT50F-C20	Corrugated loom tubing slit, 0.50" (12.7mm) X 100' (30.5m), Black.	1	—
CLT125F-L20	Corrugated loom tubing slit, 1.25" (31.8mm) X 50' (15.2m), Black.	1	—
CLT150F-X4	Corrugated loom tubing slit, 1.50" (38.1mm) X 10' (3.0m), Yellow.	1	—
<b>Grommet Edging</b>			
GEE62F-A-C	Adhesive lined, 0.062" (1.57mm) thickness, polyethylene, Natural.	1	—
GEE62F-A-C0	Adhesive lined, 0.062" (1.57mm) thickness, weather resistant polyethylene, Black.	1	—
GEE71N-C	0.079" (2.01mm) thickness, nylon 6, Natural.	1	—
GEE99F-C	0.099" (2.5146mm) thickness, polyethylene, natural, Natural.	1	—
GEE99FR-CY	0.099" (2.5146mm) thickness, flame retardant polyethylene, Natural.	1	—
GES62F-A-C	Adhesive lined, 0.062" (1.57mm) thickness, polyethylene, Natural.	1	—
GEE99F-A-C	Adhesive lined, 0.099" (2.5146mm) thickness, polyethylene, Natural.	1	—
GEE99F-A-C0	Adhesive lined, 0.099" (2.5146mm) thickness, weather resistant polyethylene, Black.	1	—
GES99F-A-C0	Adhesive lined, 0.099" (2.5146mm) thickness, weather resistant polyethylene, Black.	1	—
GEE144F-A-C	Adhesive lined, 0.144" thickness, polyethylene, Natural.	1	—
GEE144F-A-C0	Adhesive lined, 0.144" (3.66mm) thickness, weather resistant polyethylene, Black.	1	—
<b>Spiral Wrap</b>			
T25FR-CY	0.25" (6.3mm) x 100', flame retardant polyethylene, Natural.	1	—
T25FR-MY	0.25" (6.3mm) x 1000', flame retardant polyethylene, Natural.	1	—
T25FR-C20Y	0.25" (6.3mm) x 100', flame retardant polyethylene, Black.	1	—
T38FR-C20Y	0.38" (9.7mm) x 100', flame retardant polyethylene, Black.	1	—
T62FR-CY	0.62" (15.8mm) x 100', flame retardant polyethylene, Natural.	1	—
HSTT06-CC	Heat shrink thin, 0.06" (1.6mm) diameter, Clear.	1	10
SE50PFR-CR0	Expandable sleeving, 0.50" (12.7mm), flame retardant, Black.	1	4
DS1	Duct seal compound, 1 lb. (0.454 kg).	1	30
DS5	Duct seal compound, 5 lbs. (2.27 kg).	1	6

## Wiring Duct

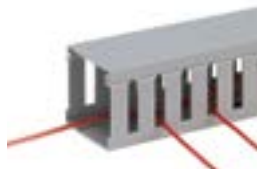

Part Number	Description	Std. Pkg. Qty.	Std. Ctn. Qty.
<b>Duct Cover</b>			
C1LG6	Duct cover, PVC, 1"W X 6' (25.4mm x 1.83m), Light Gray.	6	120
C1.5BL6	Duct cover, PVC, 1.5"W X 6' (38.1mm x 1.83m), Black.	6	120
C1.5LG6	Duct cover, PVC, 1.5"W X 6' (38.1mm x 1.83m), Light Gray.	6	120
C2LG6	Duct cover, PVC, 2"W X 6' (50.8mm x 1.83m), Light Gray.	6	120
C3LG6	Duct cover, PVC, 3"W X 6' (76.2mm x 1.83m), Light Gray.	6	120
C4LG6	Duct cover, PVC, 4"W X 6' (101.6mm x 1.83m), Light Gray.	6	120
NC1WH6	Duct cover, halogen free, 1"W X 6' (25.4mm x 1.83m), White.	6	120
FS1.5X1.5BL6	Solid raceway, PVC, 1.5" X 1.5" X 6' (38.1mm x 38.1mm x 1.83m), Black.	6	120
<b>Slotted Duct</b>			
G1X1.5LG6	Slotted duct, PVC, 1" X 1.5" X 6' (25.4mm x 38.1mm x 1.83m), Light Gray.	6	120
G1X2LG6	Slotted duct, PVC, 1" X 2" X 6' (25.4mm x 50.8mm x 1.83m), Light Gray.	6	120
G1X3LG6	Slotted duct, PVC, 1" X 3" X 6' (25.4mm x 76.2mm x 1.83m), Light Gray.	6	120
G1.5X2LG6	Slotted duct, PVC, 1.5" X 2" X 6' (38.1mm x 50.8mm x 1.83m), Light Gray.	6	120
G1.5X3LG6	Slotted duct, PVC, 1.5" X 3" X 6' (38.1mm x 76.2mm x 1.83m), Light Gray.	6	120
G1.5X4LG6	Slotted duct, PVC, 1.5" X 4" X 6' (38.1mm x 101.6mm x 1.83m), Light Gray.	6	60
G2X2LG6	Slotted duct, PVC, 2" X 2" X 6' (50.8mm x 50.8mm x 1.83m), Light Gray.	6	120
G2X3LG6	Slotted duct, PVC, 2" X 3" X 6' (50.8mm X 76.2mm X 1.83m), Light Gray.	6	60
G2X4LG6	Slotted duct, PVC, 2" X 4" X 6' (50.8mm x 101.6mm x 1.83m), Light Gray.	6	60
G3X2LG6	Slotted duct, PVC, 3" X 2" X 6' (76.2mm x 50.8mm x 1.83m), Light Gray.	6	120
G3X3LG6	Slotted duct, PVC, 3" X 3" X 6', (76.2mm x 76.2mm x 1.83m), Light Gray.	6	60
G3X4LG6	Slotted duct, PVC, 3" X 4" X 6' (76.2 mm x 101.6 mm x 1.83 m), Light Gray.	6	60
G4X2LG6	Slotted duct, PVC, 4" X 2" X 6' (101.6mm x 50.8mm x 1.83m), Light Gray.	6	60
G4X4LG6	Slotted duct, PVC, 4" X 4" X 6' (101.6mm x 101.6mm x 1.83m), Light Gray.	6	60
NE1X3WH6	Slotted duct, halogen free, 1" X 3" X 6' (25.4mm x 76.2mm x 1.83m), White.	6	120
NR1-M	Duct nylon push rivet for mounting.	1000	5000
DCT	Duct cutting tool.	1	—





**PANDUIT™**

Panduit Singapore Pte. Ltd.  
60 Tuas Avenue 11  
Singapore 639106

cs-ap@panduit.com  
1-800-PANDUIT (Singapore)  
1800 801 435 (Malaysia)  
001 803 65 7571 (Indonesia)  
001 800 65 6385 (Thailand)

[www.panduit.com](http://www.panduit.com)