

# PatchRunner™ 2 Enhanced Vertical Cable Manager with Vertical Patching

## specifications

The Patchrunner™2 Enhanced Vertical Cable Manager with Vertical Patching shall consist of a metal backbone with cable management fingers that align with EIA rack spacing. The backbone shall be an open design that will accept 19" EIA accessories such as patch panels, strain relief bars, blanking panels, and a PDU mounted vertically in a zero RU format. The fingers shall be molded out of plastic and provide integral bend radius control throughout the entire length. Finger sections shall be removable. The manager shall accept a metal, hinged, push-to-close door that can open to the right or left. The vertical panel shall be able to manage all the cable on the rack without the aid of horizontal cable managers.



PE2VD12 PE2VFD12

## key features and benefits

<b>Integral EIA 19" Zero RU Mounting</b>	Allows mounting of many standard EIA 19" accessories such as patch panels, strain relief bars, and blanking panels, within the vertical channel of the manager
<b>26.8" Extra Deep Manager</b>	26.8" depth at a 60/40 split provides the highest capacity for latest high performance switches and Category 6A cabling
<b>Improved Door Function</b>	"Push-to-close" door design allows for easy operation
<b>Dual Hinged Doors are Included</b>	Doors ship with manager, simplifying ordering process with less packaging waste
<b>Color Options</b>	Managers and doors now available in black and white as standard
<b>Highest Density with Increased Cable Capacity</b>	Up to 45% more usable capacity over PR2V manager
<b>Bend Radius Control</b>	Fingers support cables as they transition to vertical pathway while maintaining cable bend radius control, ensuring network performance and system reliability
<b>Optional Accessories</b>	Allows for personalization based on network equipment needs

## applications

Panduit Patchrunner™2 Enhanced Vertical Cable Manager with Vertical Patching is designed to manage, protect, and showcase cabling for the latest high performance switching equipment. Ideal for the highest-density cabling environments, the depth of the cable manager, and the integral Zero RU patching within the vertical channel saves up to half the space of a traditional

cabling management system. This reduction in square footage combined with simplified part number ordering leads to cost savings for the overall network infrastructure. When used with Panduit connectivity, patch cords, and racks, the user receives a complete cable management solution that maximizes density while minimizing the area required for their network.

### Vertical Cable Managers – 7 Foot

#### Double-sided with two doors:

6" wide:	PE2VD06^
8" wide:	PE2VD08^
10" wide:	PE2VD10^
12" wide:	PE2VD12^

#### Double-sided with one door:

6" wide:	PE2VSD06^
8" wide:	PE2VSD08^
10" wide:	PE2VSD10^
12" wide:	PE2VSD12^

#### Single-sided with one door:

6" wide:	PE2VFD06^
8" wide:	PE2VFD08^
10" wide:	PE2VFD10^
12" wide:	PE2VFD12^

### Vertical Cable Managers – 8 Foot

#### Double-sided with two Doors:

6" wide:	PE2VD0696^
8" wide:	PE2VD0896^
10" wide:	PE2VD1096^
12" wide:	PE2VD1296^

#### Double-sided with one door:

6" wide:	PE2VSD0696^
8" wide:	PE2VSD0896^
10" wide:	PE2VSD1096^
12" wide:	PE2VSD1296^

#### Single-sided with one door:

6" wide:	PE2VFD0696^
8" wide:	PE2VFD0896^
10" wide:	PE2VFD1096^
12" wide:	PE2VFD1296^

### Accessories

<b>7" front slack management spool:</b>	PRSP7
<b>5" rear slack management spool:</b>	PRSP5
<b>End Panel:</b>	PE2VEP^
<b>Cable retainer:</b>	WR5E-X
<b>Waterfall trough for use with 2-post and 4-post racks:</b>	PE2VWF^

### Standard EIA Racks – 7ft.

<b>2-Post Aluminum Rack with #12-24 threaded Rails:</b>	R2P^
<b>4-post Steel rack with #12-24 threaded rails:</b>	R4P^
<b>4-post steel rack with cage nut rails:</b>	R4PCN^

\*For part numbers 8 feet tall, add "96" to end of part number. Ex: PE2VEP96 or R2P96

^For part numbers in white, add "WH" to end of part number. Ex: PE2VD06WH or R2PWH

# PatchRunner™ 2 Enhanced Vertical Cable Manager with Vertical Patching

## technical information

### 7 Foot Vertical Cable Managers


Part Number	Height	Width	Depth	No. of Rack Units
<b>Double Sided</b>				
PE2VD06*	84.0" (2130mm)	6.0" (152mm)	26.8" (681mm)	45
PE2VD08*	84.0" (2130mm)	8.0" (203mm)	26.8" (681mm)	
PE2VD10*	84.0" (2130mm)	10.0" (254mm)	26.8" (681mm)	
PE2VD12*	84.0" (2130mm)	12.0" (305mm)	26.8" (681mm)	
<b>Single Sided</b>				
PE2VFD06*	84.0" (2130mm)	6.0" (152mm)	16.3" (415mm)	45
PE2VFD08*	84.0" (2130mm)	8.0" (203mm)	16.3" (415mm)	
PE2VFD10*	84.0" (2130mm)	10.0" (254mm)	16.3" (415mm)	
PE2VFD12*	84.0" (2130mm)	12.0" (305mm)	16.3" (415mm)	
<b>Double Sided - 1 Door</b>				
PE2VSD06*	84.0" (2130mm)	6.0" (152mm)	26.8" (681mm)	45
PE2VSD08*	84.0" (2130mm)	8.0" (203mm)	26.8" (681mm)	
PE2VSD10*	84.0" (2130mm)	10.0" (254mm)	26.8" (681mm)	
PE2VSD12*	84.0" (2130mm)	12.0" (305mm)	26.8" (681mm)	

\* Add "WH" to end of part numbers for white products

### 8 Foot Vertical Cable Managers

Part Number	Height	Width	Depth	No. of Rack Units
<b>Double Sided</b>				
PE2VD0696*	96.0" (2435mm)	6.0" (152mm)	26.8" (681mm)	52
PE2VD0896*	96.0" (2435mm)	8.0" (203mm)	26.8" (681mm)	
PE2VD1096*	96.0" (2435mm)	10.0" (254mm)	26.8" (681mm)	
PE2VD1296*	96.0" (2435mm)	12.0" (305mm)	26.8" (681mm)	
<b>Single Sided</b>				
PE2VFD0696*	96.0" (2435mm)	6.0" (152mm)	16.3" (415mm)	52
PE2VFD0896*	96.0" (2435mm)	8.0" (203mm)	16.3" (415mm)	
PE2VFD1096*	96.0" (2435mm)	10.0" (254mm)	16.3" (415mm)	
PE2VFD1296*	96.0" (2435mm)	12.0" (305mm)	16.3" (415mm)	
<b>Double Sided - 1 Door</b>				
PE2VSD0696*	96.0" (2435mm)	6.0" (152mm)	26.8" (681mm)	52
PE2VSD0896*	96.0" (2435mm)	8.0" (203mm)	26.8" (681mm)	
PE2VSD1096*	96.0" (2435mm)	10.0" (254mm)	26.8" (681mm)	
PE2VSD1296*	96.0" (2435mm)	12.0" (305mm)	26.8" (681mm)	

\* Add "WH" to end of part numbers for white products

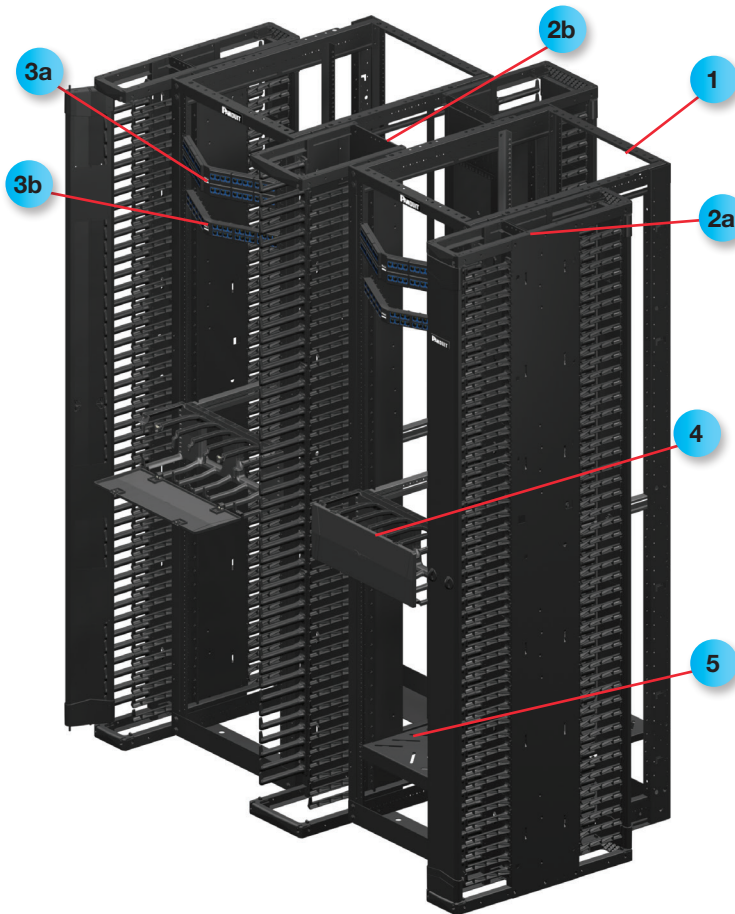

#### 4 Post Rack

1. R4P – 19" EIA Rack, 45RU x 30" Depth

#### PatchRunner™2 Enhanced Vertical Cable Managers

2a. PE2VD06 – 6" wide

2b. PE2VFD08 – 8" wide

#### Angled Modular Patch Panels

3a. CPPLA48WBLY – 2 RU, 48-Port

3b. CPPLA24WBLY – 1 RU, 24-Port

#### Cable Management Accessories

4. PR2HF4 – Cable Manager, 4 RU

5. RSHLF – 4 Post Rack Mount Shelf

#### WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA  
Phone: 800.777.3300

PANDUIT EUROPE LTD.  
London, UK  
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.  
Republic of Singapore  
Phone: 65.6305.7575

PANDUIT JAPAN  
Tokyo, Japan  
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA  
Guadalajara, Mexico  
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.  
Victoria, Australia  
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to [www.panduit.com/warranty](http://www.panduit.com/warranty)

# PANDUIT®

Visit us at [www.panduit.com](http://www.panduit.com)

[edi@panduit.com](mailto:edi@panduit.com)

© 2020 Panduit Corp.  
ALL RIGHTS RESERVED.  
CMSPO4--WW-ENG  
4/2020